


RALEC => LR2512-23R004F4 (4m ohm/2512/1%/3W)
TA-I Tech => RLP25FEGR004 (4m ohm/2512/1%/3W)
YAGEO => PA2512FKE7T0R004E (4m ohm/2512/1%/2W)

N-Channel MOSFET
PJQ5450
VDS : 40V, VGS : ± 20 V, ID : 21A, VGS(th) : 1.8V Typ

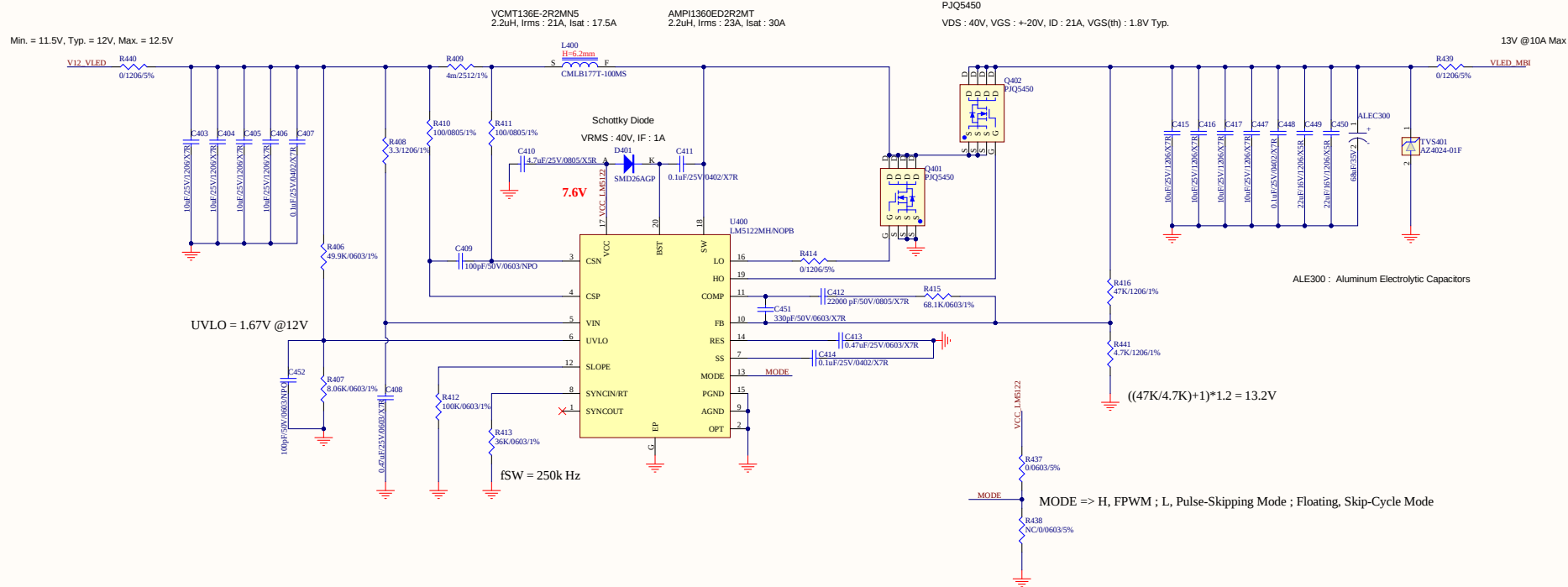

ALE300 : Aluminum Electrolytic Capacitors

MODE => H, FPWM ; L, Pulse-Skipping Mode ; Floating, Skip-Cycle Mode

Title		
Size A3	Number	Revision
Date: 7/08/2021	Sheet of	
File: C:\Users\timhuang\Desktop\Sheet1.SchDoc Drawn By:		