 




20.0 GSa/s 2.00 Mpts




1 On ☐ 2 On ☒ 2.00 V/ ☐ 3 On ☐ 4 On ☒ 1.00 A/ ☐



LM5166/ SW (10:1)

Lの電流

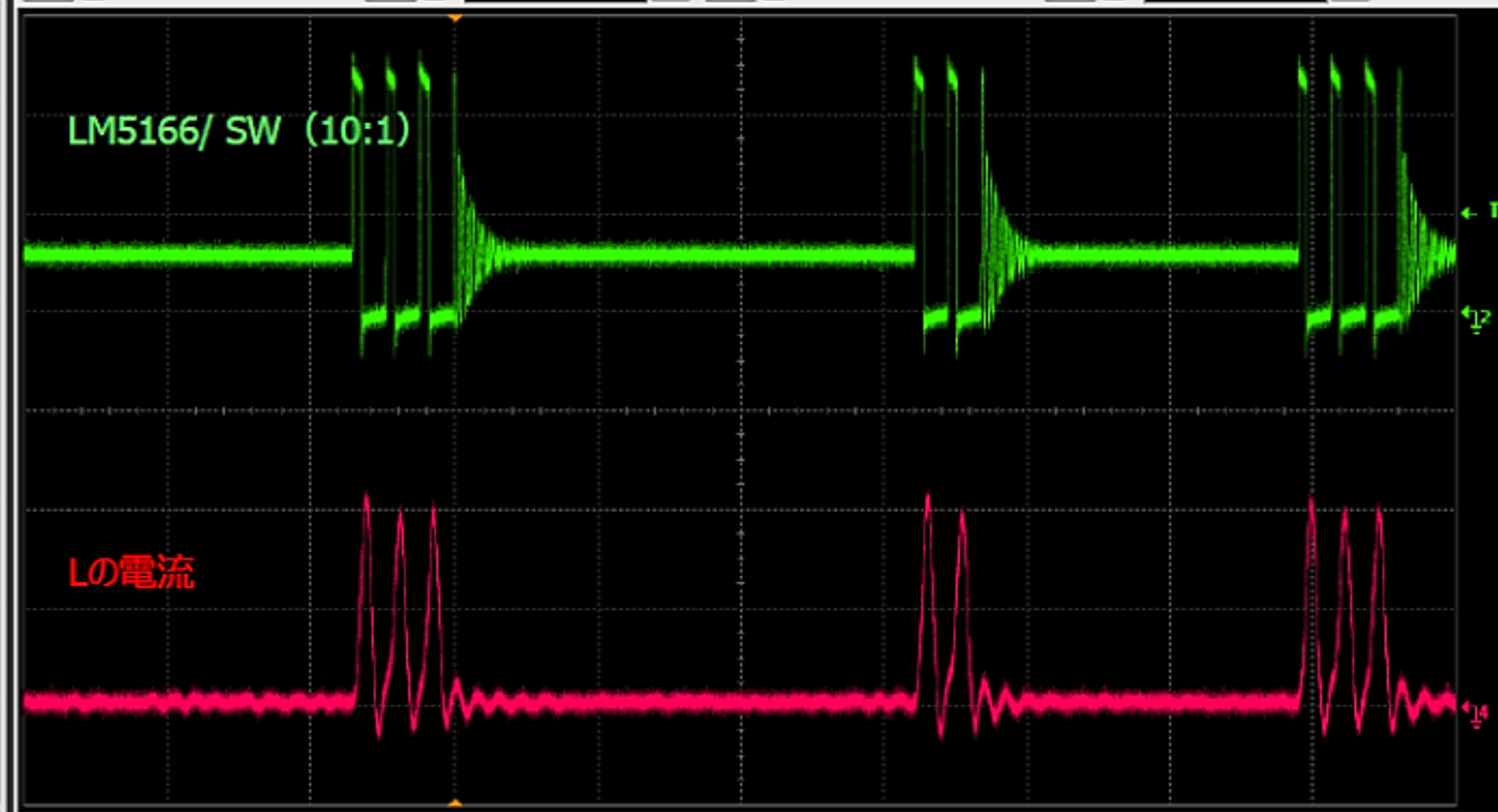

More
(1 of 2)

Delete
All

10.0 μ s/ 20.000000 μ s 2.00 V

Status Scales

Acquisition:	Trigger:
Sampling Mode Real Time	Mode Pulse (+)
Capture Time 100 μ s	Time < 200 ns
Effective Res 50.0 ps/pt	InfiniiScan Off
Bits Of Rec 8 bits	