


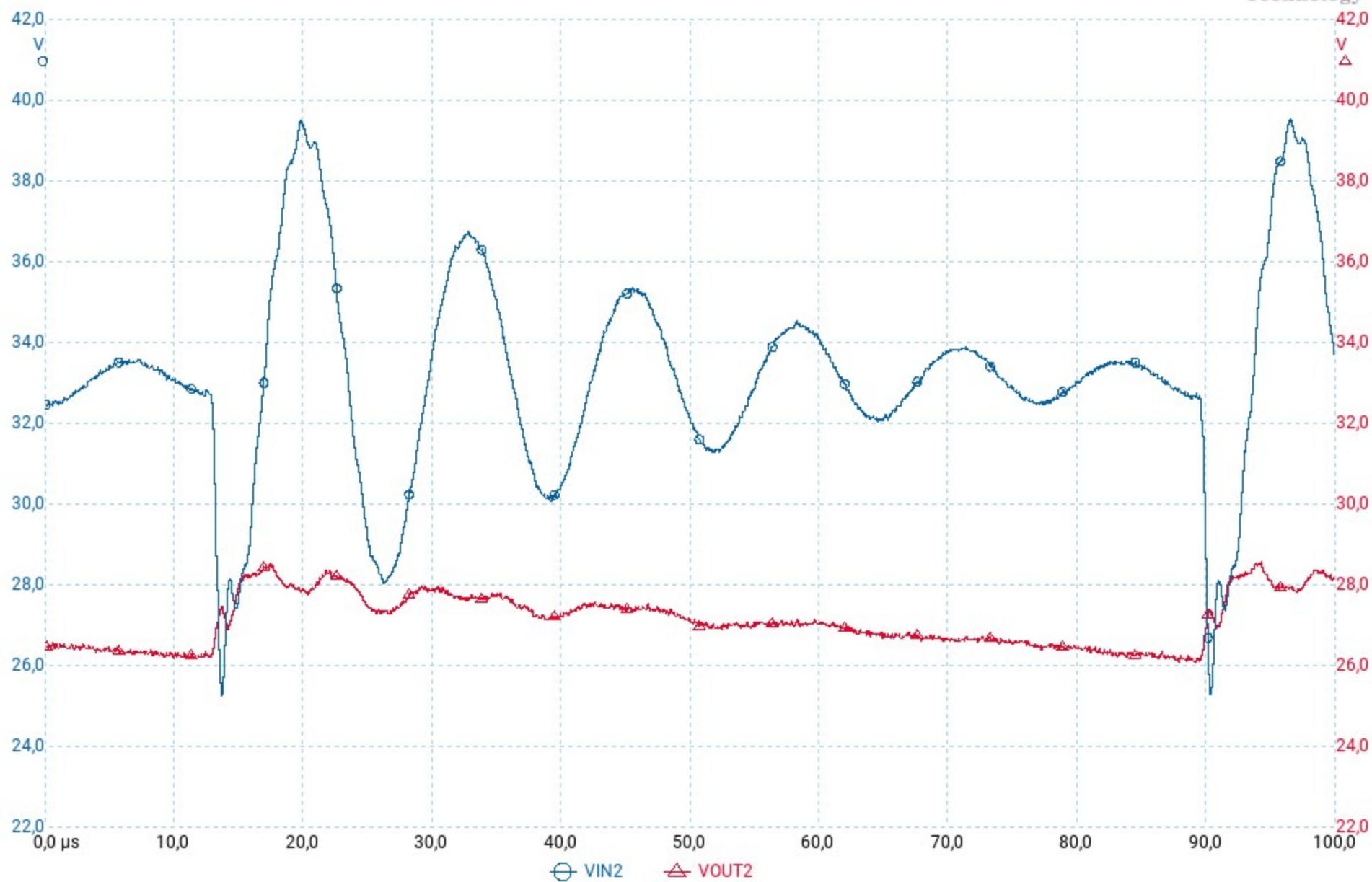

31-10-2024 09:20:31

Channel	Name	Span	Value	Min.	Max.	$\bar{x}$	σ
VIN2	Minimum	Whole trace	25,27 V	19,45 V	38 V	31,21 V	3,244 V
VIN2	Maximum	Whole trace	39,55 V	32,93 V	41,45 V	34,59 V	2,595 V
VOUT2	Minimum	Whole trace	26,09 V	-456,8 mV	36,51 V	30,68 V	5,122 V
VOUT2	Maximum	Whole trace	28,56 V	-99,96 mV	36,89 V	31,46 V	4,772 V