
 
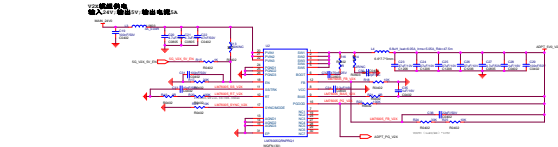



Input: 12V/24V
Output: 5V
Output current rating: 5A
Operating frequency: 398.33KHz





Input: 12V/24V
Output: 5V
Output current rating: 5A
Operating frequency: 398.33KHz

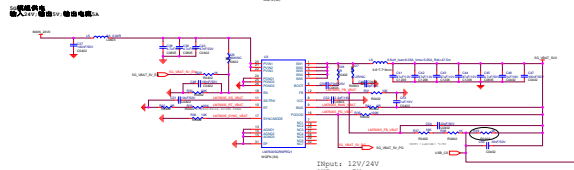



Input: 12V/24V
Output: 5V
Output current rating: 5A
Operating frequency: 398.33KHz

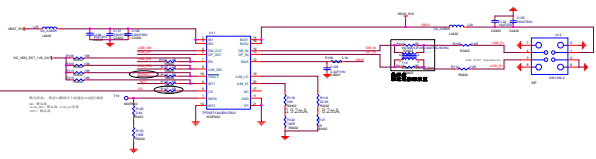

V2X模块4V电源: 输出电流2A

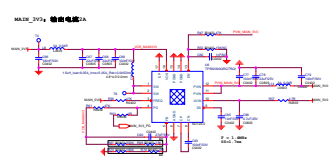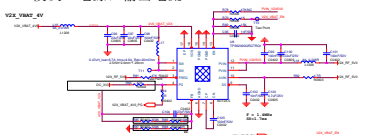

5G模块3.8V电源: 输出电流3A

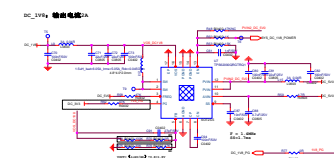 

LIN 12V电源: 输出电流30mA

