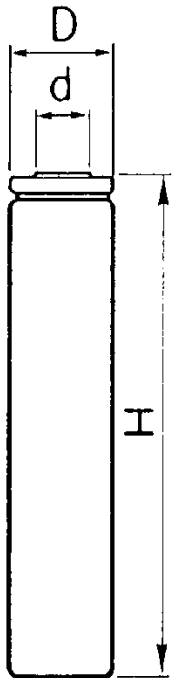


# Spec Sheet for NCR18650BF

## Cell Type NCR18650BF

### Specifications

		
Dimensions(Typ.) of Bare Cell	H	65.0mm
	D	18.2mm
	d	9.0 mm

Rated Capacity		*at 20deg.C	Min.3200mAh	*at 0.2Cdischarge
Nominal Capacity		*at 25deg.C	Min.3250mAh	*at 0.2Cdischarge
			Typ.3350mAh	*at 0.2Cdischarge
Nominal Voltage			3.6V	
Charging Method			Constant Current -Constant Voltage	
Charging Voltage			4.2V	
Charging Current			Std.1625mA	
Charging Time			3.5hrs.	
Ambient Temperature	Charge		0~+45	
	Discharge		-20~+60	
	Storage		-20~+50	
Weight (Max.)			46.5g	
Dimensions (Max.)*	(D)		18.24mm	*without tube
			18.50mm	*with tube
	(H)		65.10mm	*without tube
			65.30mm	*with tube
Volumetric Energy Density			677Wh/l	
Gravimetric Energy Density			248Wh/kg	