

RIGOL

AUTO



f



1.76U



5.00U

Time 200.0us

20.40ms

RIGOL

AUTO



f



1.76U



5.00V

Time 200.0us

20.40ms

RIGOL


5.00V



f



1.76V

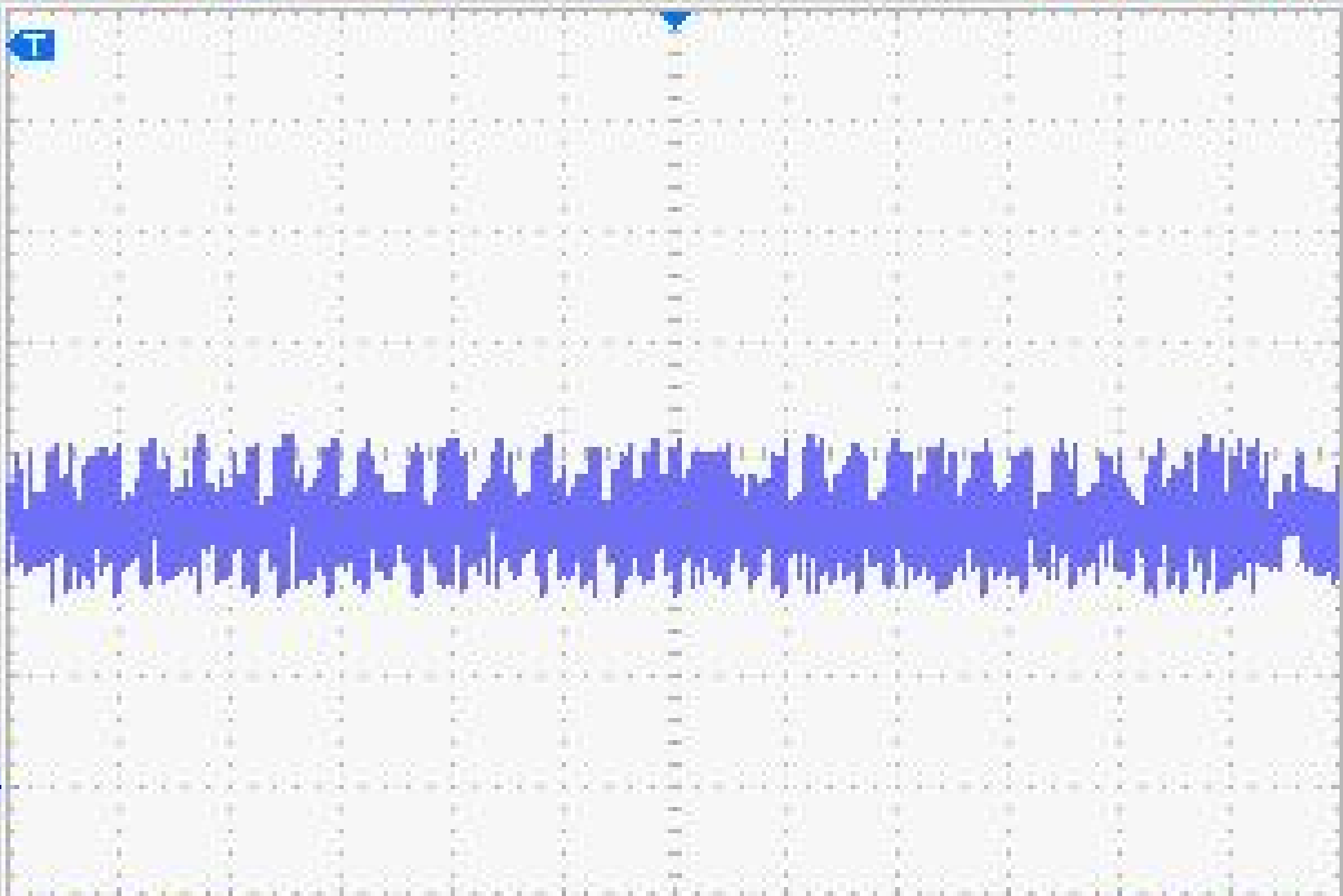

5.00V

Time 200.0us

20.40ms