


PFC in AC100V LLC out DC12V 4mA Board default

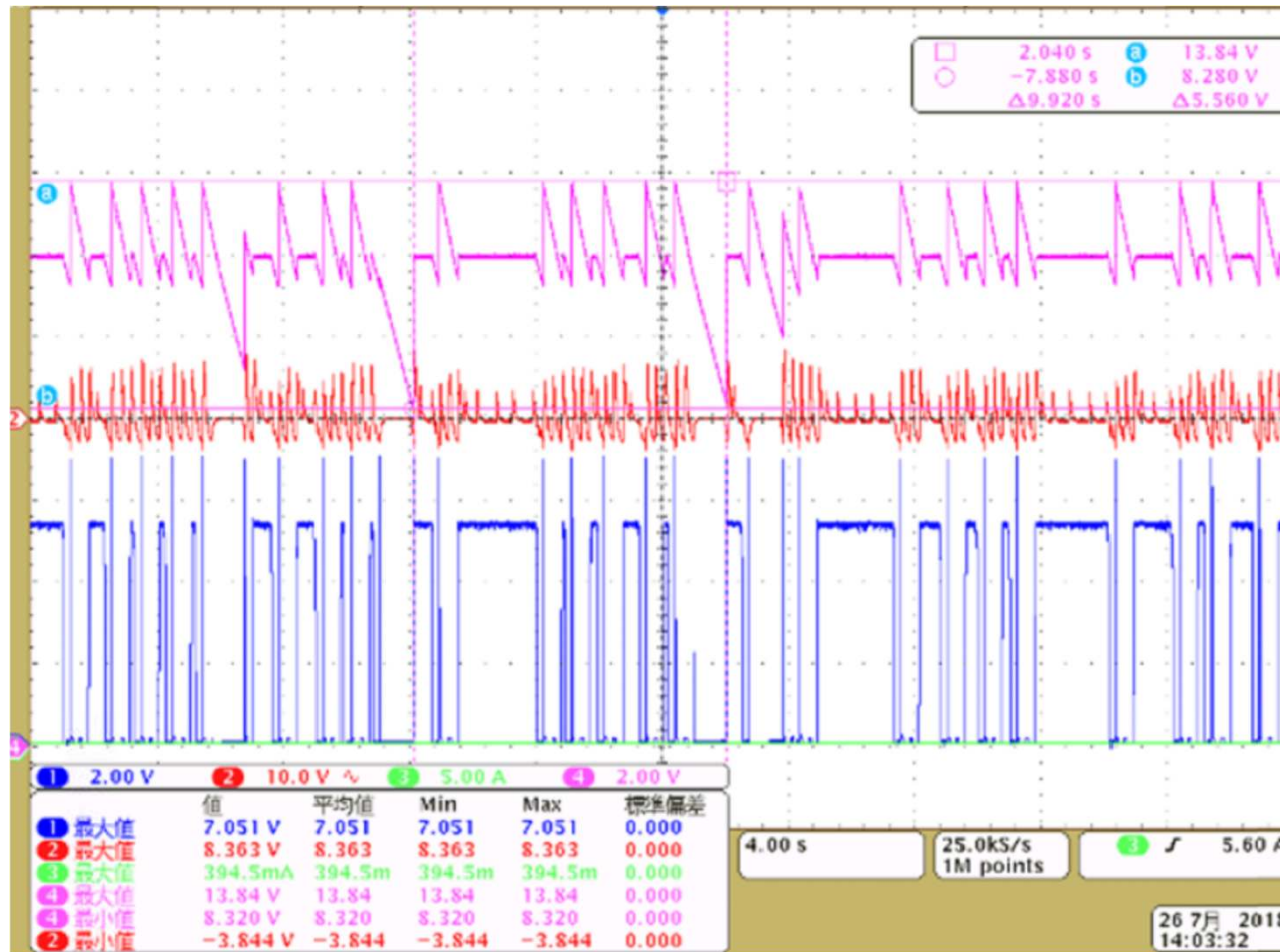

Red PFCout ripple 10v/div
Pink LLC Vout 2v/div
Blue VFB 2v/div
Green LLC Iout 5mA/div

H: 4sec/div

PFC in AC100V LLC out DC12V 4mA **C10 15nF->6.8nF**



Red PFCout ripple 10v/div
 Pink LLC Vout 2v/div
 Blue VFB 2v/div
 Green LLC Iout 5mA/div

H: 4sec/div