


Zoom Factor: 40 X

Zoom Position: -21.7µs

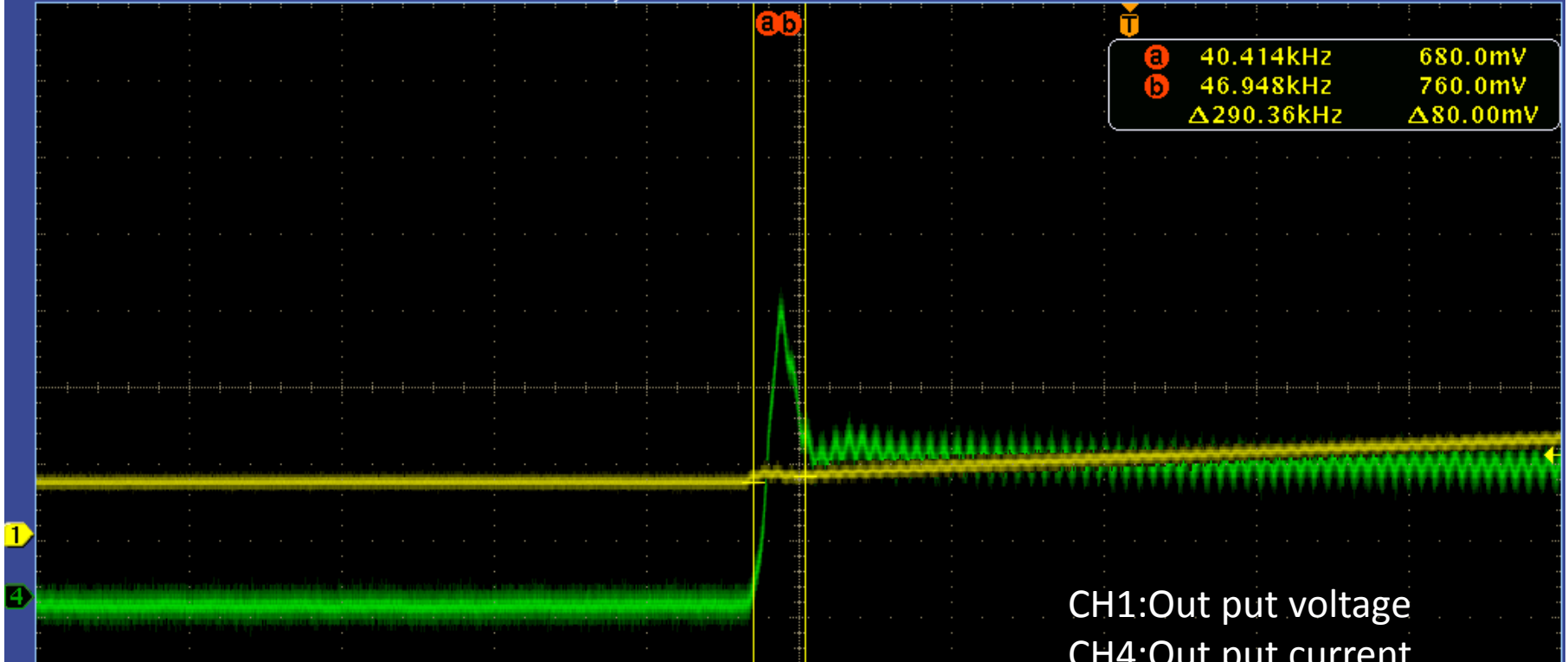

a	40.414kHz	680.0mV
b	46.948kHz	760.0mV
	Δ290.36kHz	Δ80.00mV

CH1:Out put voltage
CH4:Out put current

	Value	Mean	Min	Max	Std Dev
1 Max	1.36 V	-----	-----	-----	-----
1 RMS	867mV	-----	-----	-----	-----
1 Min	520mV	-----	-----	-----	-----
4 Max	200mA	-----	-----	-----	-----
4 RMS	66.3mA	66.3m	66.3m	66.3m	0.00
1 Peak-Peak	840mV	840m	840m	840m	0.00
4 Min	-26.0mA	-26.0m	-26.0m	-26.0m	0.00

Z 10.0µs
0.00000 s

5.00GS/s
20M points

1 1.04 V