



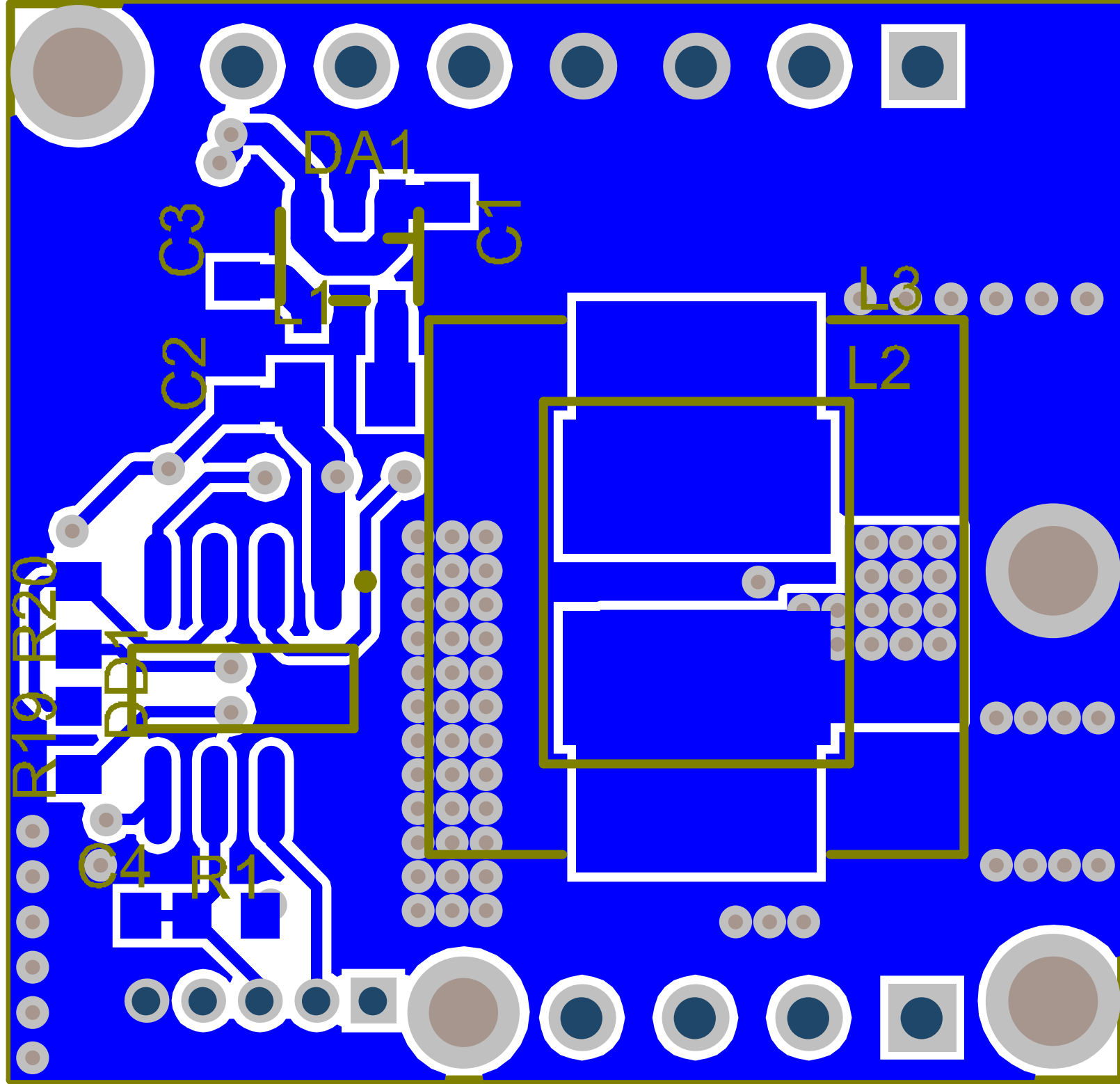

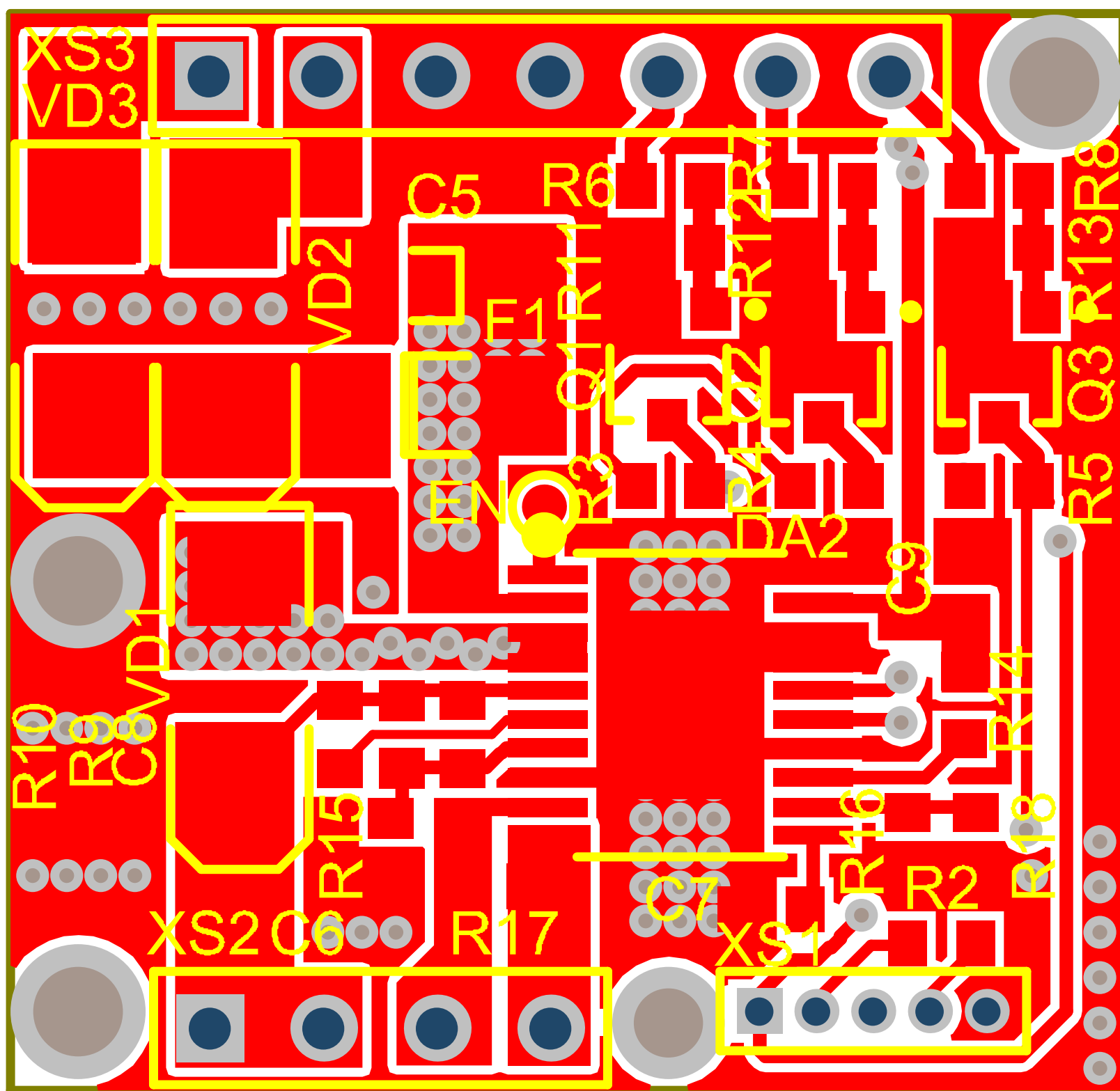

Part List		<Parameter Title not found>		
Source Data From:		SL_LSeries_test.PrjPcb		
Project:		SL_LSeries_test.PrjPcb		
Variant:		None		
Report Date: 24.06.2017		10:45:02		
Print Date: 24-Jun-17		10:45:05 AM		
Designator	Comment	LibRef	Footprint	Description
C1	1uF*25V	Cap_SMD	0603_C	Capacitor
C2	2.2uF*16V	Cap_SMD	0603_C	Capacitor
C3	10nF	Cap_SMD	0603_C	Capacitor
C4	2.2n	Cap_SMD	0603_C	Capacitor
C5	22uF*20V	Cap_POL	Case B	Polarized Capacitor (Surface Mount)
C6	1uF*50V	Cap_SMD	0603_C	Capacitor
C7	390nF*6.3V	Cap_SMD	0603_C	Capacitor
C8	10pF*50V	Cap_SMD	0603_C	Capacitor
C9	1uF*16V	Cap_SMD	0603_C	Capacitor
DA1	LP2985-3.3	LP2985	SOT-23-5	Преобразователь напряжения
DA2	LM3492	LM3492	HTTSOP-21	Two-Channel Individual Dimmable LED Driver With Boost Converter and Fast Current Regulator
DD1	MSP430G2210	MSP430G2210	D008_N	MIXED SIGNAL MICROCONTROLLER
F1	Fuse 1	Fuse 1	1808	Fuse
L1	TB201209 B601	Inductor	0805_L	Inductor
L2	10nH	Inductor	LQH66S	Inductor
L3	10nH	Inductor	CDRH127	Inductor
Q1, Q2, Q3	BC847	NPN	SOT-23	NPN Bipolar Transistor
R1	47k	Res_SMD	0603_R	Semiconductor Resistor
R2	330	Res_SMD	0603_R	Semiconductor Resistor
R3, R4, R5	4.7k*	Res_SMD	0603_R	Semiconductor Resistor
R6, R7, R8	100k	Res_SMD	0603_R	Semiconductor Resistor
R9	402k	Res_SMD	0603_R	Semiconductor Resistor
R10	226k	Res_SMD	0603_R	Semiconductor Resistor
R11, R12	20k	Res_SMD	0603_R	Semiconductor Resistor
R13	2k	Res_SMD	0603_R	Semiconductor Resistor
R14	52.3k	Res_SMD	0603_R	Semiconductor Resistor
R15	16.2k	Res_SMD	0603_R	Semiconductor Resistor
R16	8.25k	Res_SMD	0603_R	Semiconductor Resistor
R17, R19, R20	0	Res_SMD	0603_R	Semiconductor Resistor
R18		Res_SMD	0603_R	Semiconductor Resistor
VD1, VD2, VD3	B2100	D Schottky	SMB	Schottky Diode
XS1	PLS-5	2-Wire	MHDR1X5	
XS2	Header 4	Header 4	HDR1X4	Header, 4-Pin
XS3	Header 7	Header 7	HDR1X7	Header, 7-Pin