
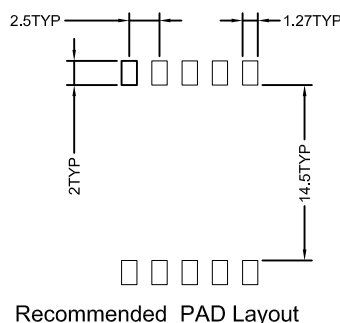
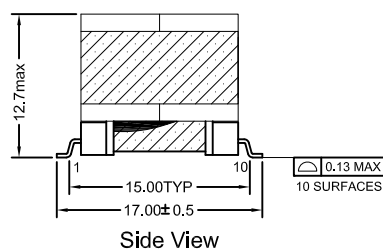


- IEC60950 Compatible.
- RoHS Compliant.
- SMT Transformers.
- Operating Temperature range: -40 °C to 85 °C.
- Bobbin meet 94-V0

Electrical Specifications @25°C


Part Number	Turns Ratio(± 0.3 TS) @20KHz,1V	OCL(μ H $\pm 5\%$) @100KHz,0.3V	LK(μ H Max.) @100KHz,0.3V	DCR (m Ω Max.)			HI-POT (VAC,3S)	
	3-1 : 5-4 : 6,7-9,10	3-1	3-1 (short other pins)	3-1	5-4	6,7-9,10	PRI TO SEC	WDG TO CORE
TOEP13	28:8:8	150	5	TBD	TBD	TBD	1500	500

MECHANICAL DIMENSIONS

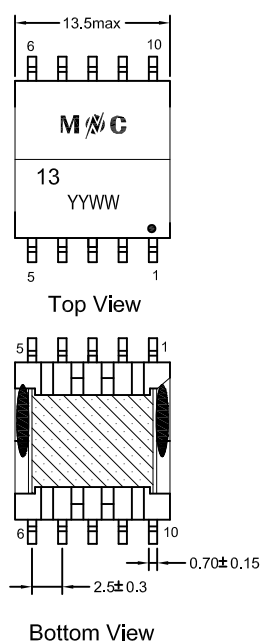

- Unless otherwise specified all tolerances are: ± 0.25 in mm

SCHEMATICS

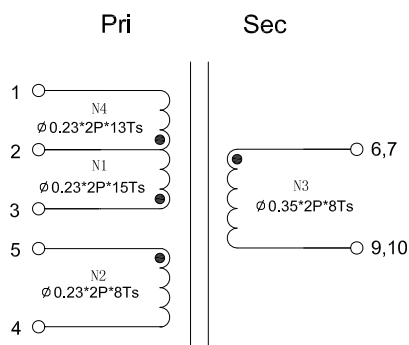

Winding construction

