



1. Select your configuration:


Are you a power source (provider) and a power sink (consumer)?

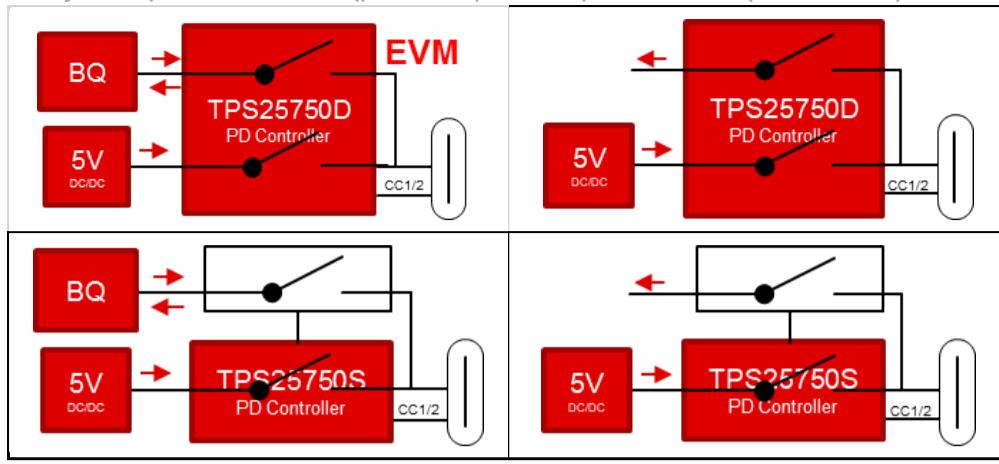

Are you a power sink (consumer) only?

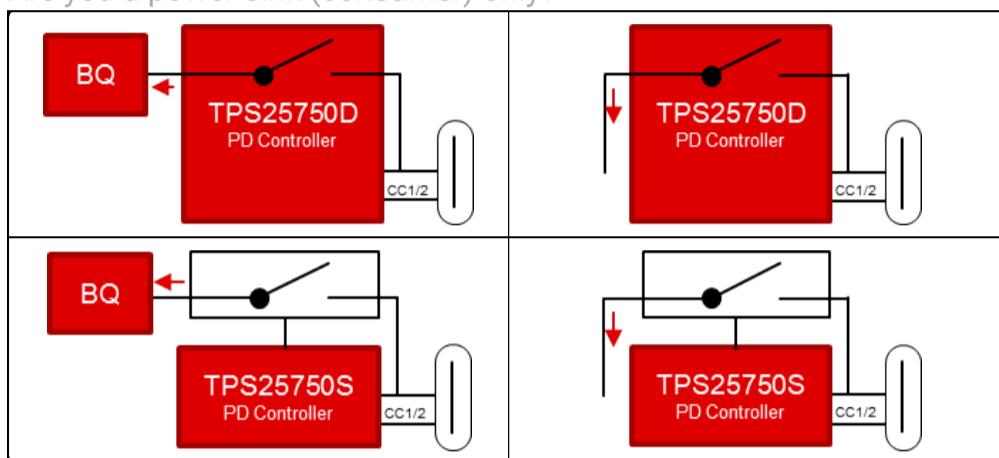

Are you a 5V @ 3A power source (provider) only?

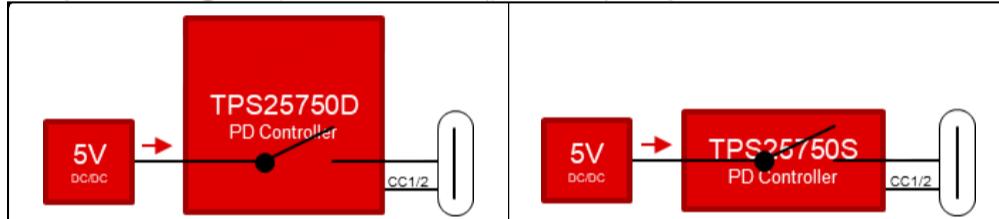

2. What is the maximum power that can be sourced?

- 15W (5V)
- 27W (9V)
- 45W (15V)
- 60W (20V)
- 100W (20V)

3. What is the required sink power or power consumed?

- 15W (5V)
- 27W (9V)
- 45W (15V)
- 60W (20V)
- 100W (20V)

4. What is the preferred power role?

- Power source (provider)
- Power sink (consumer)

5. What is the supported USB Highest Speed?

- No USB data is being used
- USB 2
- USB 3.2 Gen 1
- USB 3.2 Gen 2

6. Do you have a preferred data role?

- No
- Host (PC, hub, etc.) to which devices are connected - Downstream Facing Port (DFP)
- Device (USB flash drive, USB monitor, USB mouse, etc.) that connects to another USB Host - Upstream Facing Port (UFP)
- Host & Device - Dual Role Port (DRP)

7. Do you have a Vendor ID provided by the USB-IF?

- Yes, enter here as a 4-digit hexadecimal number: e.g. 0a8f, BC23
- No, use the TI Vendor ID in the Vendor Information File (VIF)

8. Do you have a desired Product ID?

- Yes, enter here as a 4-digit hexadecimal number: e.g. 123d, FA10

New Configuration

Advanced Configuration

Export Settings

Import Settings

Browse

Generate Low Region Binary

Generate Full Flash Binary

Generate VIF File

Flash To Device From Current Configuration

Flash To Device From Binary File

Select Binary File

Browse