


Evaluating Environment

Sink side
TPS25750EVM

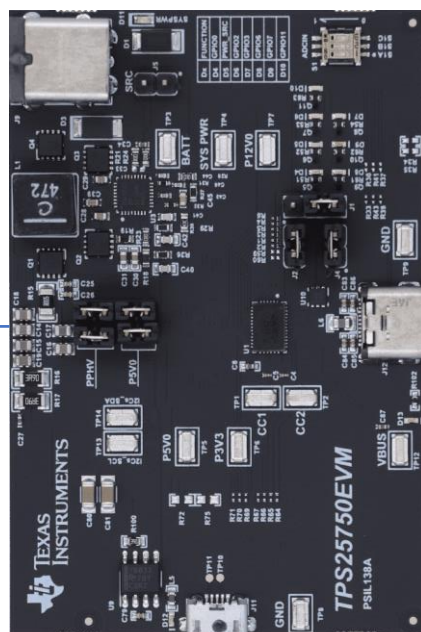


E-Load

PC

USB-PD
Protocol Analyzer

Source side
USB-PD-CHG-EVM-01

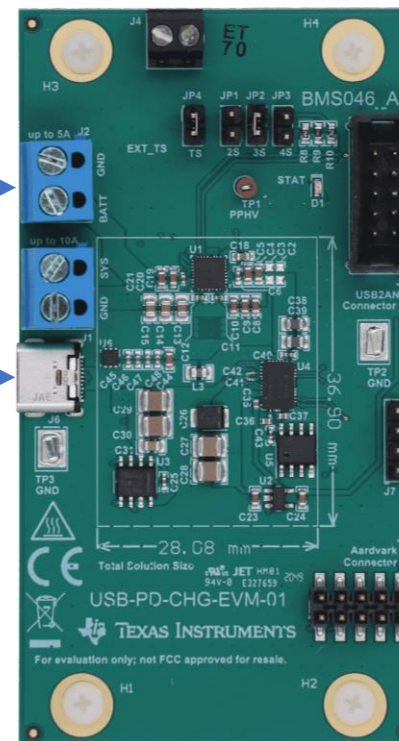

9V/3A

DC/DC 15V

Evaluating Environment

Packet	Direction	Source	Destination	Msg Type	DR	PR	Msg ID	Max Cur	Voltage	Max Cur	Voltage	Duration	Idle	Time Stamp
32	Left	SRC	SOP	Source Cap	DFP	SRC	4	Fixed 3.00 A	5.00 V	Fixed 3.00 A	9.00 V	752.732 us	61.684 us	5 . 202 722 780
33	Right	SOP	SNK	GoodCRC	UFP	SNK	4					488.187 us	4.098 ms	5 . 203 537 176
34	Right	SOP	SNK	Request	UFP	SNK	0	RDO 3.00A	3.00A	0	2	621.214 us	53.138 us	5 . 208 123 016
35	Left	SRC	SOP	GoodCRC	DFP	SRC	0					487.452 us	4.135 ms	5 . 208 797 388
36	Left	SRC	SOP	Accept	DFP	SRC	5					487.599 us	53.337 us	5 . 213 419 400
37	Right	SOP	SNK	GoodCRC	UFP	SNK	5					488.187 us	46.045 ms	5 . 213 960 336

It establishes a CC link negotiation, but it repeats itself over and over again.

