



Horizontal



Period



Freq



Rise Time




Fall Time



+Width



-Width

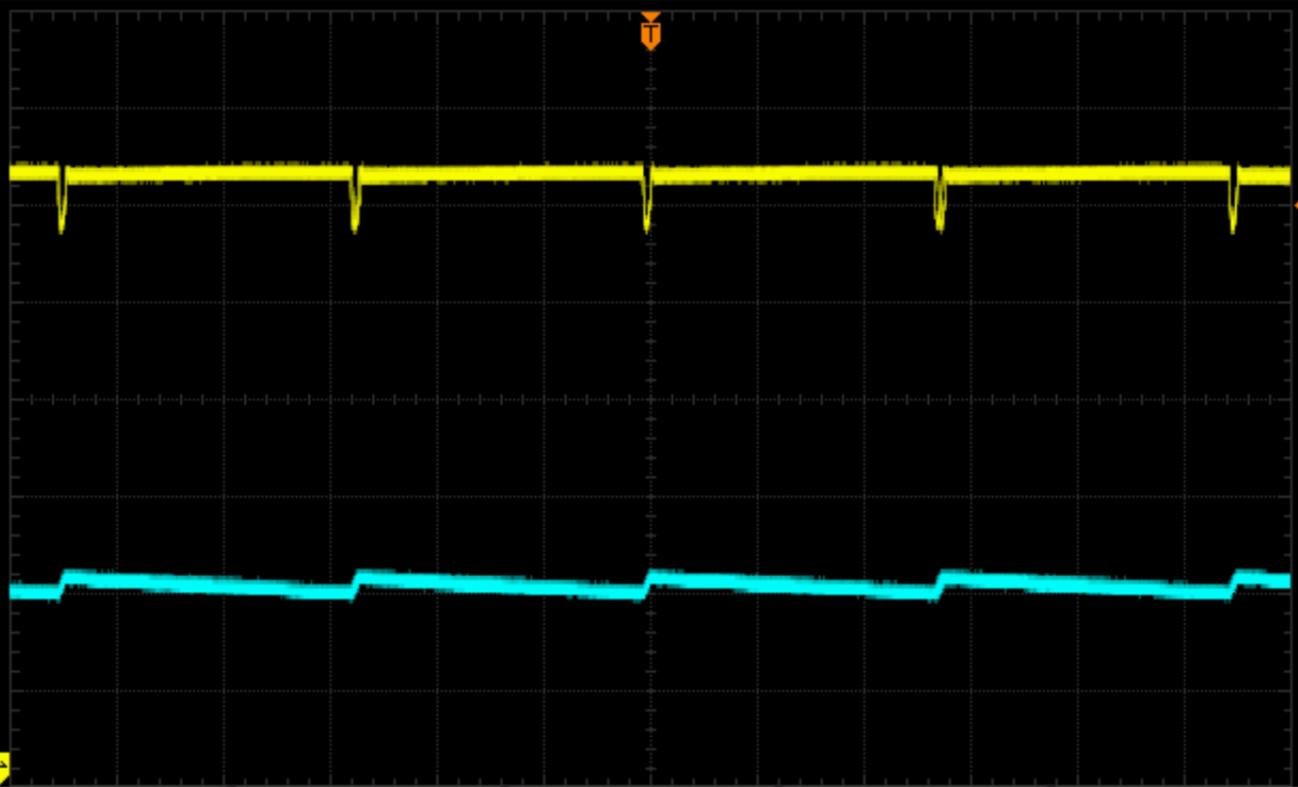

Save

Save

New File

NewFolder

Delete

Period 1	Cur: 1.380ms Avg: 1.378ms Max: 1.420ms Min: 1.360ms	Freq 1	Cur: 725 Hz Avg: 725 Hz Max: 735 Hz Min: 704 Hz	Min 1	Cur: 2.92 V Avg: 2.92 V Max: 2.92 V Min: 2.92 V	Max 1	Cur: 3.28 V Avg: 3.28 V Max: 3.28 V Min: 3.28 V	Max 2	Cur: 5.26 V Avg: 5.26 V Max: 5.28 V Min: 5.26 V
-------------------------------	--	-----------------------------	--	----------------------------	--	----------------------------	--	----------------------------	--

1 = 500mV

2 = 500mV

3 = 10.0mV

4 = 1.00 V





Horizontal



Period



Freq



Rise Time




Fall Time



+Width



-Width

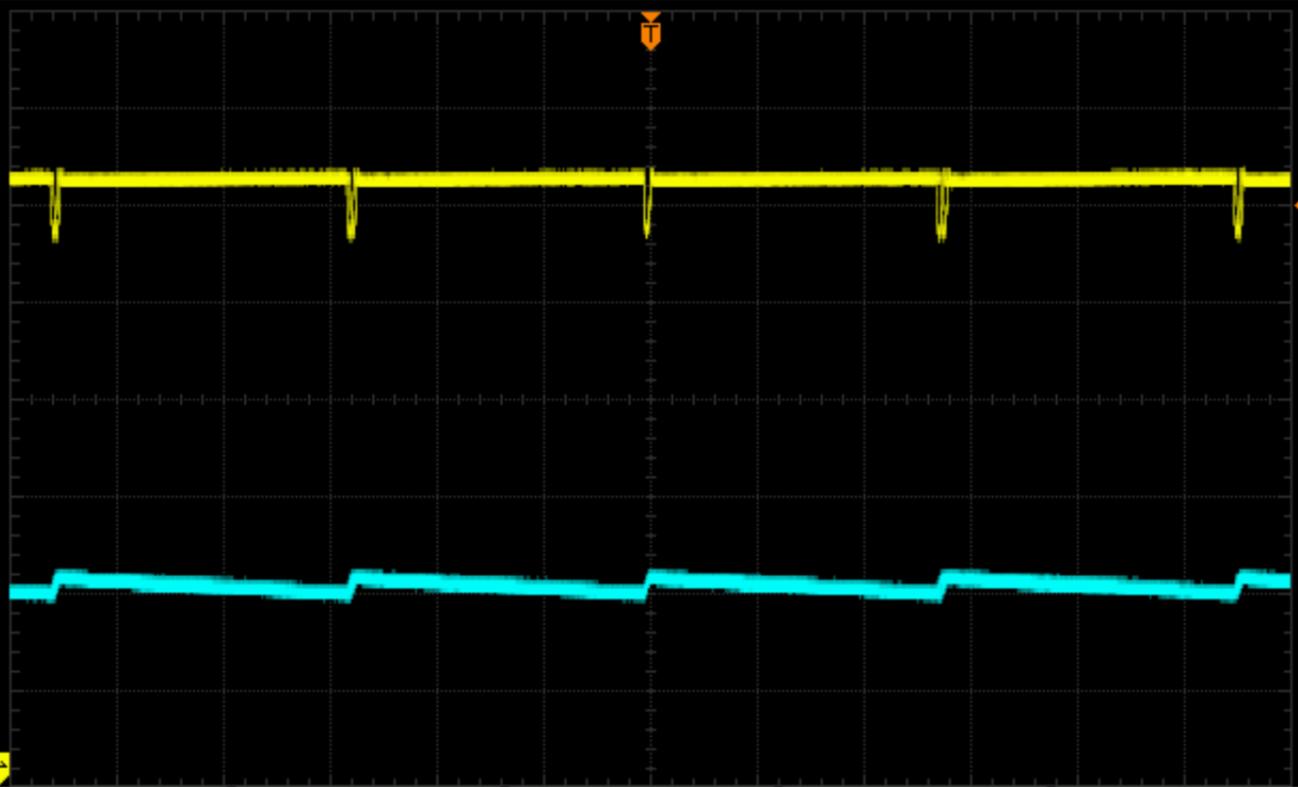

Save

Save

New File

NewFolder

Delete

Period 1	Cur: 1.390ms Avg: 1.385ms Max: 1.410ms Min: 1.360ms	Freq 1	Cur: 719 Hz Avg: 722 Hz Max: 735 Hz Min: 709 Hz	Min 1	Cur: 3.40 V Avg: 3.40 V Max: 3.42 V Min: 3.40 V	Max 1	Cur: 3.78 V Avg: 3.76 V Max: 3.78 V Min: 3.76 V	Max 2	Cur: 5.26 V Avg: 5.26 V Max: 5.28 V Min: 5.26 V
-------------------------------	--	-----------------------------	--	----------------------------	--	----------------------------	--	----------------------------	--

1 = 500mV


2 = 500mV

3 = 10.0mV

4 = 1.00 V



- Horizontal
- Period
- Freq
- Rise Time
- Fall Time
- +Width
- Width

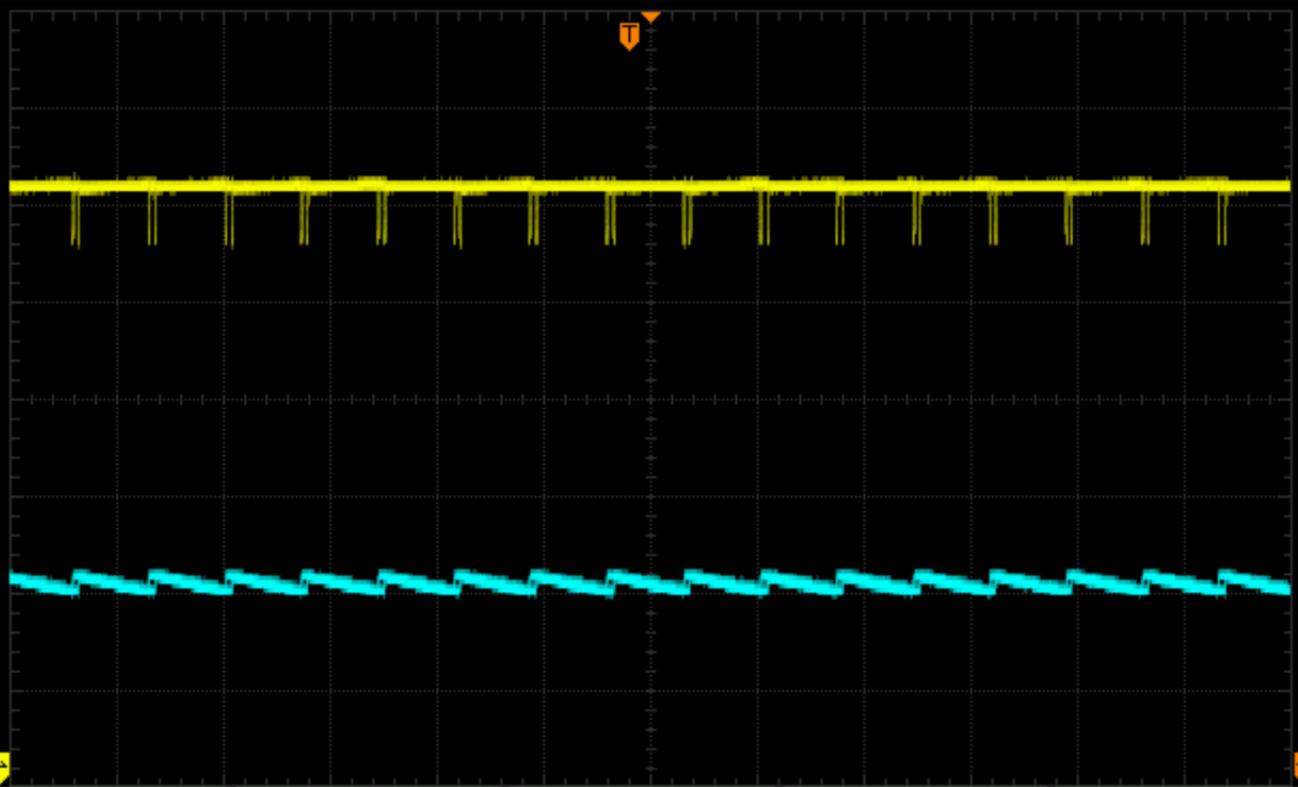

- Save
- New File
- NewFolder
- Delete

Period 1	Cur:1.440ms Avg:1.433ms Max:1.480ms Min:1.400ms	Freq 1	Cur:694 Hz Avg:698 Hz Max:714 Hz Min:676 Hz	Min 1	Cur:3.84 V Avg:3.84 V Max:3.86 V Min:3.84 V	Max 1	Cur:4.20 V Avg:4.21 V Max:4.22 V Min:4.20 V	Max 2	Cur:5.28 V Avg:5.29 V Max:5.30 V Min:5.28 V
-------------	--	-----------	--	----------	--	----------	--	----------	--

