


2MHz setting by SYNC pin

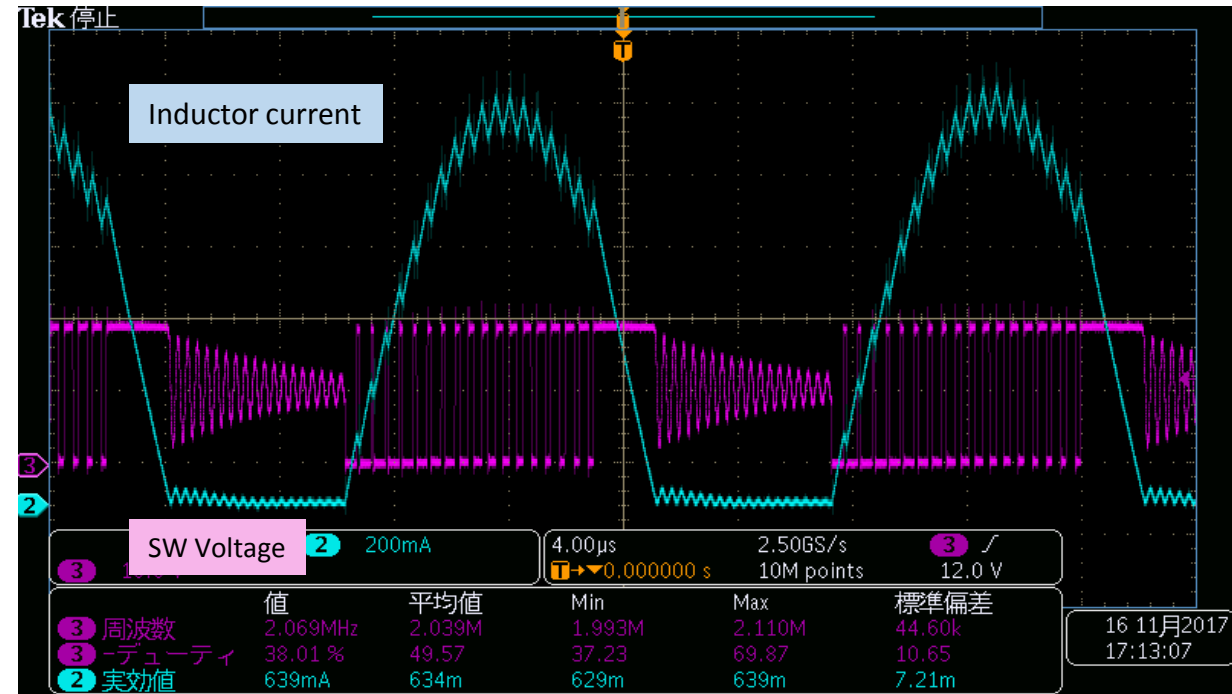


Vin=8V, Fsw=2MHz by SYNC pin




Vin=10V, Fsw=2MHz by SYNC pin

Cin=20 μ F, L=22 μ H, Cout=40 μ F+ 47pF, LED 4p6s, ILED=60mA/ch

2MHz setting by FSET pin

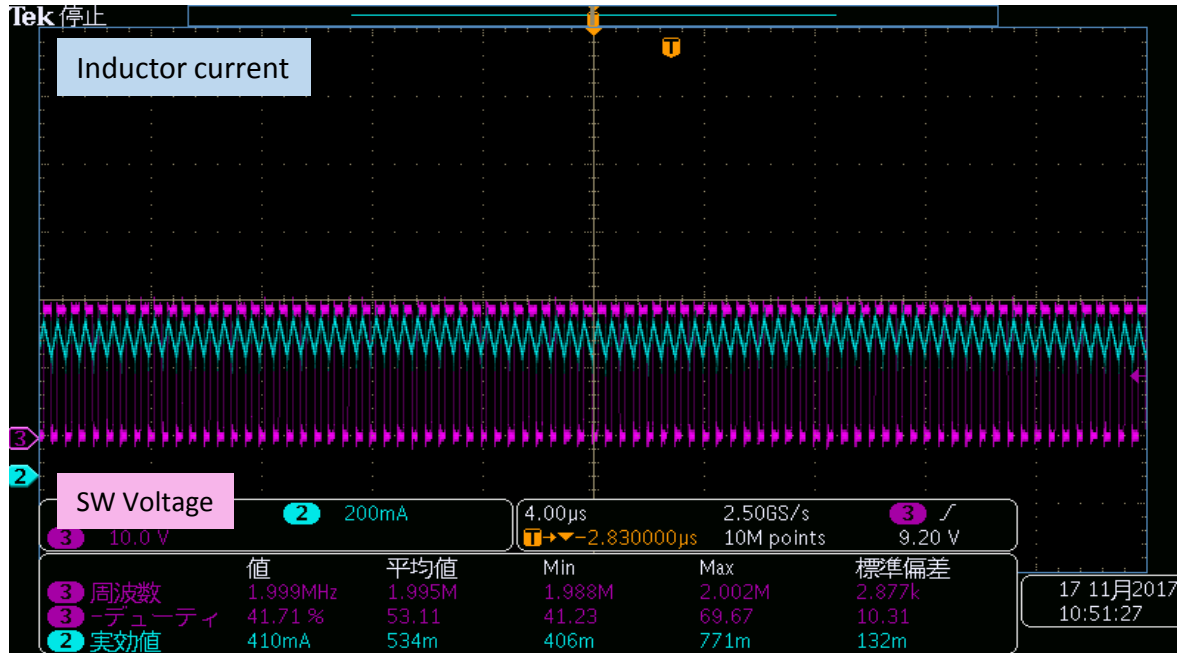

Vin=11V, Fsw=2MHz by FSET

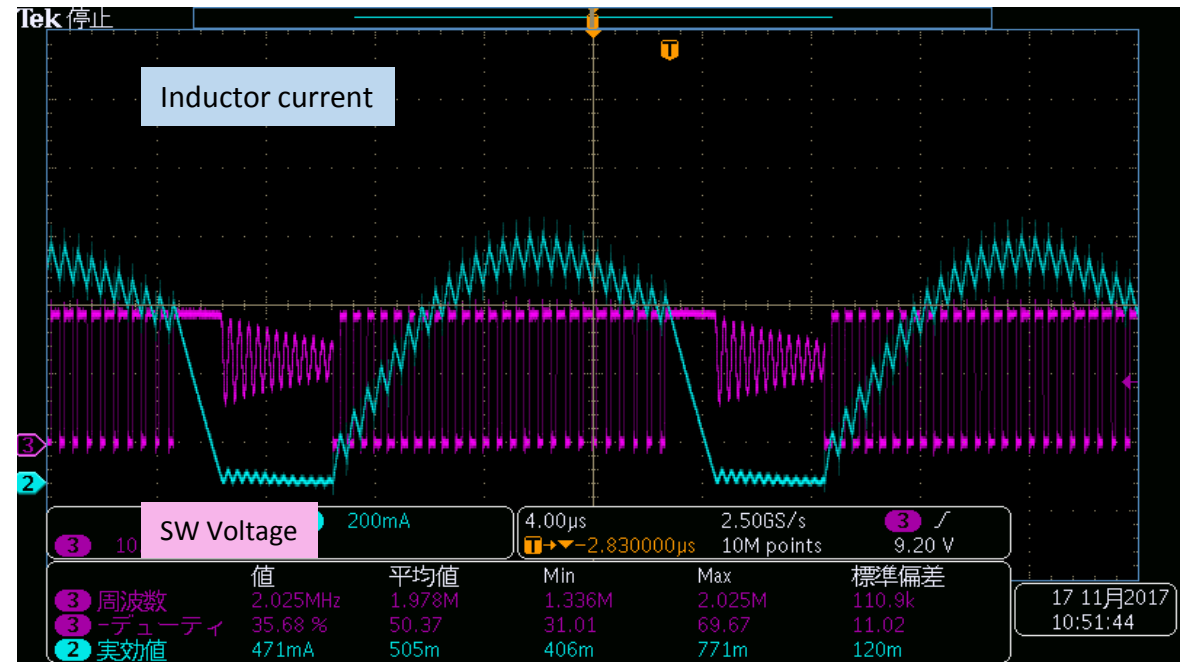

Vin=12V, Fsw=2MHz by FSET

Cin=20uF, L=22uH, Cout=40uF+ 47pF, LED 4p6s, ILED=60mA/ch