



Load Efficiency


Output Current	2.2uH /82mΩ	1.5uH /58mΩ	1.0uH /40mΩ
0.00	80.9	83.9	86.0
0.30	88.7	88.7	89.7
0.60	90.9	91.2	91.3
0.90	90.7	91.3	91.7
1.20	89.9	90.8	91.3
1.50	88.9	90.0	90.7
1.80	87.8	89.0	89.9
2.10	86.5	88.0	89.1
2.40	85.3	86.9	88.2
2.70	84.0	85.8	87.2
3.00	82.7	84.7	86.2

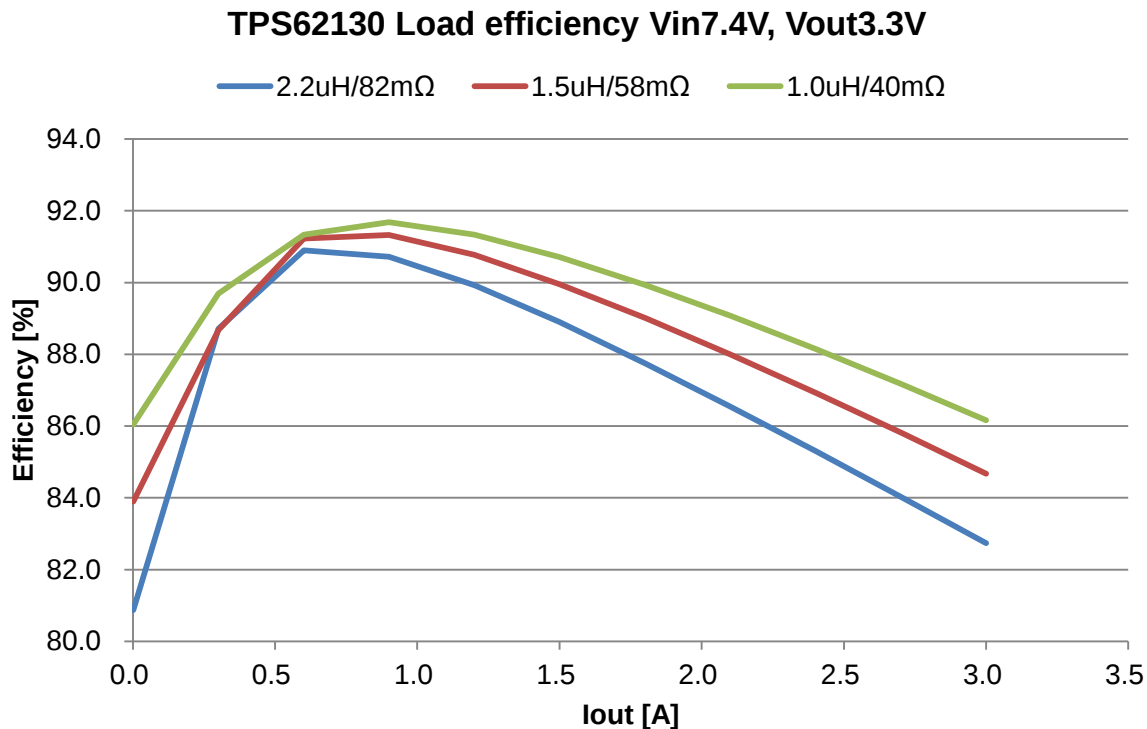


Webench Simulation model

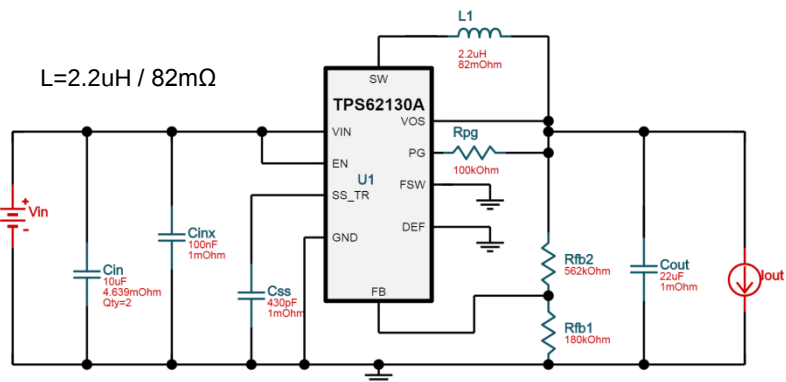

<https://webench.ti.com/appinfo/webench/scripts/SDP.cgi?ID=8B8EF4C7ABC73828>

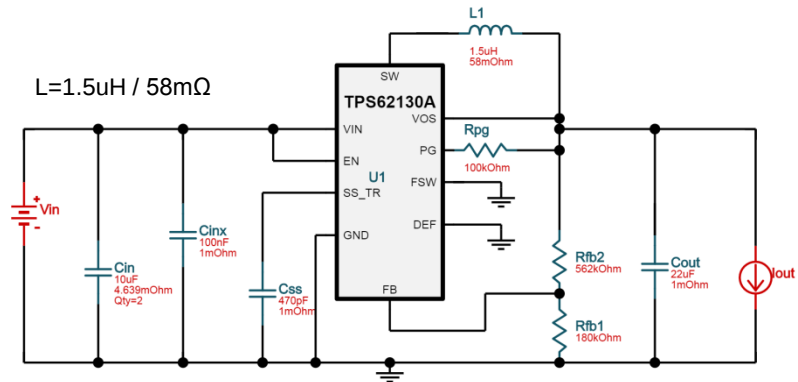

<https://webench.ti.com/appinfo/webench/scripts/SDP.cgi?ID=C1AC37B9FD6BFF48>

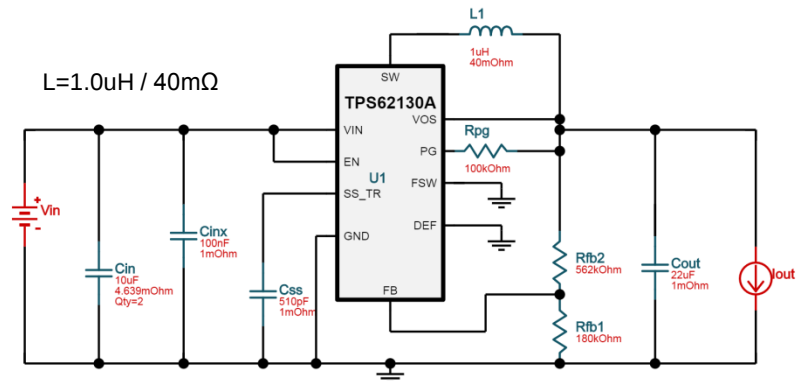

<https://webench.ti.com/appinfo/webench/scripts/SDP.cgi?ID=5484D2C77D6C501F>