

TPS7A02 AND TPS7A03

Low Load Transients Response


TI – LDO

TPS7A0218

1uF || 10uF Output Capacitor

10uA – 10mA Load

Overshoot 16.2mV
Undershoot 46mV

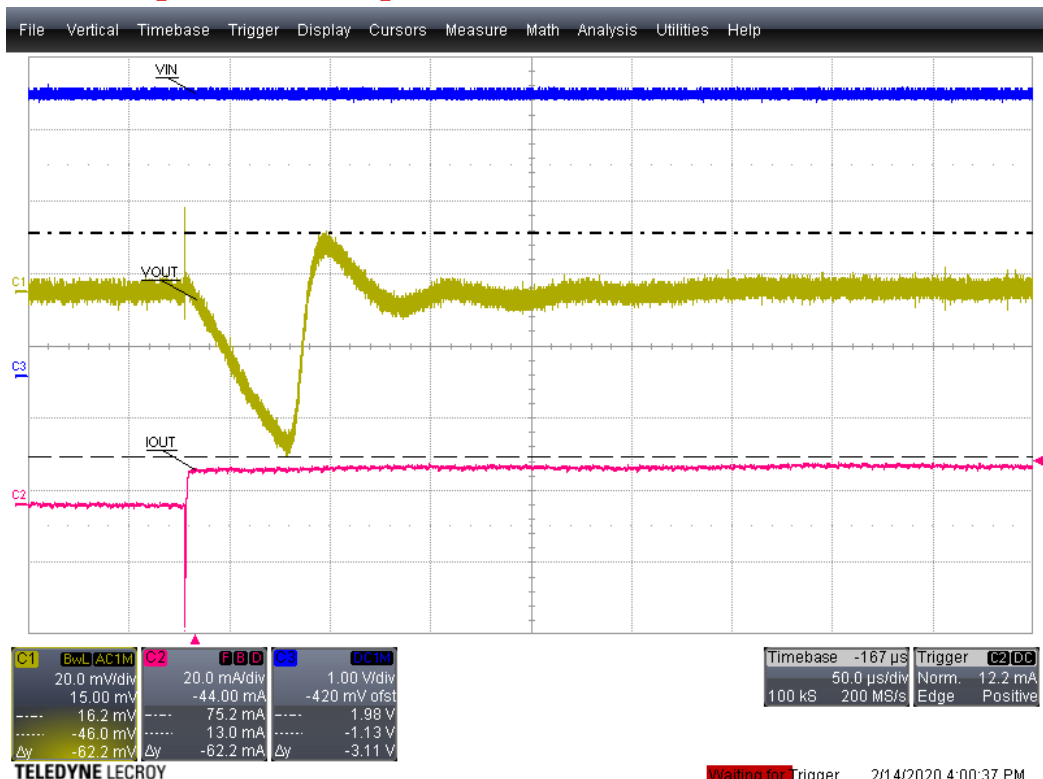

TPS7A0318

1uF || 10uF Output Capacitor

10uA – 10mA Load

Overshoot 12.8mV
Undershoot 18.4mV

