

# TPSM84A21EVM-808 0.85Vout 100uFx4+330uF





0A

3A




6A

9A





9Vin

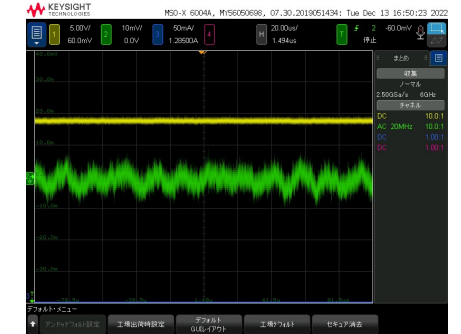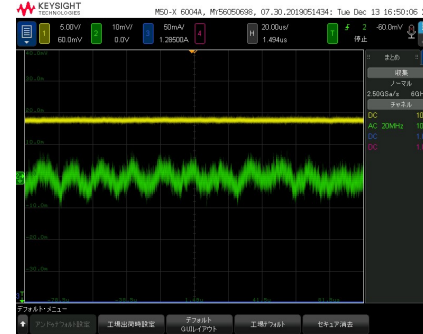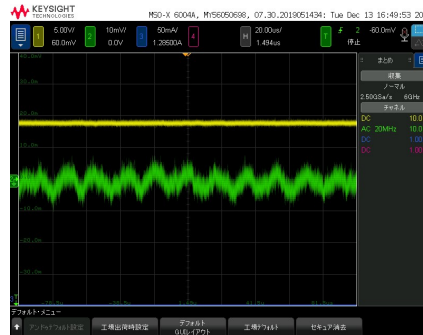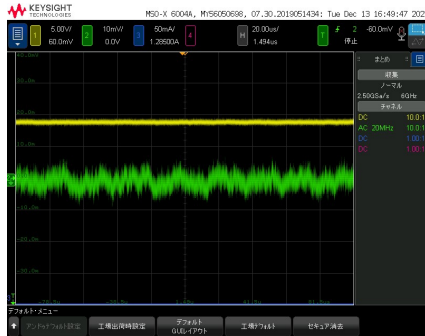

12Vin

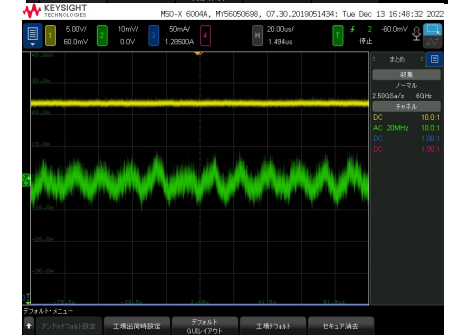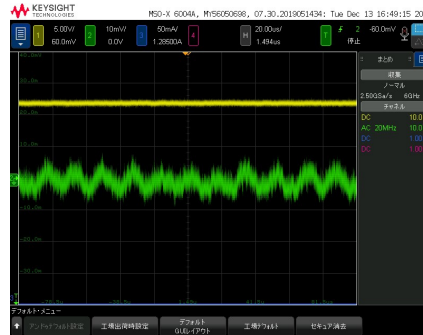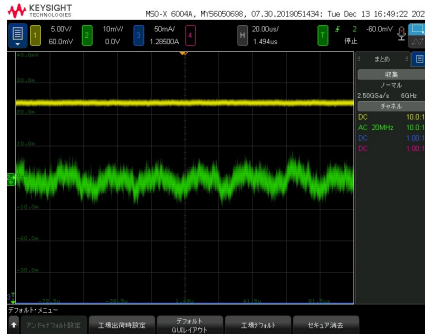

13Vin

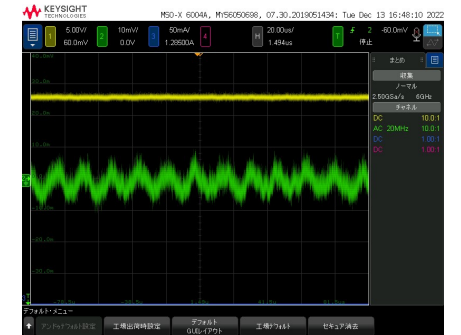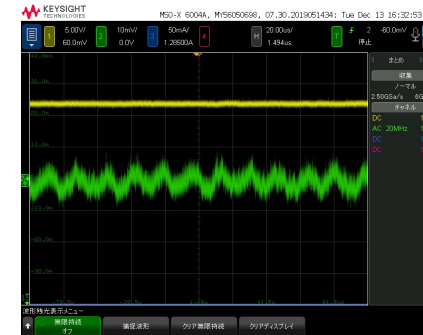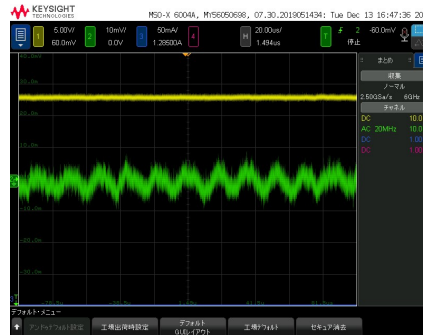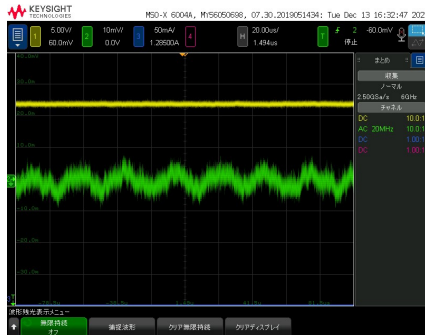

# TPSM84A21EVM-808 0.85Vout 330uF





0A

3A



6A

9A

9Vin

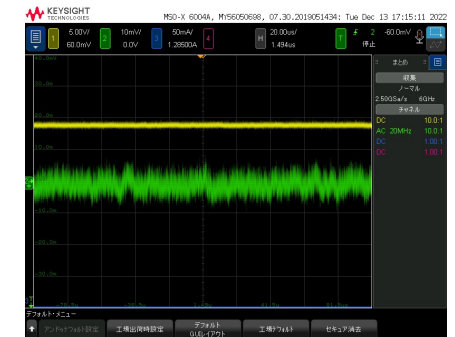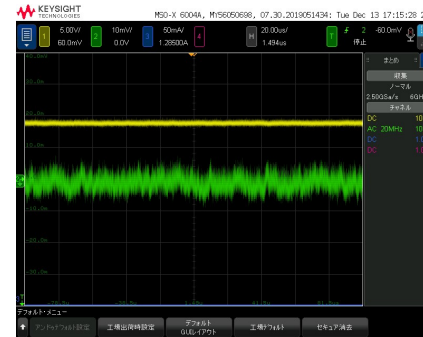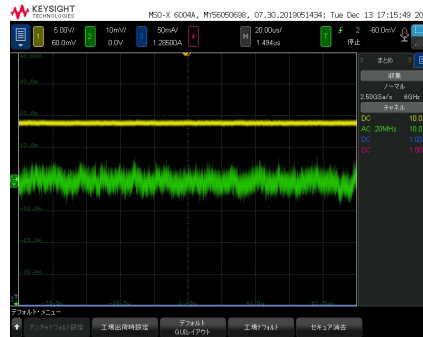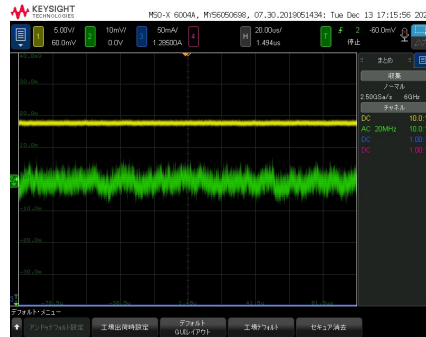

12Vin

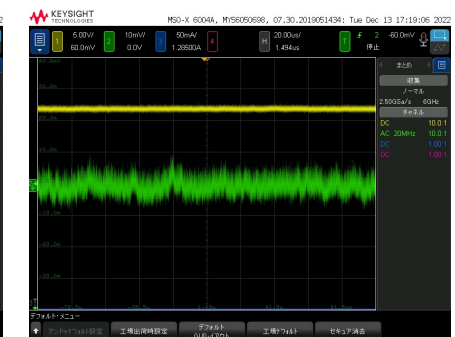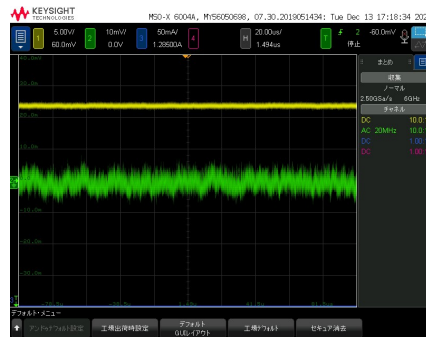

13Vin

