


UCC25630-1 EVM-291 Waveform 1s/div range

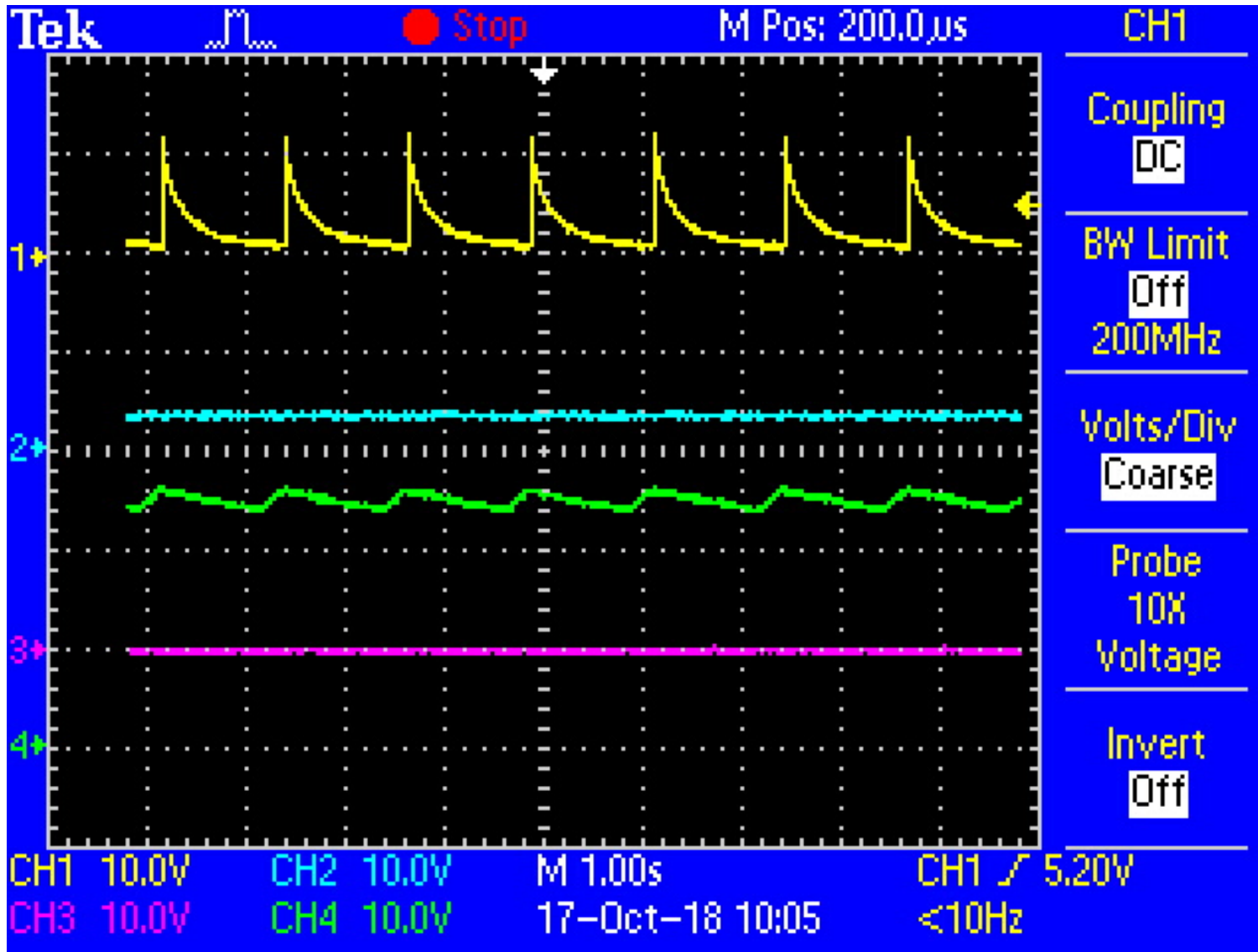

<Measurement point>

Ch1 : RVCC

Ch2 : VCR

Ch3 : ISNS

Ch4 : VCC

<Test Specification
condition>

Vin : 140Vdc


Vout : 12V dc

Iout : 0A

■ UCC25630-1 EVM-291 change schematic.

■ UCC256301 changed to UCC256304.

UCC25630-1 EVM-291 Waveform 100ms/div range

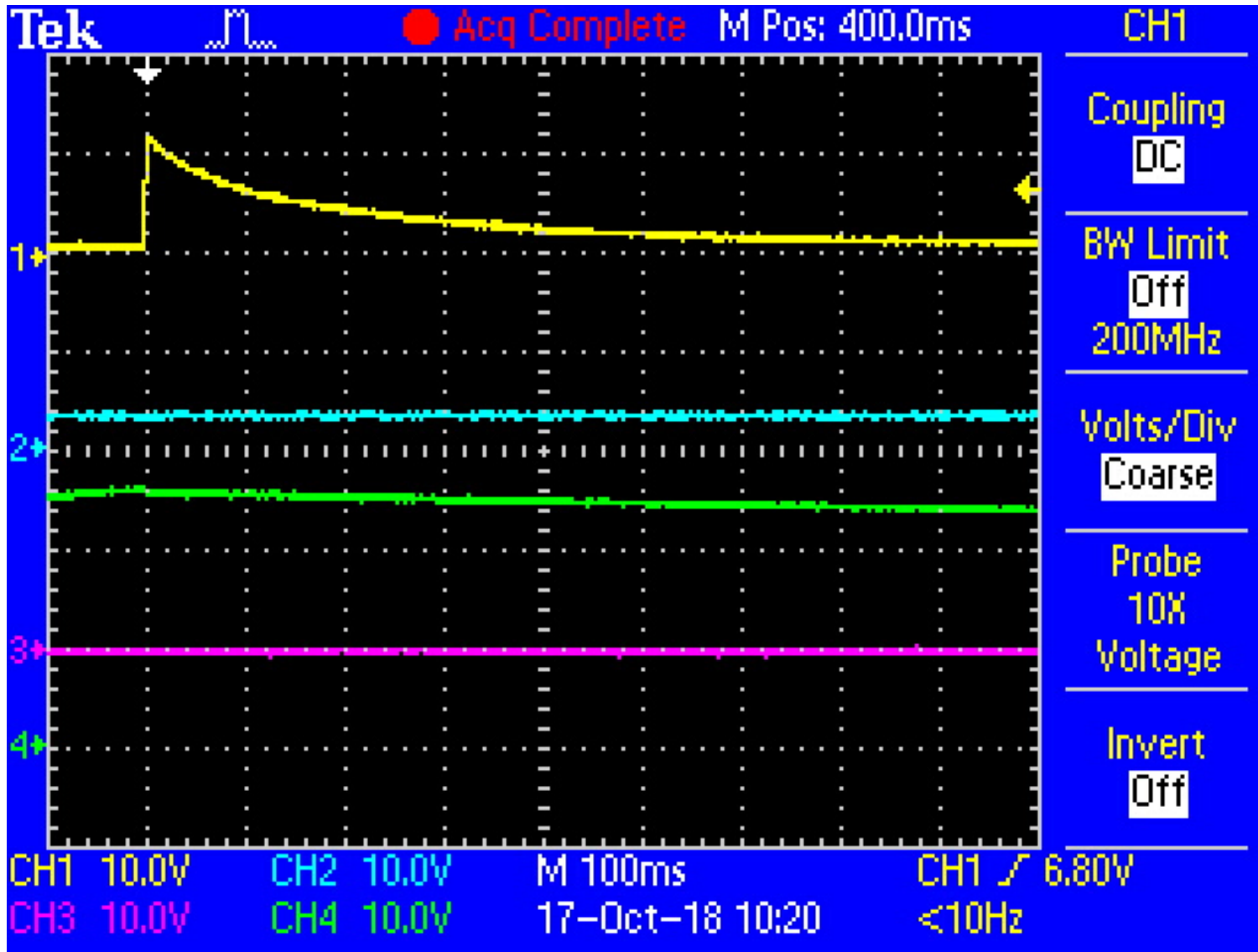

<Measurement point>

Ch1 : RVCC

Ch2 : VCR

Ch3 : ISNS

Ch4 : VCC

<Test Specification
condition>

Vin : 140Vdc

Vout : 12V dc

Iout : 0A

■ UCC25630-1 EVM-291 change schematic.

■ UCC256301 changed to UCC256304.