


Vin : 264VAC
Vo : 390V

CH1 : Vo_100V/div
CH2 : A-side FET Vds_100V/div

CH3 : B-side FET Vds_100V/div
CH4 : COMP_0.5V/div


Io : 0.25A

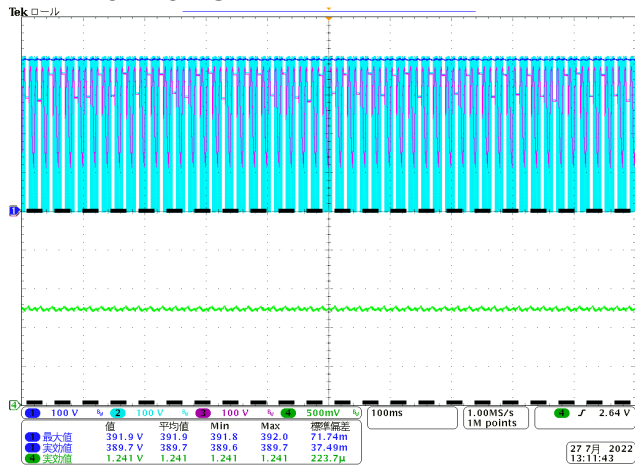

CH1~3 GND

CH4 GND


Io : 0.26A

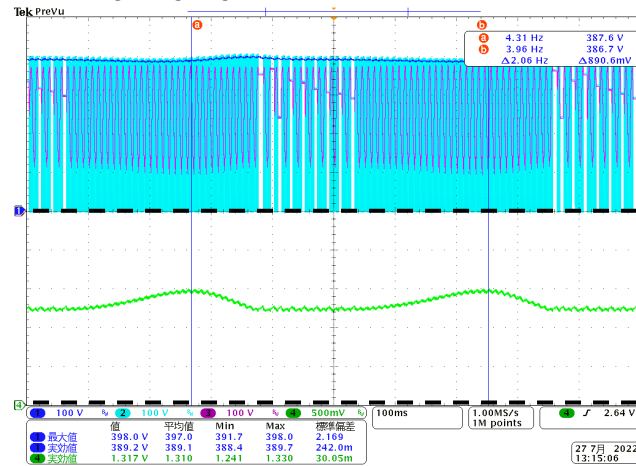

CH1~3 GND

CH4 GND


Io : 0.27A

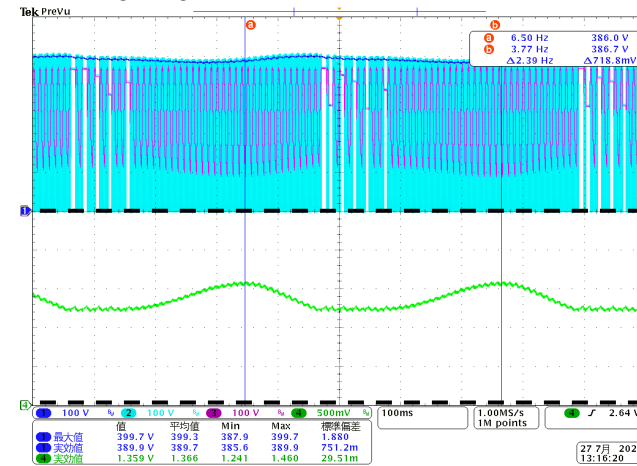

CH1~3 GND

CH4 GND


Io : 0.30A

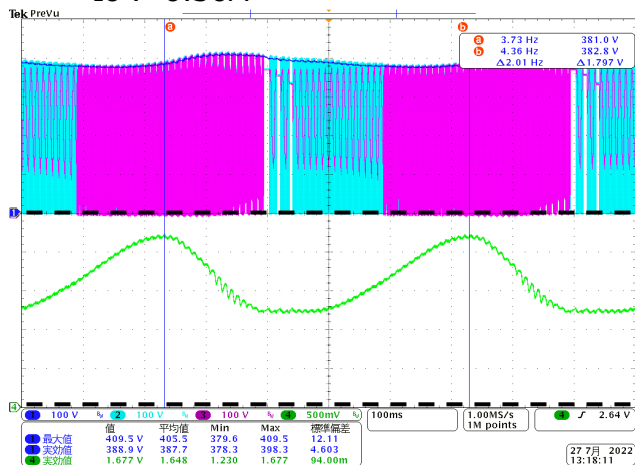

CH1~3 GND

CH4 GND


Io : 0.34A

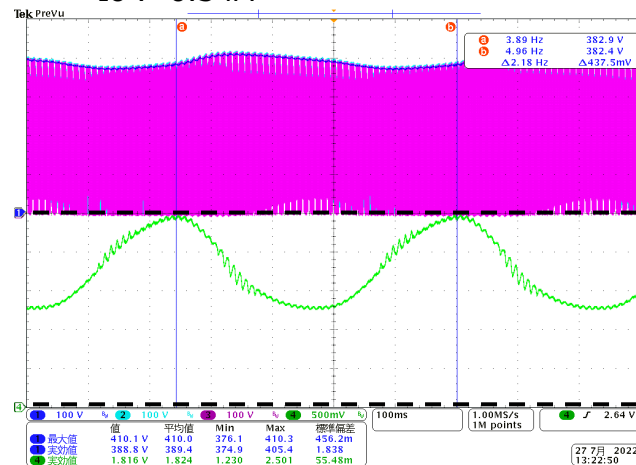

CH1~3 GND

CH4 GND


Io : 0.40A

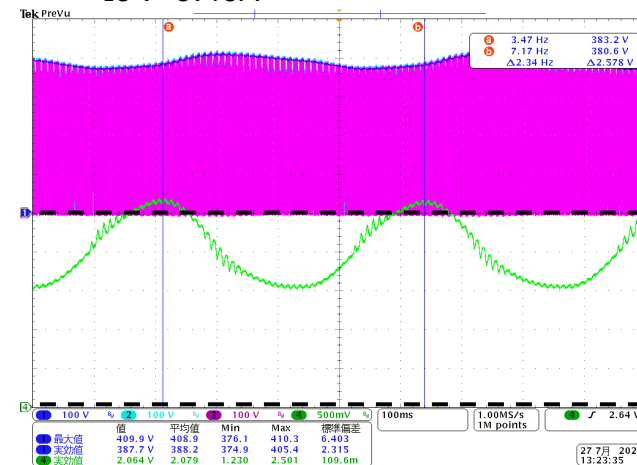

CH1~3 GND

CH4 GND


Io : 0.50A

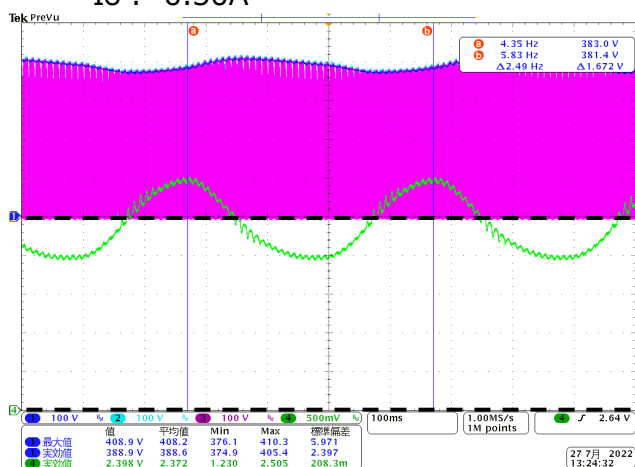

CH1~3 GND

CH4 GND


Io : 0.60A

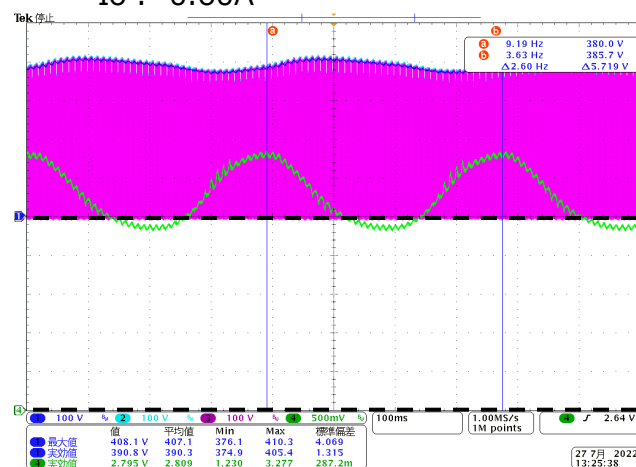

CH1~3 GND

CH4 GND

Io : 0.70A

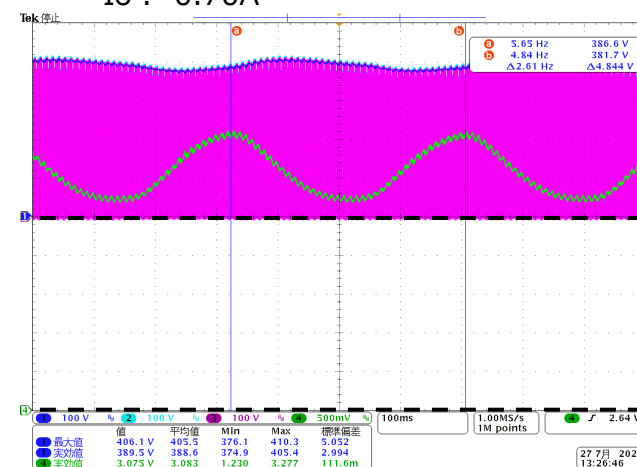

CH1~3 GND

CH4 GND