


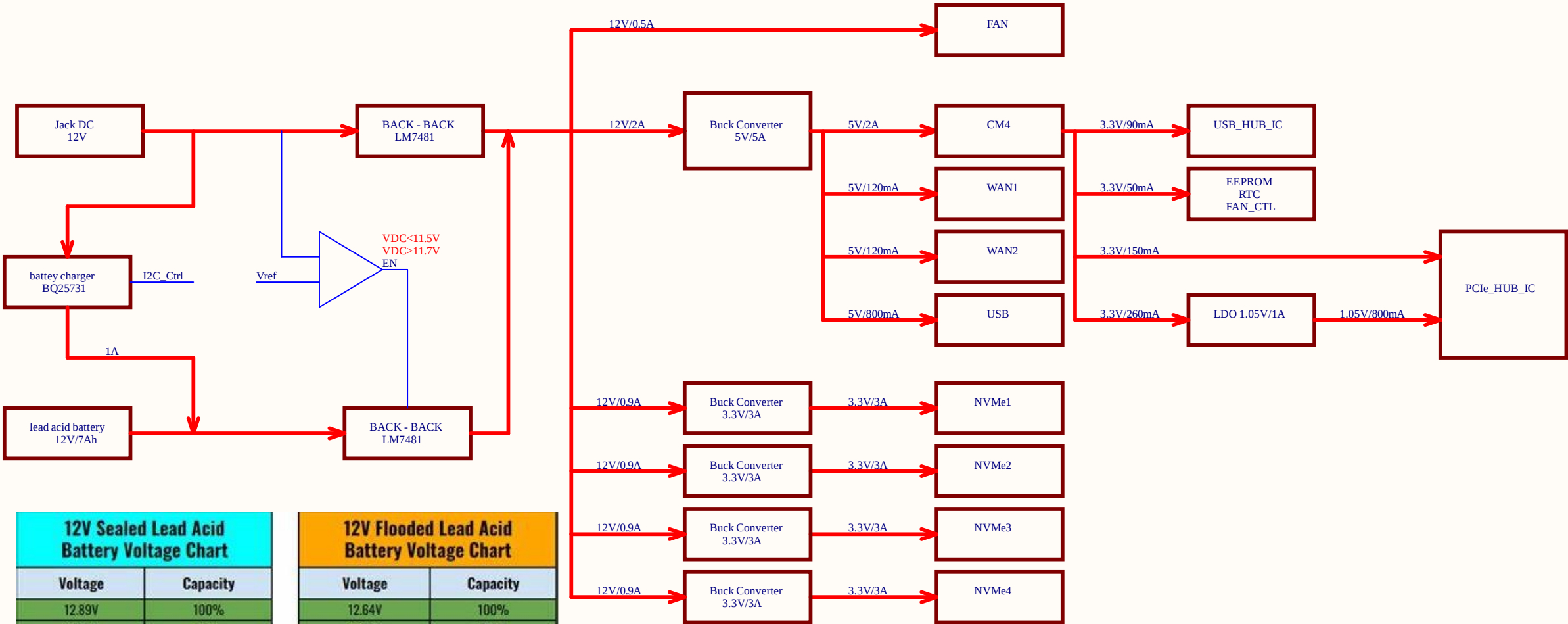

12V Sealed Lead Acid Battery Voltage Chart	
Voltage	Capacity
12.89V	100%
12.78V	90%
12.65V	80%
12.51V	70%
12.41V	60%
12.23V	50%
12.11V	40%
11.96V	30%
11.81V	20%
11.70V	10%
11.63V	0%

12V Flooded Lead Acid Battery Voltage Chart	
Voltage	Capacity
12.64V	100%
12.53V	90%
12.41V	80%
12.29V	70%
12.18V	60%
12.07V	50%
11.97V	40%
11.87V	30%
11.76V	20%
11.63V	10%
11.59V	0%

Battery capacity

Voltage

12 v

Battery capacity

7 Ah

Watt-hours

84 Wh

Runtime to full capacity

C-rate

0.9286 C

Discharge current

6.5 A

Runtime to full capacity

64.62 min

