


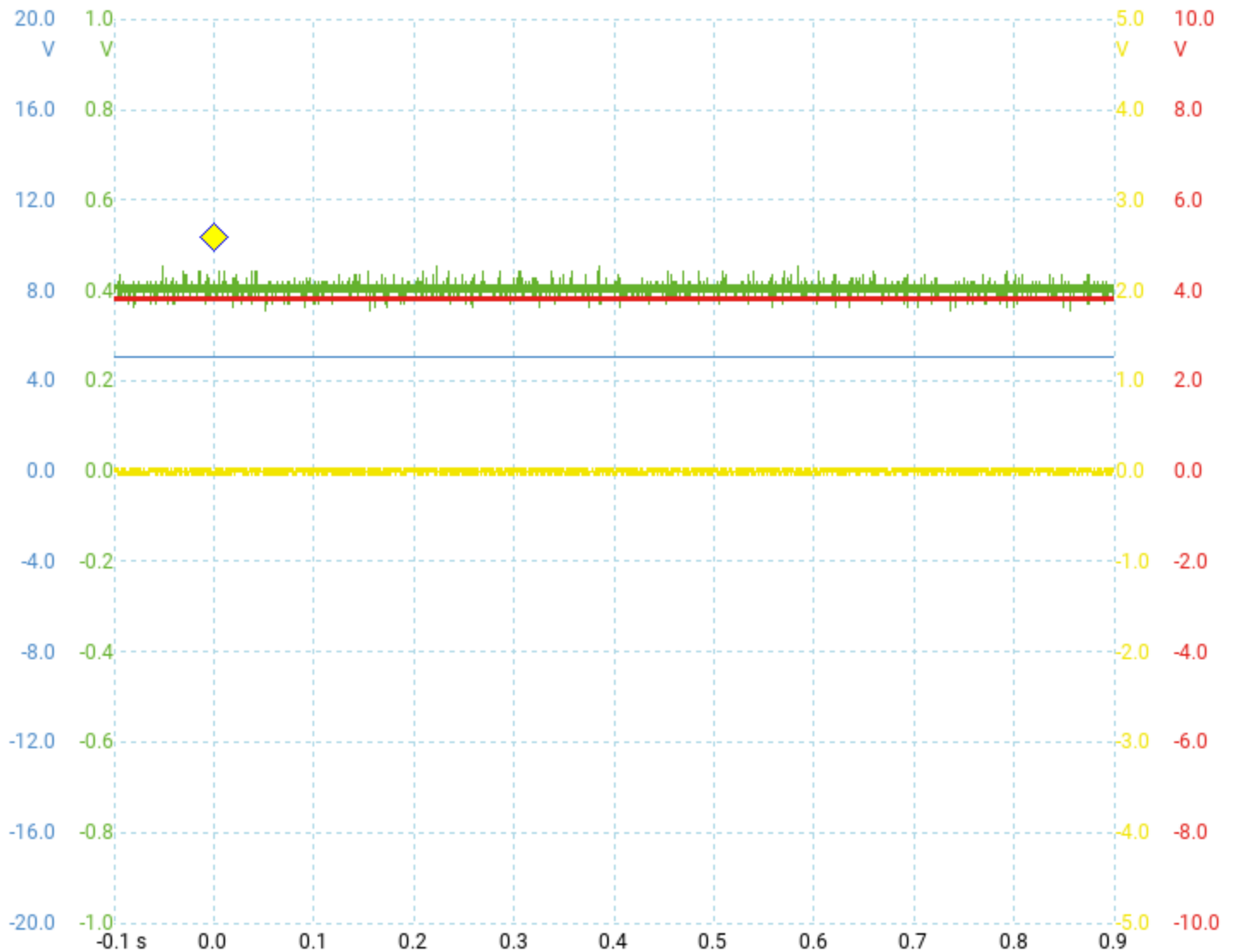

12.04.2024 13:58:25

Channel	Name	Span	Value	Min.	Max.	$\bar{x}$	σ
Vin	Mean	Whole trace	5.097 V	5.097 V	5.097 V	5.097 V	2.313 mV
Vout	Mean	Whole trace	3.84 V	2.846 V	3.848 V	3.701 V	292.6 mV
TS	Mean	Whole trace	406.2 mV	389.8 mV	424.1 mV	415.1 mV	9.703 mV
nCHG	Mean	Whole trace	256.5 μ V	100.8 μ V	1.474 mV	653.7 μ V	267.8 μ V