


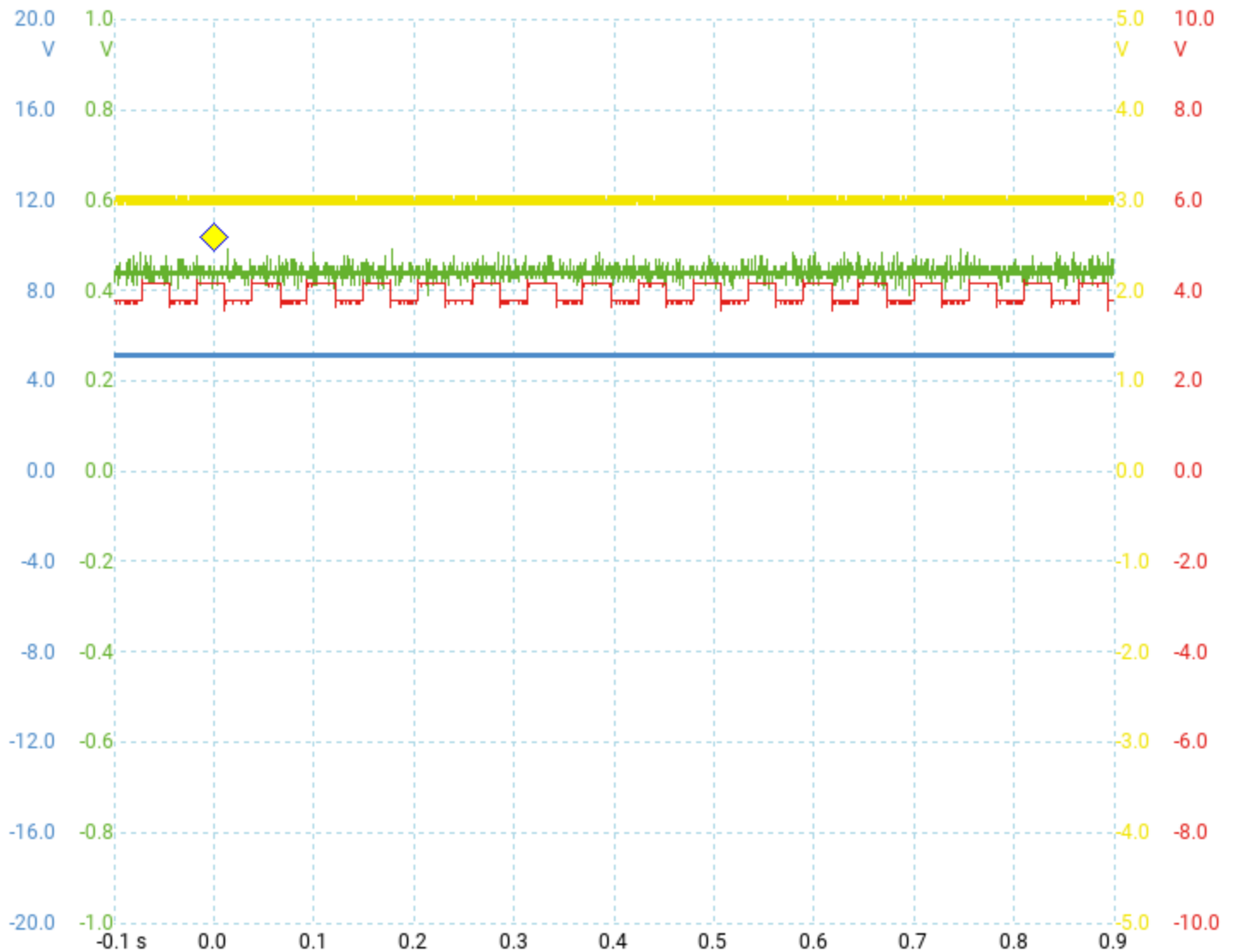

12.04.2024 13:59:25

Channel	Name	Span	Value	Min.	Max.	$\bar{x}$	σ
Vin	Mean	Whole trace	5.113 V	5.113 V	5.114 V	5.113 V	0 V
Vout	Mean	Whole trace	3.991 V	3.991 V	3.994 V	3.992 V	1.588 mV
TS	Mean	Whole trace	443.2 mV	426.7 mV	443.2 mV	436.7 mV	5.519 mV
nCHG	Mean	Whole trace	3.007 V	3.007 V	3.008 V	3.007 V	403.3 μ V