


Waveform of SW1, SW2, Vout, Inductor Current

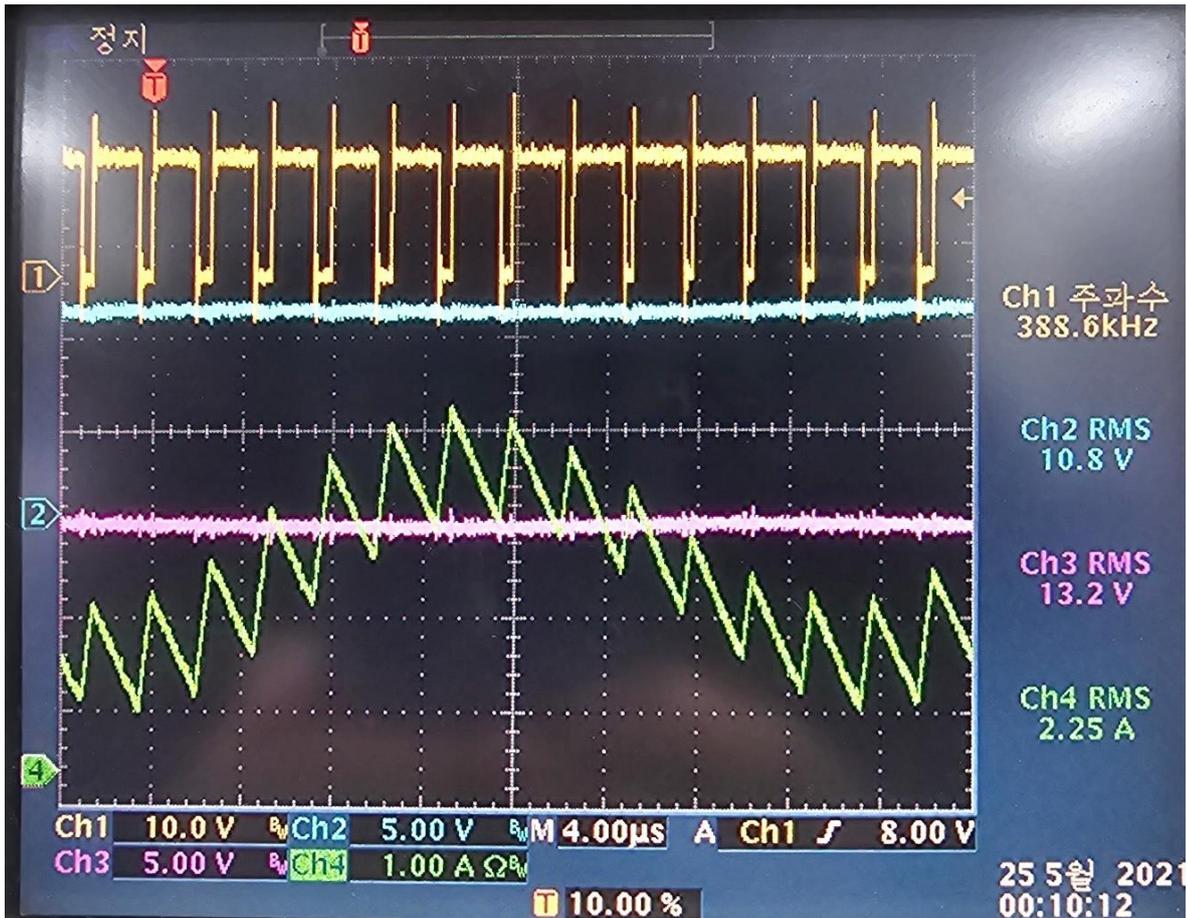

- CH1 SW1
- CH2 SW2
- CH3 Vout
- CH4 Inductor Current

- R17 10 kohm
- C25 10 nF
- C26 10 pF
- L 4.7 uH
- Fsw 400 kHz

