



Waveform of SW1, SW2, Vout, Inductor Current

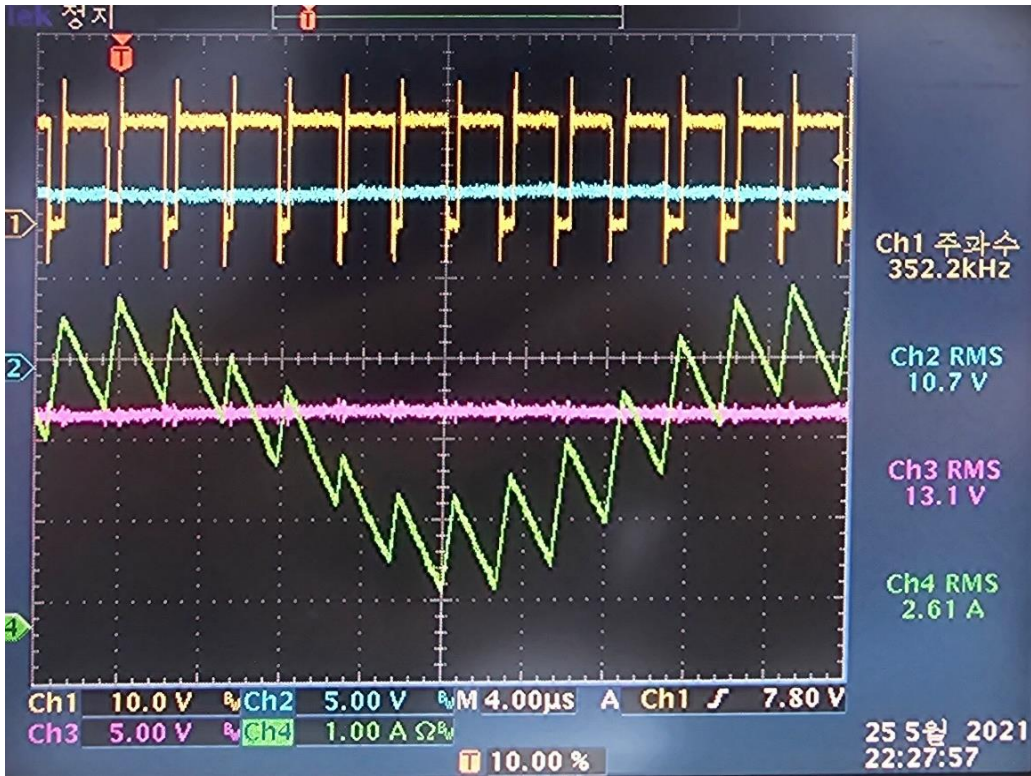

R17=5.1kohm, C25=10pF, C26=10nF, L=4.7uH, Fsw=400kHz

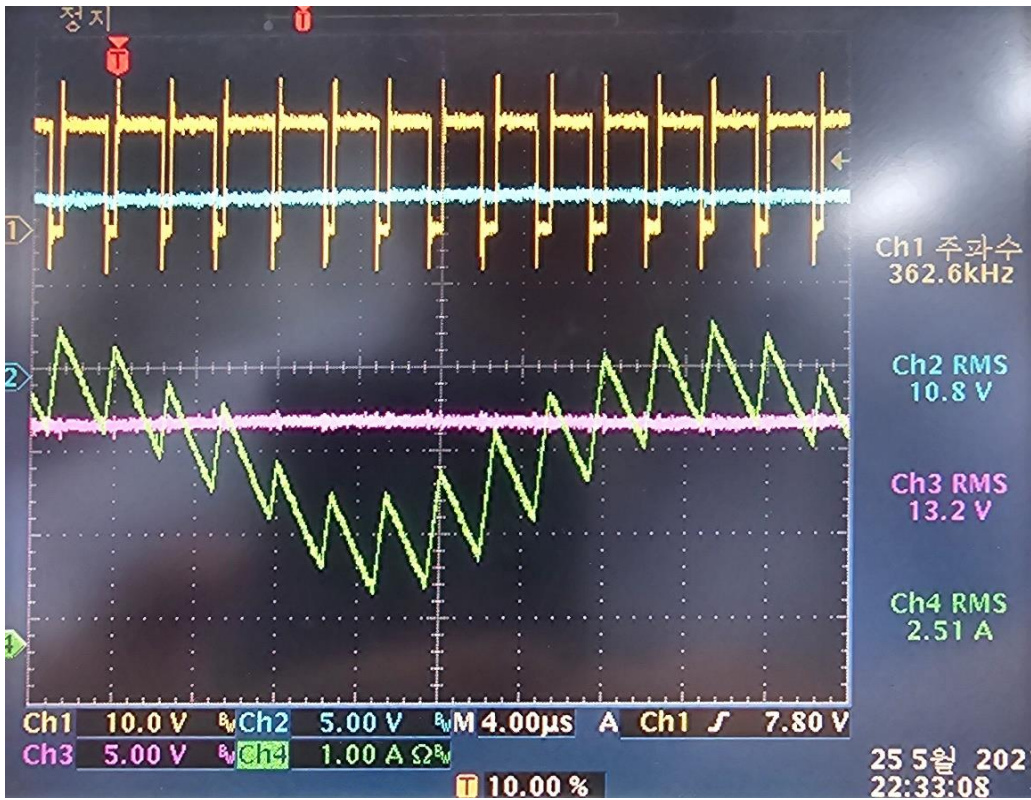

R17=5.1kohm, C25=10pF, C26=1uF, L=4.7uH, Fsw=400kHz