


JULUEN

Conducted Emissions Test Report

Device under Test HEF1(RED+YELLOW)
 Operating Condition +27V
 Operator Name Andrew
 Test Specification CISPR 25 CE test _PK_AV_voltage(+)
 PCB Version <click here and enter additional information>
 Note

Pre-measurement Graph

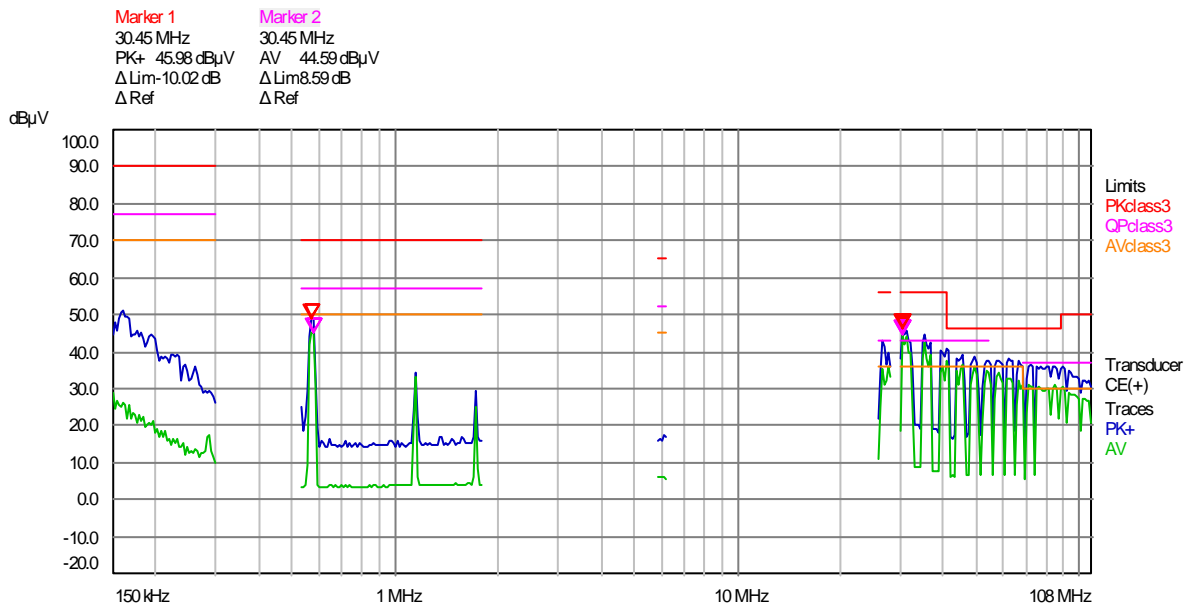

Peak Search Results

Trace	Frequency (MHz)	Level (dBµV)	Limit (dBµV)	Delta Limit (dB)	Delta Ref (dB)	Comment
1 PK+	0.573	48.90	70.00	-21.10		
2 AV	0.575	44.99	50.00	-5.01		
1 PK+	30.45	45.98	56.00	-10.02		
2 AV	30.45	44.59 *	36.00	8.59		

* = limit exceeded