


JULUEN

Conducted Emissions Test Report

Device under Test HEF1(RED+YELLOW)
 Operating Condition -13.5V
 Operator Name Andrew
 Test Specification CISPR 25 CE test _PK_AV_voltage(-)
 PCB Version <click here and enter additional information>
 Note

Pre-measurement Graph

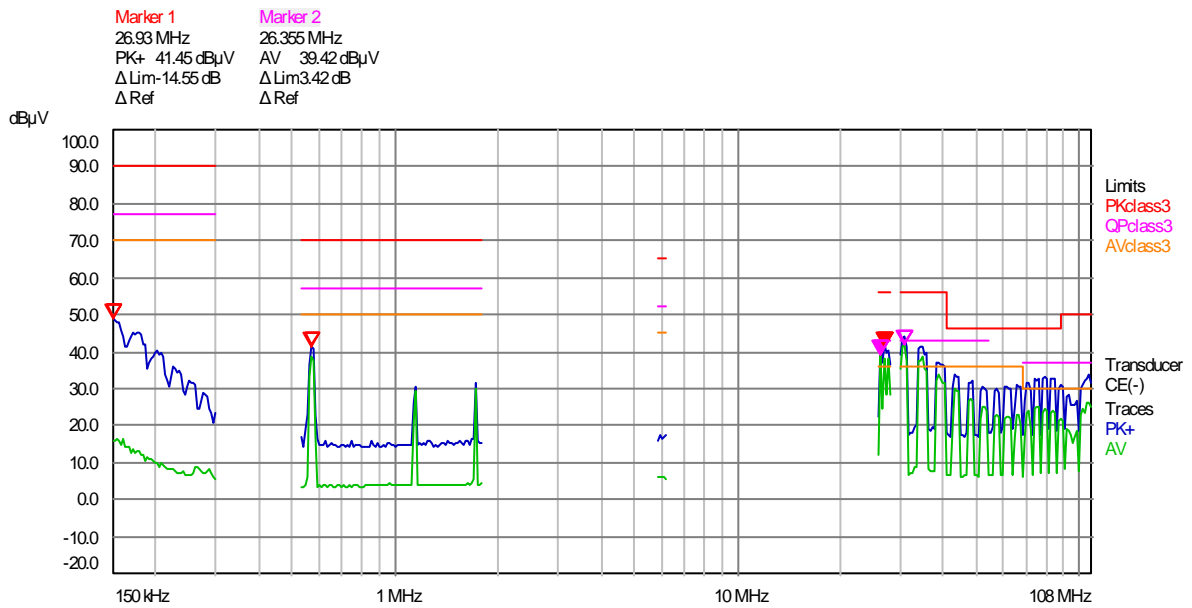

Peak Search Results

Trace	Frequency (MHz)	Level (dBµV)	Limit (dBµV)	Delta Limit (dB)	Delta Ref (dB)	Comment
1 PK+	0.151	48.80	90.00	-41.20		
1 PK+	0.572	41.25	70.00	-28.75		
2 AV	26.355	39.42 *	36.00	3.42		
1 PK+	26.93	41.45	56.00	-14.55		
2 AV	30.95	42.02 *	36.00	6.02		

* = limit exceeded