


JULUEN

Conducted Emissions Test Report

Device under Test HEF1(RED+YELLOW)
 Operating Condition -27V
 Operator Name Andrew
 Test Specification CISPR 25 CE test _PK_AV_voltage(-)
 PCB Version <click here and enter additional information>
 Note

Pre-measurement Graph

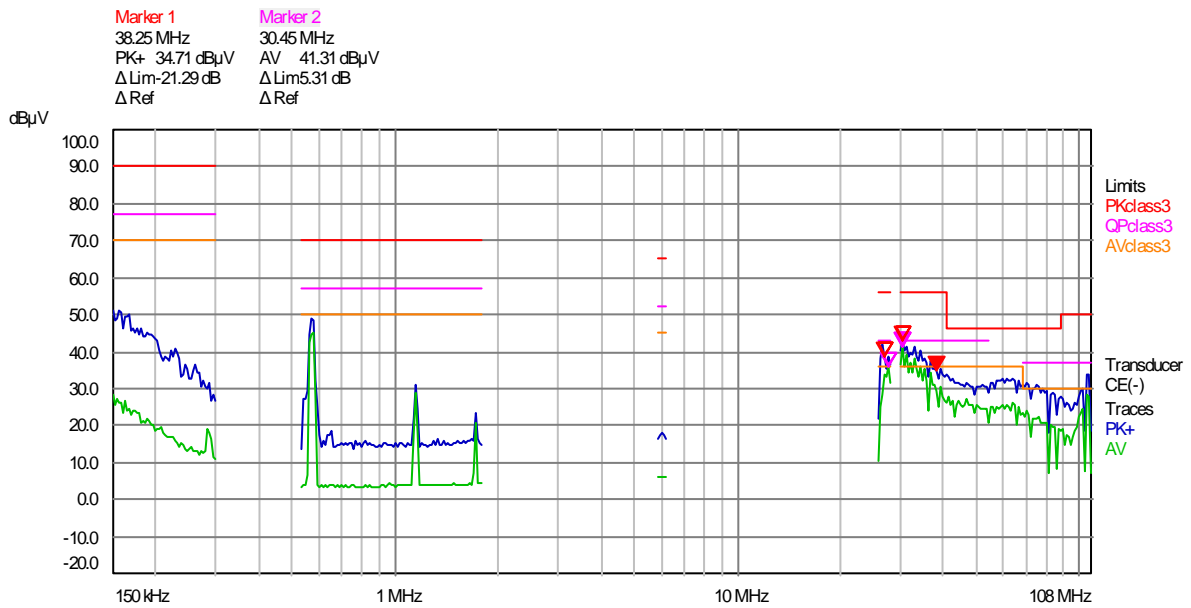

Peak Search Results

Trace	Frequency (MHz)	Level (dBµV)	Limit (dBµV)	Delta Limit (dB)	Delta Ref (dB)	Comment
1 PK+	27.035	38.85	56.00	-17.15		
2 AV	27.595	36.01 *	36.00	0.01		
1 PK+	30.45	43.23	56.00	-12.77		
2 AV	30.45	41.31 *	36.00	5.31		

* = limit exceeded