



RADIATED EMISSION

Date 2019-06-24

Order No.
Power Supply
Temp/Humi
Test Condition

Memo 일반동작모드 시거잭 갈색 9 V

LIMIT : 32 Class B (10m)
MARGIN: 3 dB

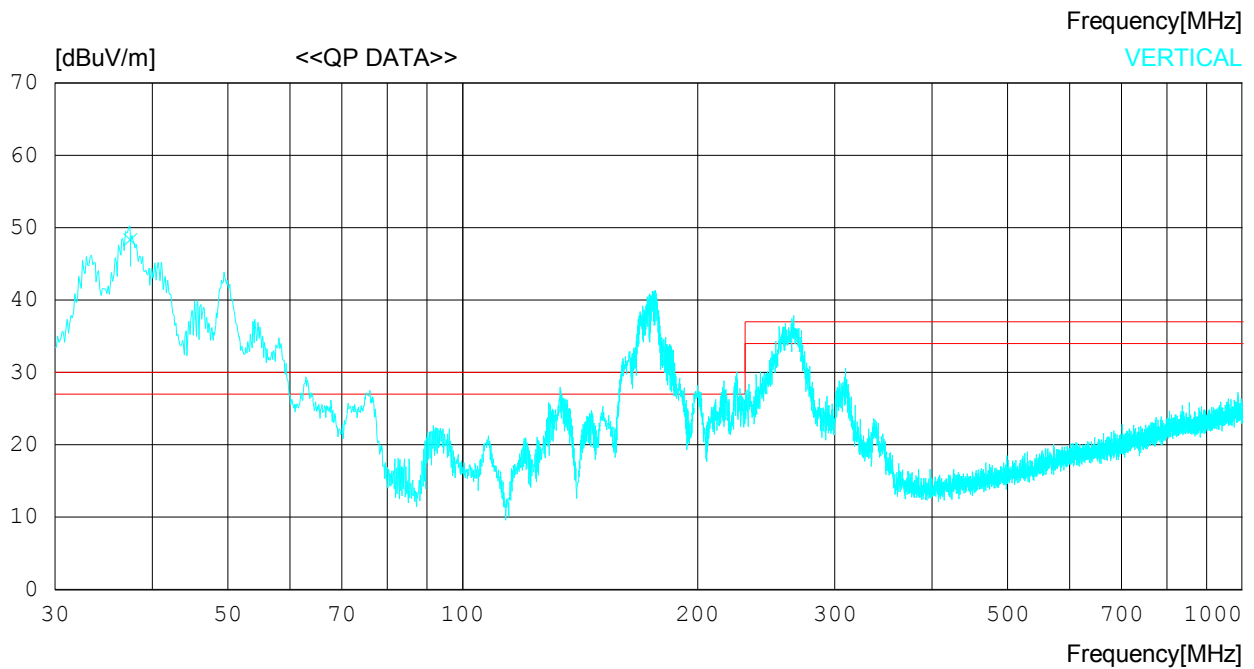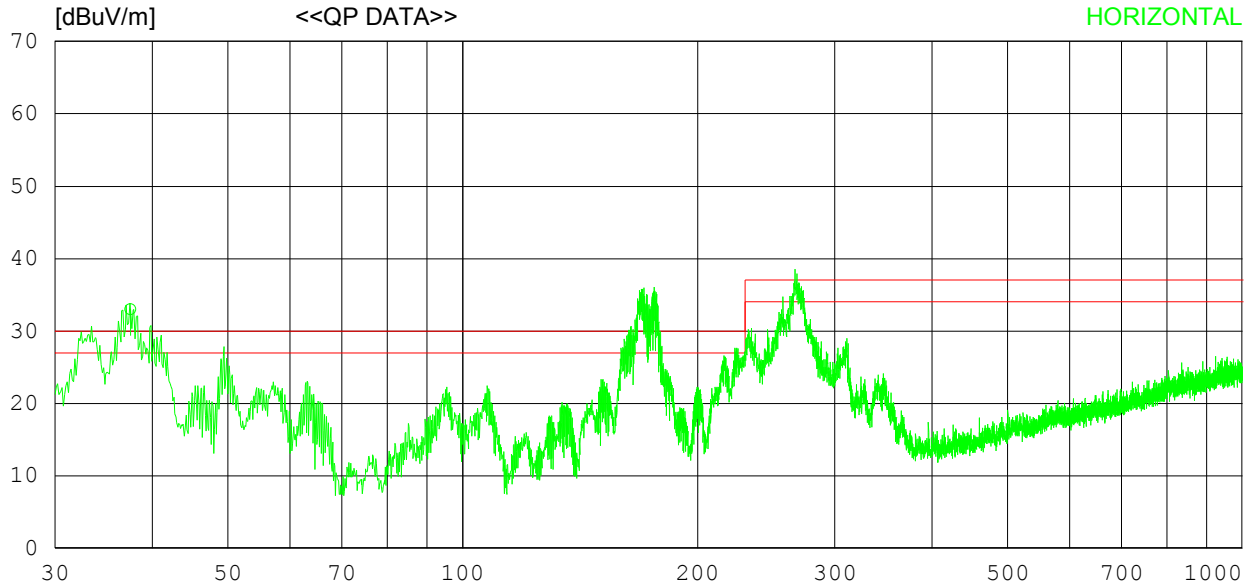

RADIATED EMISSION

Date 2019-06-24

Order No.
Power Supply
Temp/Humi
Test Condition

Memo 일반동작모드 시거잭 갈색 9 V

LIMIT : 32 Class B (10m)
MARGIN: 3 dB

No.	FREQ [MHz]	READING QP [dBuV]	ANT FACTOR [dB]	LOSS [dB]	GAIN [dB]	RESULT [dBuV/m]	LIMIT [dBuV/m]	MARGIN [dB]	ANTENNA [cm]	TABLE [DEG]
----- Horizontal -----										
1	37.484	51.10	11.08	0.88	30.05	33.01	30.00	-3.01	301	158
----- Vertical -----										
2	37.483	66.40	11.08	0.88	30.05	48.31	30.00	-18.31	103	167