



Radiated Emission

DSTech
Date : 2023-08-25 15:12:05

Order No.	:	Supplied Power	:
Temp/Humidity	:	Operator	:
Test Condition	:		:

Memo :

LIMIT : 3m CLASS B
MARGIN: 3 dB

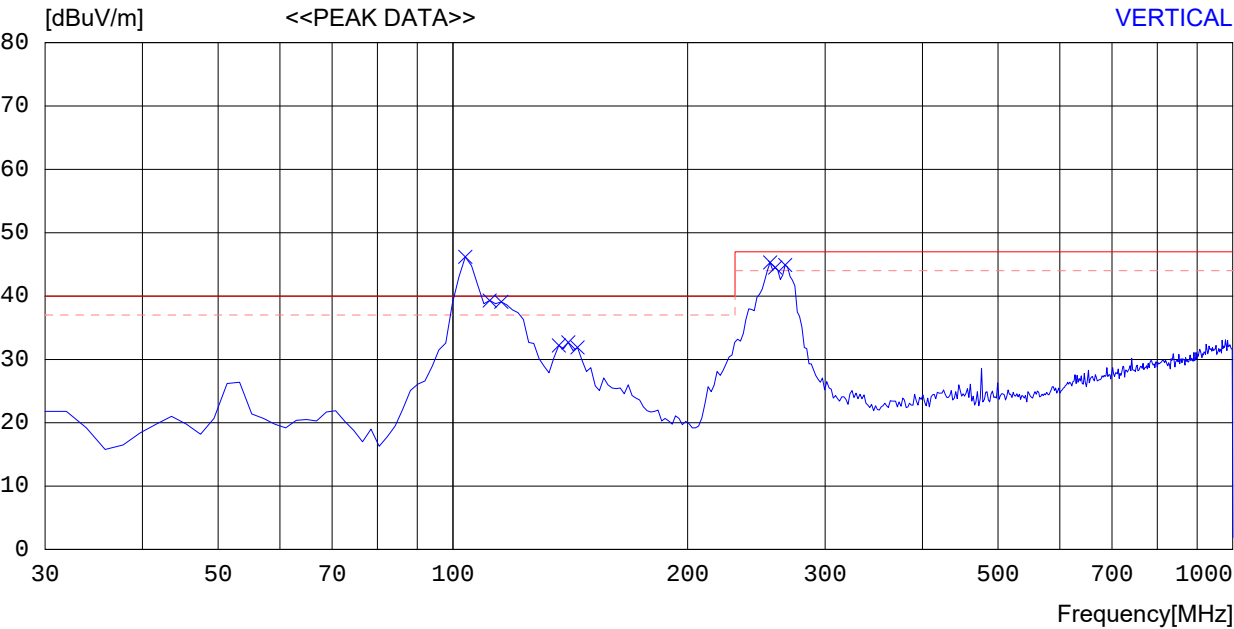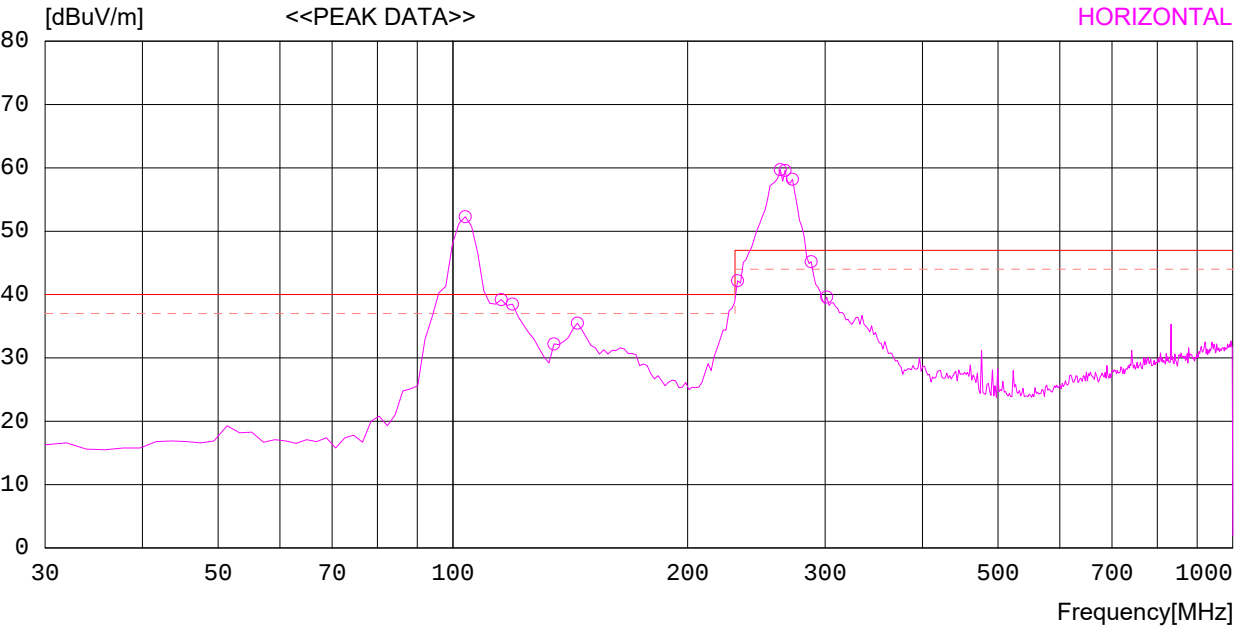

Radiated Emission

DSTech

Date : 2023-08-25 15:12:05

Order No. :
Temp/Humidity :
Test Condition :
Memo :
Supplied Power :
Operator :

LIMIT : 3m CLASS B
MARGIN: 3 dB

No.	FREQ [MHz]	READING PEAK [dBuV]	ANT FACTOR [dB]	LOSS [dB]	GAIN [dB]	RESULT [dBuV/m]	LIMIT [dBuV/m]	MARGIN [dB]	ANTENNA [cm]	TABLE [DEG]
----- Horizontal -----										
1	103.720	67.5	9.4	1.4	26.0	52.3	40.0	-12.3	195	127
2	115.360	53.6	10.1	1.4	25.9	39.2	40.0	.8	195	306
3	119.240	52.5	10.4	1.5	25.9	38.5	40.0	1.5	195	306
4	134.760	44.3	12.3	1.5	25.9	32.2	40.0	7.8	195	359
5	144.460	46.5	13.2	1.6	25.8	35.5	40.0	4.5	195	359
6	231.760	55.4	10.4	2.0	25.6	42.2	47.0	4.8	195	359
7	262.800	70.7	12.3	2.2	25.5	59.7	47.0	-12.7	100	0
8	266.680	70.4	12.5	2.2	25.5	59.6	47.0	-12.6	100	81
9	272.500	68.7	12.8	2.2	25.5	58.2	47.0	-11.2	100	0
10	288.020	55.1	13.2	2.3	25.4	45.2	47.0	1.8	100	242
11	301.600	49.2	13.5	2.3	25.4	39.6	47.0	7.4	100	0
----- Vertical -----										
12	103.720	61.4	9.4	1.4	26.0	46.2	40.0	-6.2	100	60
13	111.480	53.6	10.2	1.4	25.9	39.3	40.0	.7	100	99
14	115.360	53.5	10.1	1.4	25.9	39.1	40.0	.9	195	94
15	136.700	44.0	12.5	1.6	25.9	32.2	40.0	7.8	100	359
16	140.580	44.2	12.8	1.6	25.9	32.7	40.0	7.3	100	359
17	144.460	42.9	13.2	1.6	25.8	31.9	40.0	8.1	100	4
18	255.040	56.7	12.0	2.1	25.5	45.3	47.0	1.7	100	236
19	258.920	55.7	12.1	2.2	25.5	44.5	47.0	2.5	100	250
20	266.680	55.7	12.5	2.2	25.5	44.9	47.0	2.1	100	60