


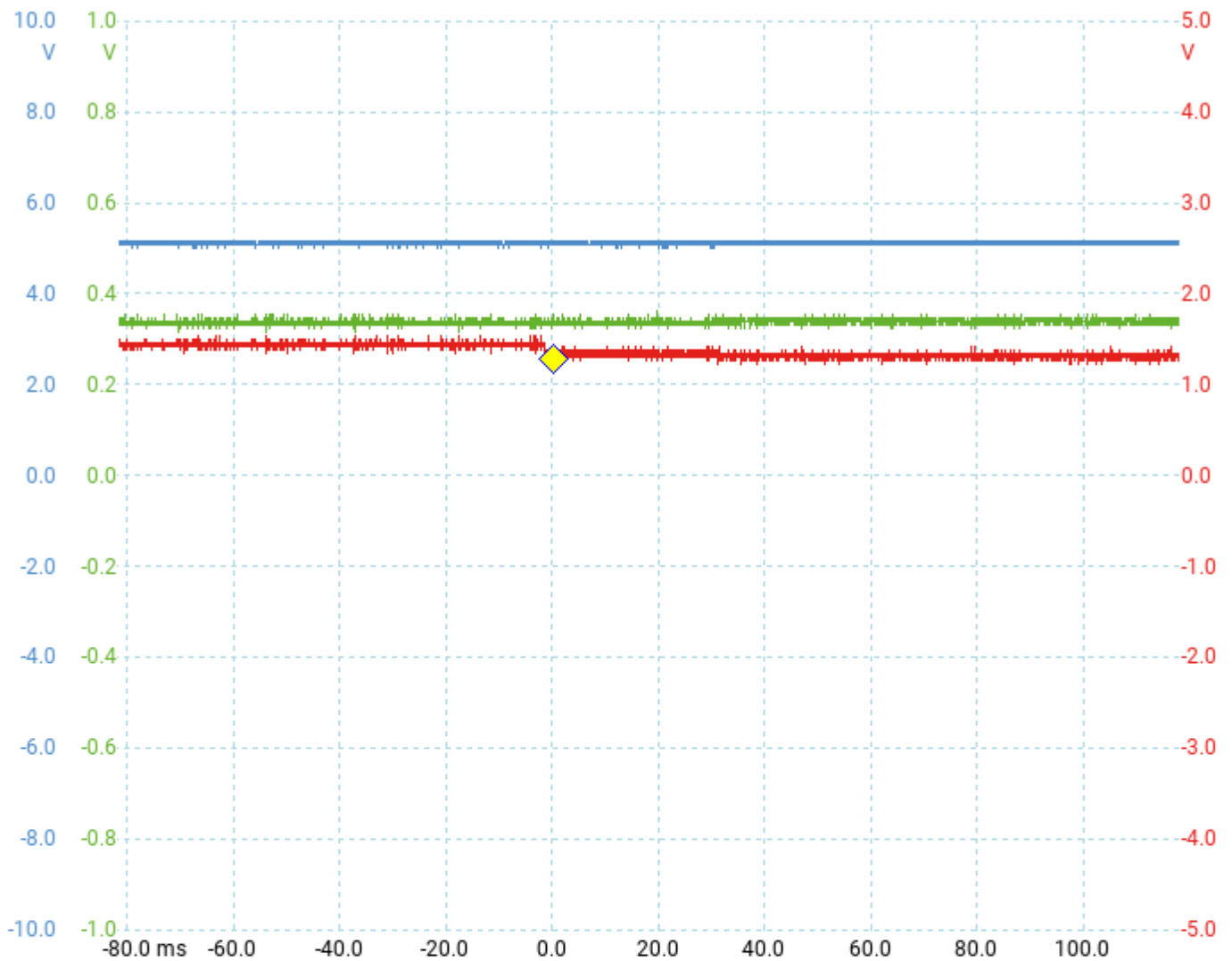

Channel	Name	Span	Value	Min.	Max.	$\bar{x}$	σ
A	Mean	Whole trace	5.121 V	5.121 V	5.121 V	5.121 V	0 V
B	Mean	Whole trace	1.371 V	1.371 V	1.371 V	1.371 V	0 V
C	Mean	Whole trace	342 mV	342 mV	342 mV	342 mV	0 V
D	Mean	Whole trace	175.9 μ V	175.9 μ V	175.9 μ V	175.9 μ V	36.48 nV