



Radiated Emission

DSTech
Date : 2023-10-13 10:46:53

Order No.	:	Supplied Power	:
Temp/Humidity	:	Operator	:
Test Condition	:		:

Memo :

LIMIT : 3m CLASS B
MARGIN: 3 dB

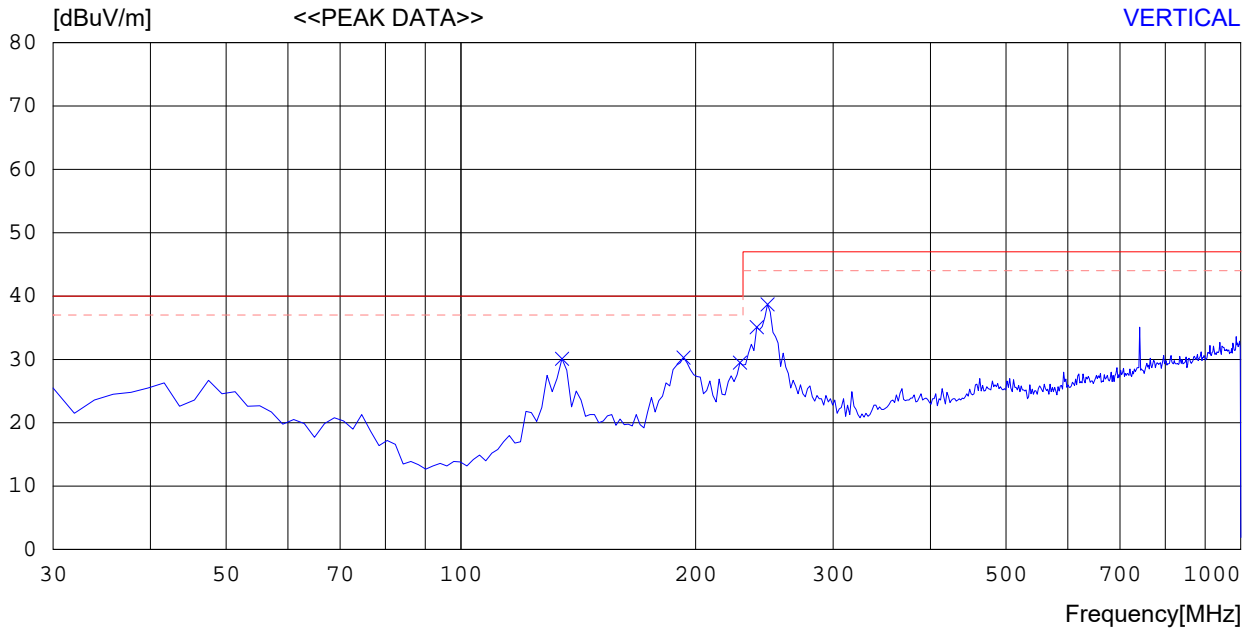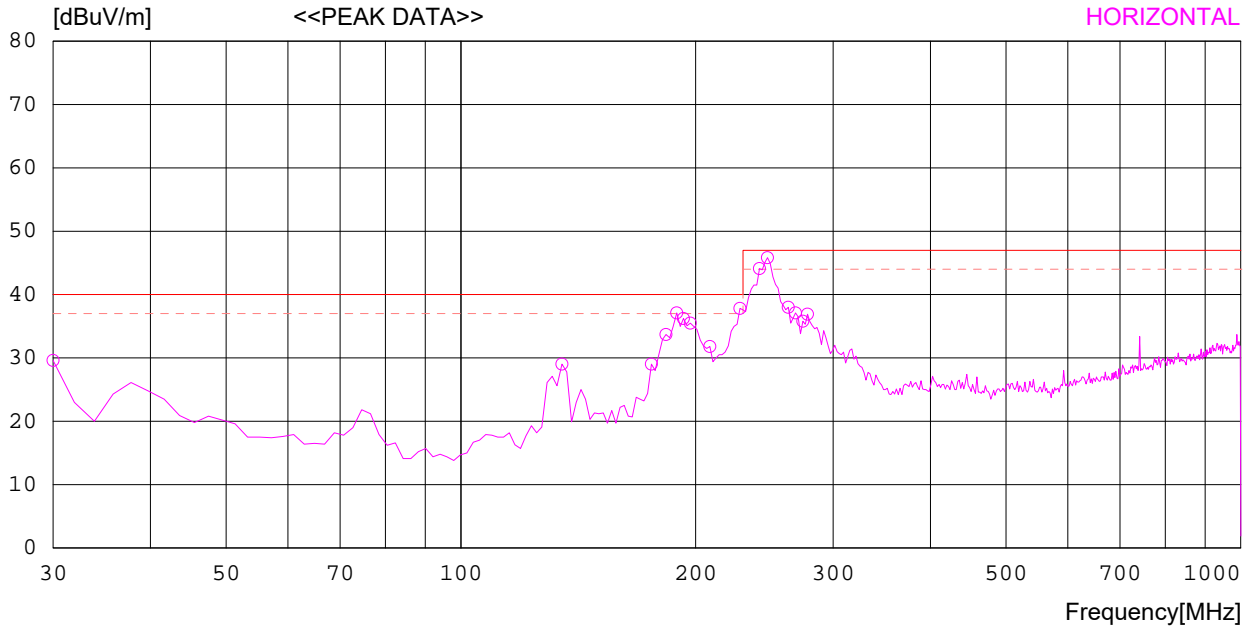

Radiated Emission

DSTech

Date : 2023-10-13 10:46:53

Order No. :	Supplied Power :
Temp/Humidity :	Operator :
Test Condition :	:

Memo :

LIMIT : 3m CLASS B
MARGIN: 3 dB

No.	FREQ [MHz]	READING PEAK [dBuV]	ANT FACTOR [dB]	LOSS [dB]	GAIN [dB]	RESULT [dBuV/m]	LIMIT [dBuV/m]	MARGIN [dB]	ANTENNA [cm]	TABLE [DEG]
----- Horizontal -----										
1	30.000	43.0	12.1	0.7	26.2	29.6	40.0	10.4	100	220
2	134.760	41.1	12.3	1.5	25.9	29.0	40.0	11	195	280
3	175.500	41.1	11.9	1.8	25.8	29.0	40.0	11	195	359
4	183.260	46.4	11.2	1.8	25.7	33.7	40.0	6.3	100	0
5	189.080	50.1	10.9	1.8	25.7	37.1	40.0	2.9	100	237
6	192.960	49.4	10.6	1.9	25.7	36.2	40.0	3.8	100	0
7	196.840	49.0	10.3	1.9	25.7	35.5	40.0	4.5	100	0
8	208.480	45.9	9.7	1.9	25.7	31.8	40.0	8.2	100	67
9	227.880	51.5	9.9	2.0	25.6	37.8	40.0	2.2	100	0
10	241.460	56.0	11.5	2.1	25.5	44.1	47.0	2.9	100	0
11	247.280	57.4	11.8	2.1	25.5	45.8	47.0	1.2	100	115
12	262.800	49.0	12.3	2.2	25.5	38.0	47.0	9	100	0
13	268.620	47.8	12.6	2.2	25.5	37.1	47.0	9.9	100	111
14	274.440	46.3	12.8	2.2	25.5	35.8	47.0	11.2	100	0
15	278.320	47.2	12.9	2.2	25.4	36.9	47.0	10.1	100	115
----- Vertical -----										
16	134.760	42.2	12.3	1.5	25.9	30.1	40.0	9.9	100	359
17	192.960	43.5	10.6	1.9	25.7	30.3	40.0	9.7	100	359
18	227.880	43.2	9.9	2.0	25.6	29.5	40.0	10.5	100	359
19	239.520	47.1	11.4	2.1	25.5	35.1	47.0	11.9	100	359
20	247.280	50.3	11.8	2.1	25.5	38.7	47.0	8.3	195	0