



Circuit component value

Bode Plot Result

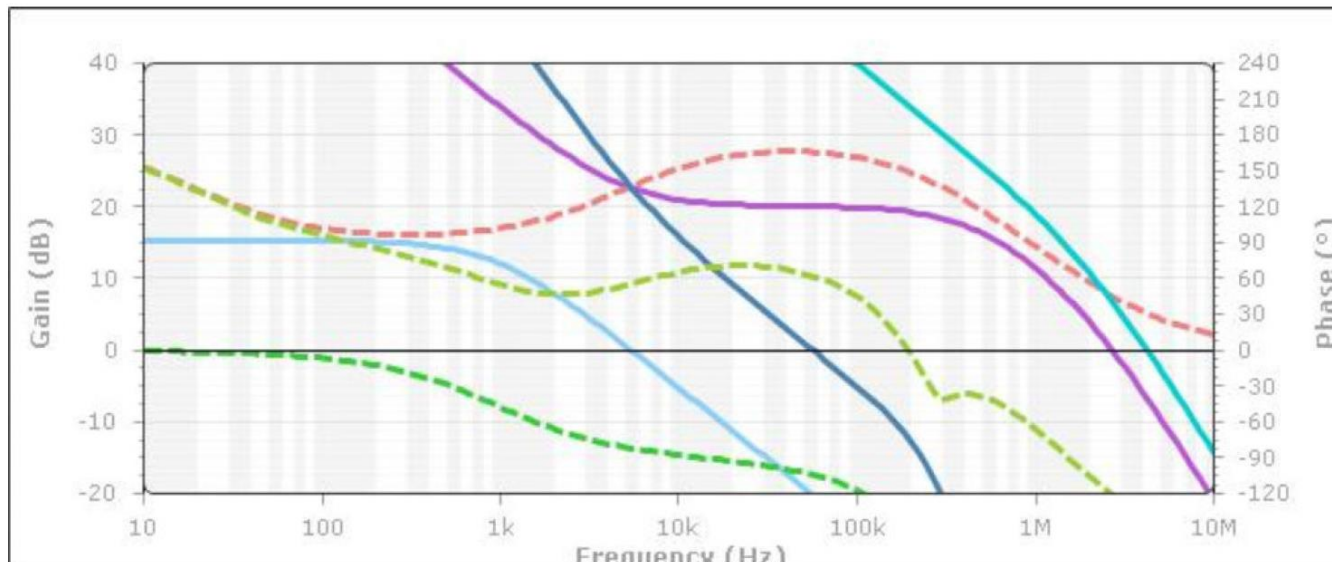

- Power Stage Gain
- Power Stage Phase
- Compensation Gain
- Compensation Phase
- Error Amp Gain
- Total Gain
- Total Phase

SwitcherPro Result: Phase Margin=63deg, Fco=57kHz, Gain Margin=-12dB

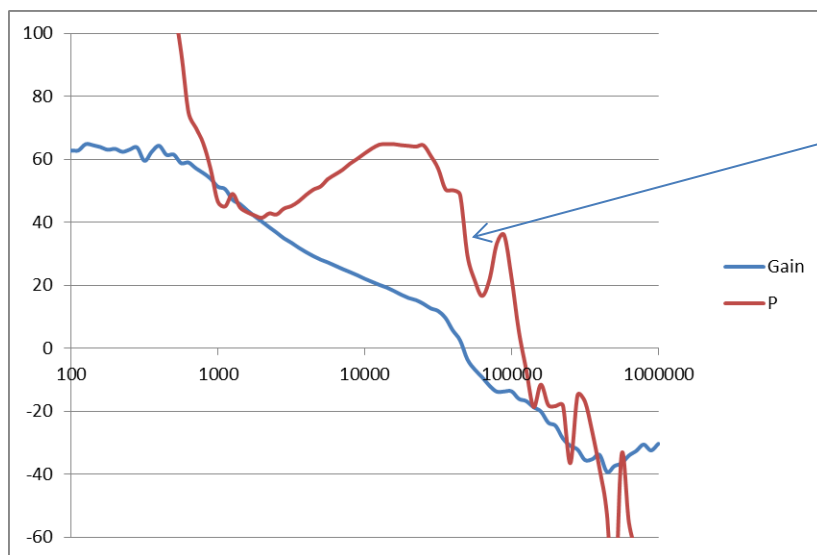

Drop suddenly at Gain=0dB point

EVM measurement Result: Phase Margin=35deg, Fco=47kHz, Gain Margin=-16dB