


In spite of $I_{SEN} < 0.25V$, Current is clamped at 6A

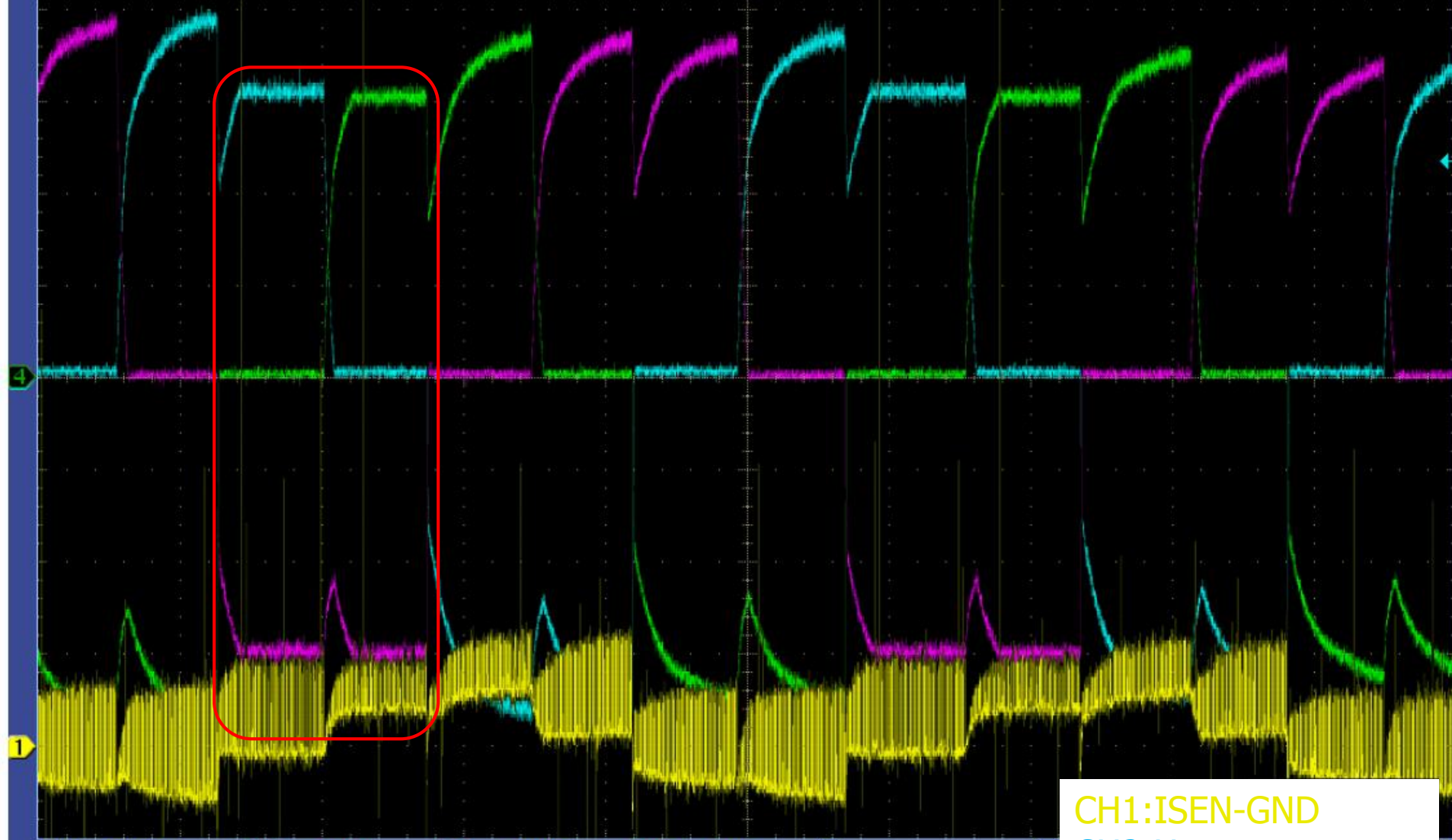

1 200mV 2 2.00 A 3 2.00 A 4 2.00 A

10.0ms
0.00000 s

CH1:I_{SEN}-GND
CH2:U motor current
CH3:V motor current
CH4:W motor current