


About Fan	VF	Angle Filter
Pole Pairs	3	
Rated DC Input (V)	12	
Rated Phase Peak Current (A)	2	
Rated Speed (rpm)	3000	
Phase Resistance (mΩ)	1050	
Phase inductance (uH)	425	
Loop Mode	Open	▼
Max Voltage Limit	18V	▼

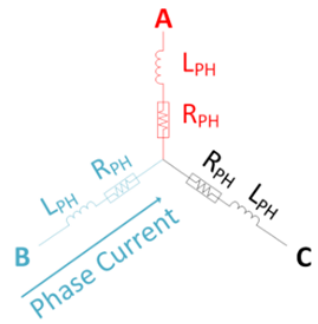

3-Phase Fan Parameters