




VM=15V, full scale current=770mA, 1/16 stepping mode, STEP=770pps

Auto tune ripple control


Yellow: OUT1, Blue: OUT2

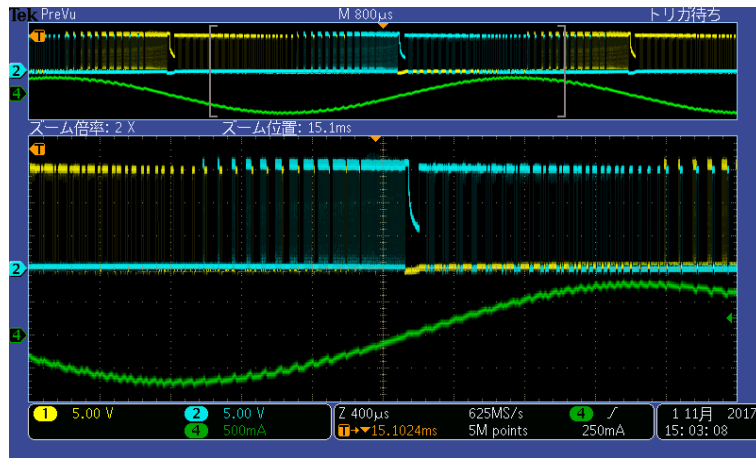

400us/div

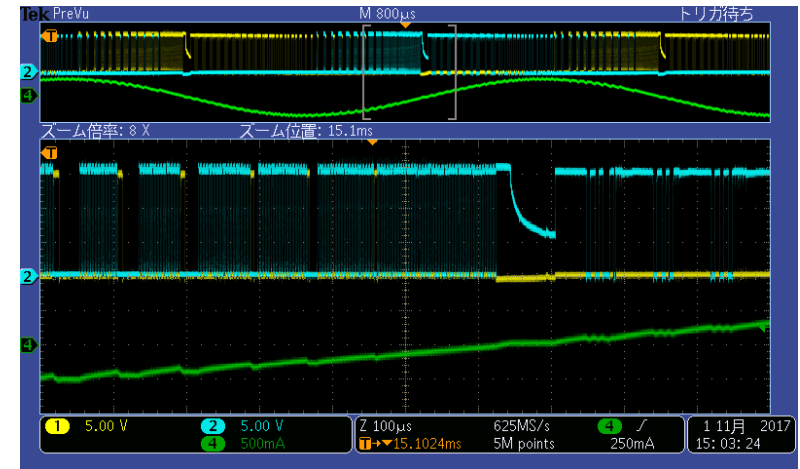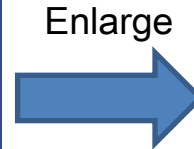

100us/div

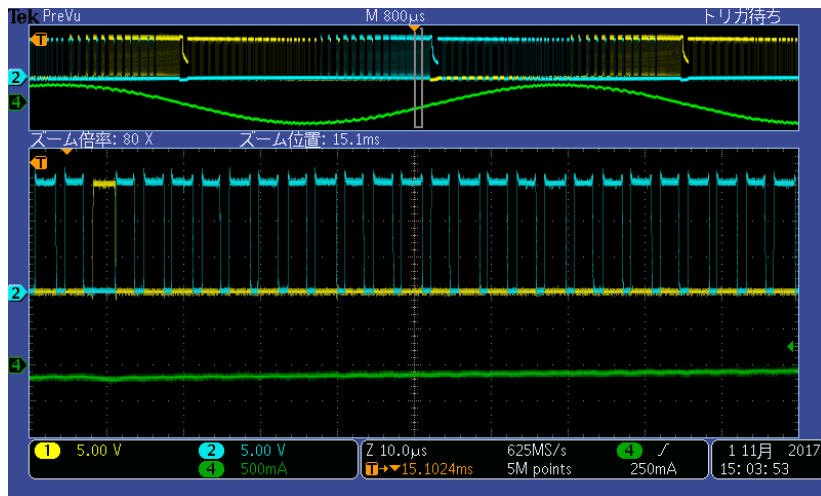


10us/div



VM=15V, full scale current=770mA, 1/16 stepping mode, STEP=770pps

Auto tune dynamic decay


Yellow: OUT1, Blue: OUT2

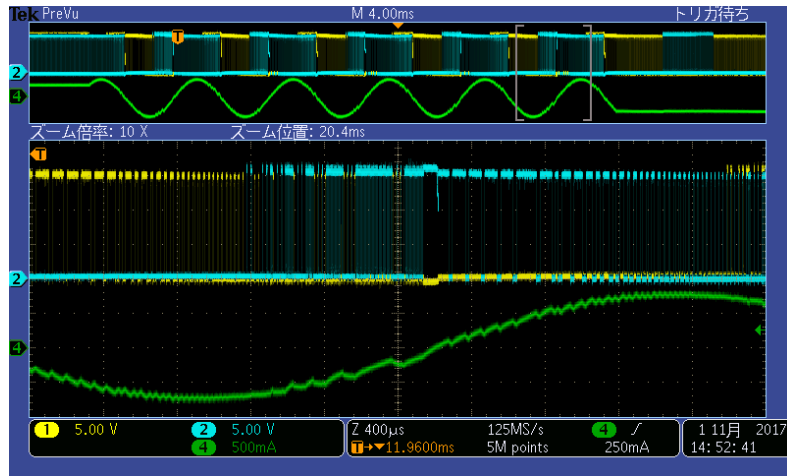



400us/div

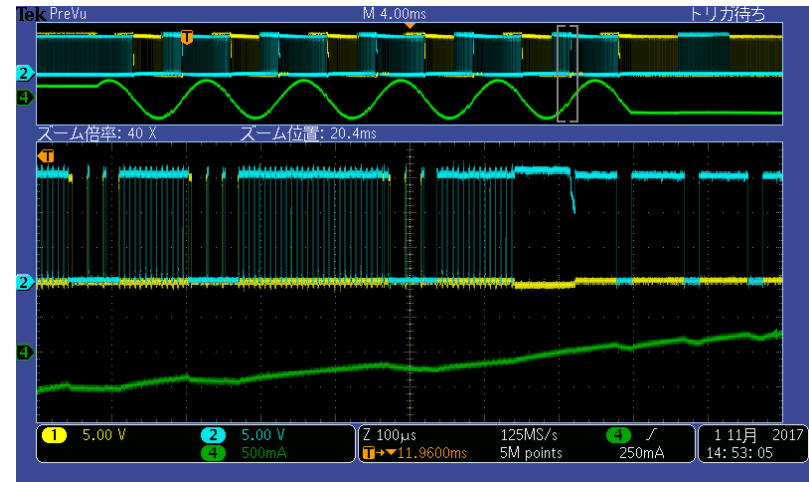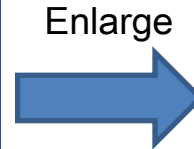

100us/div

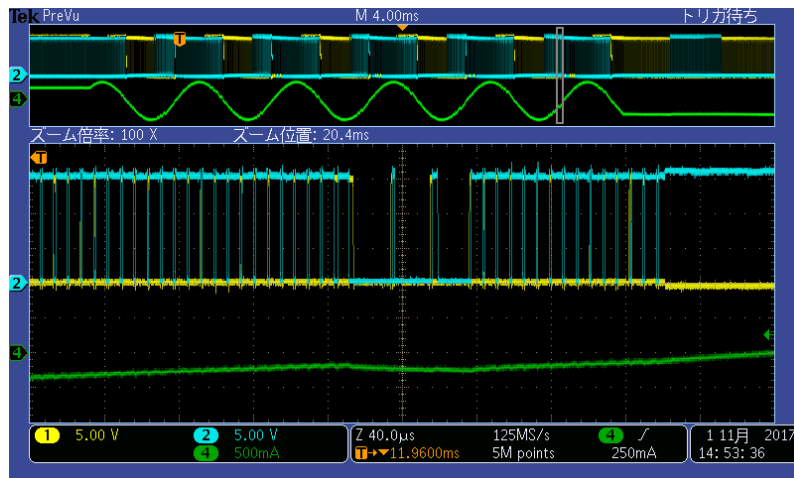

40us/div

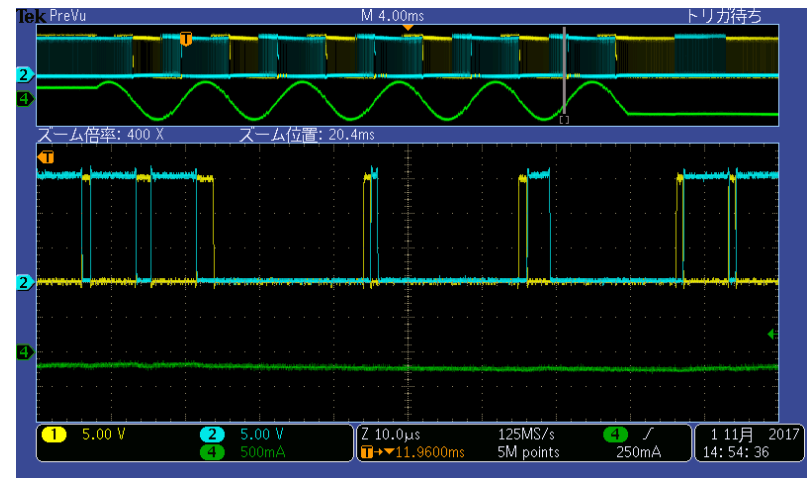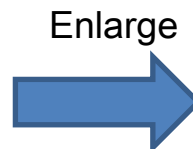

10us/div