



# Characteristics of Capacitor

## Capacitance vs Temperature

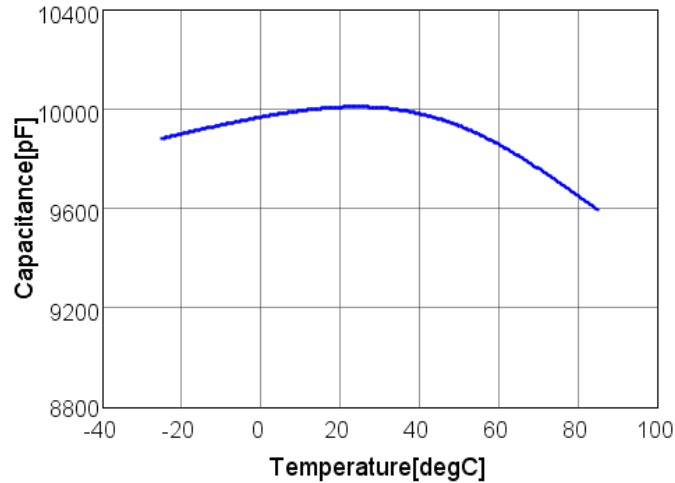


■ GRM155B31H103KA88 capacitance, DC0.0V, AC1.0Vrms

## Capacitance vs DC Bias

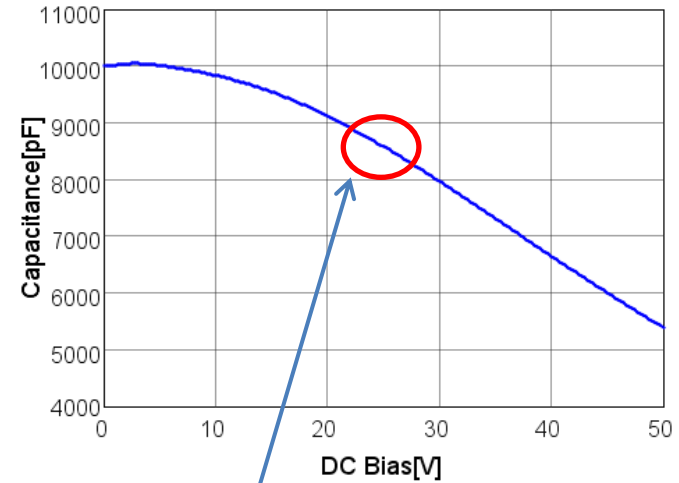


Customer use the capacitor at VM=24V

## Impedance vs Frequency

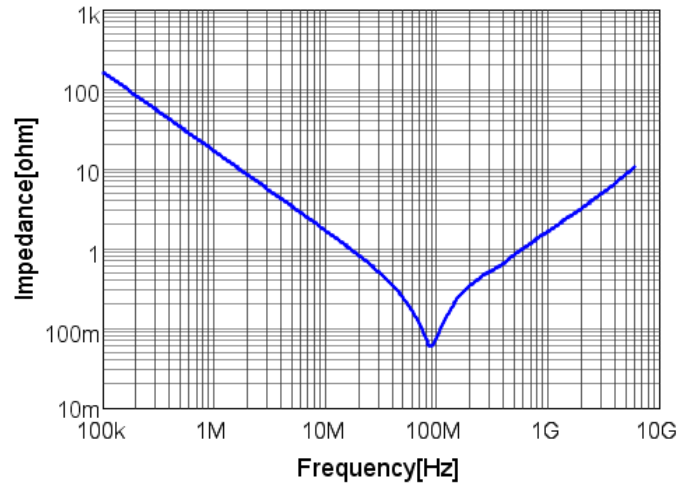

■ GRM155B31H103KA88 DC0V,20degC

## Resistance vs Frequency

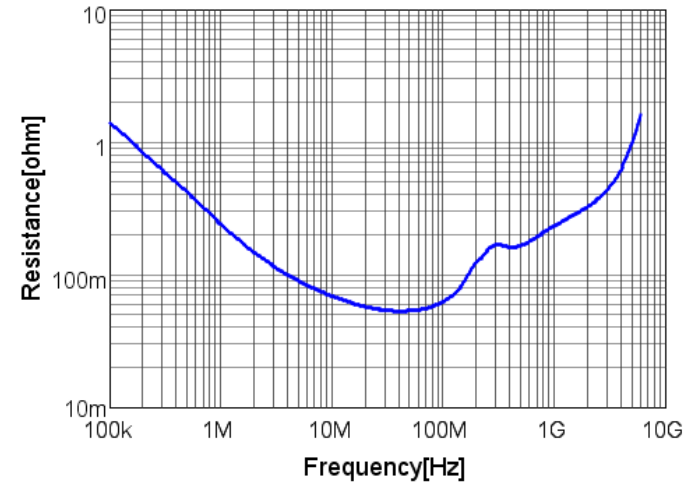

■ GRM155B31H103KA88 DC0V,20degC