


DRV8800

■ datasheet DRV8800

t_{pd}	Propagation delay time	PWM, Change to source or sink ON	600	ns
		PWM, Change to source or sink OFF	100	
t_{COD}	Crossover delay		500	ns

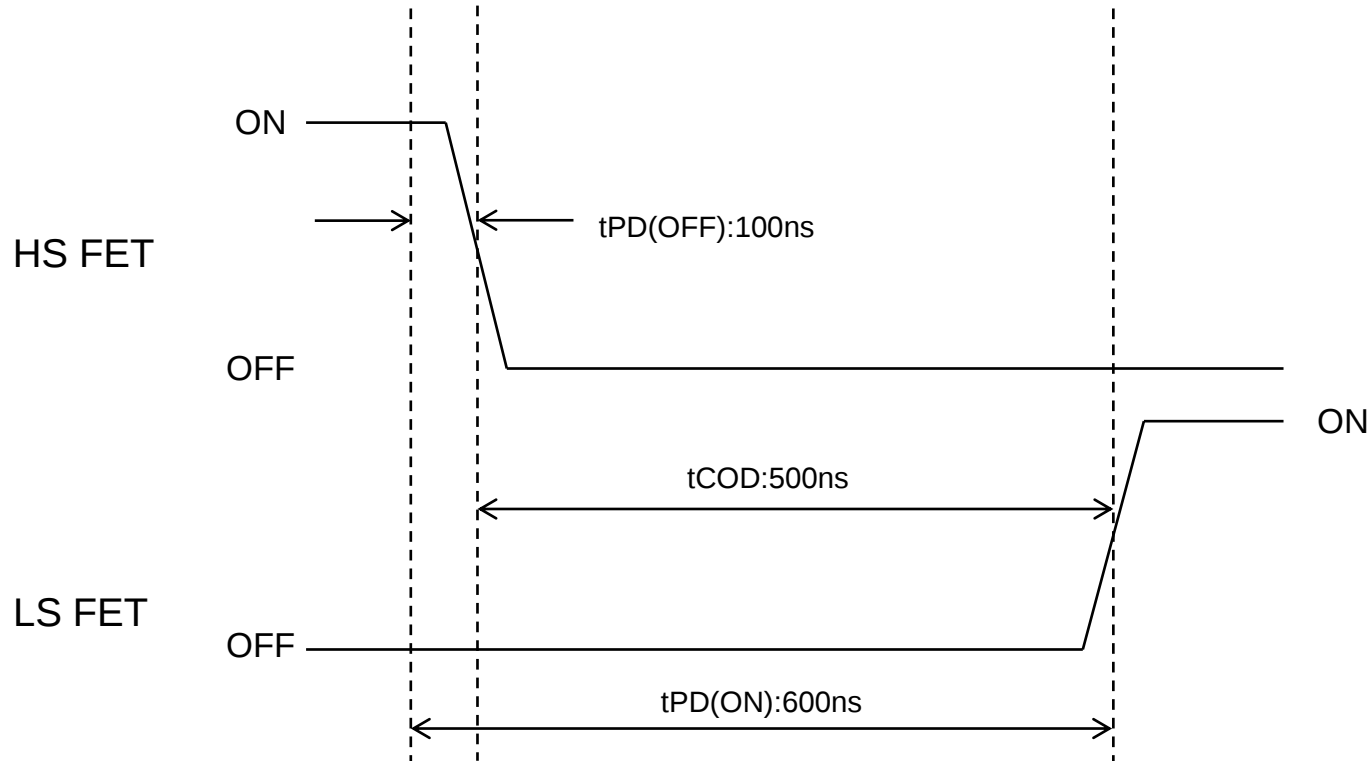

It is reasonable specifications.

DRV8824

■ datasheet DRV8824

t_R	Rise time	$V_{(VMx)} = 24\text{ V}$	100	360	ns
t_F	Fall time	$V_{(VMx)} = 24\text{ V}$	80	250	ns
t_{DEAD}	Dead time		400		ns

