


Agilent 13:45:49 11 Jul 2018

Mkr1 1.159 999 97 GHz
2.80 dBm

Ref 10 dBm

Atten 20 dB

Norm
Log
10
dB/

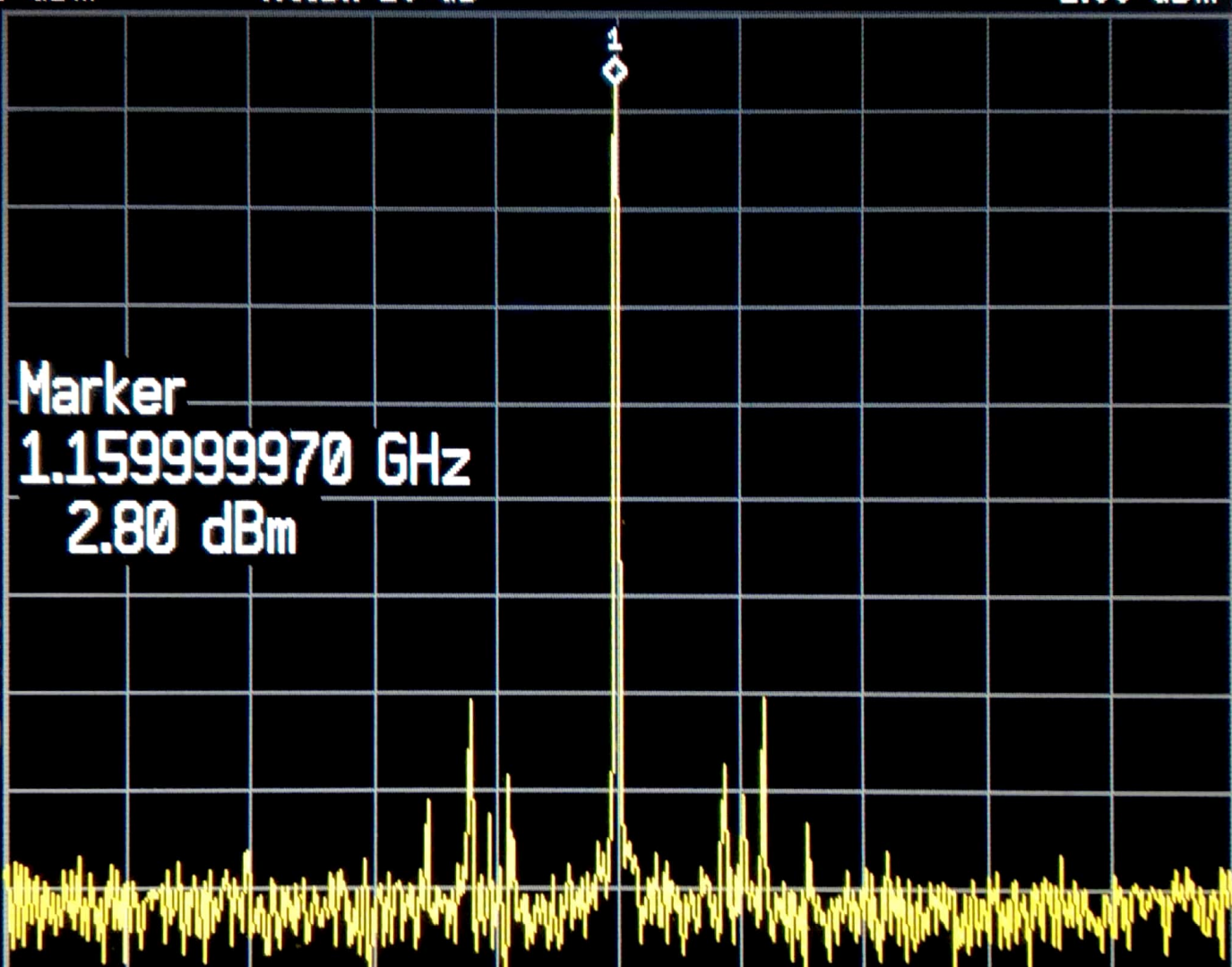

Marker
1.159999970 GHz
2.80 dBm

LgAv

W1 S2
S3 FC
AA

£(f):
f<50k
FFT

Center 1.160 000 00 GHz

Span 20 kHz

#Res BW 30 Hz

#VBW 3 Hz

Sweep 1.574 s (601 pts)

Copyright 2000-2012 Agilent Technologies