

S

* VBW 30 kHz

0.00 dBm

* SWT 100 ms

6.800000000 MHz

Ref 15 dBm

Att 50 dB

1 AP
VIEW


2 AP
CLRWR

EXREF

★

A

EXT

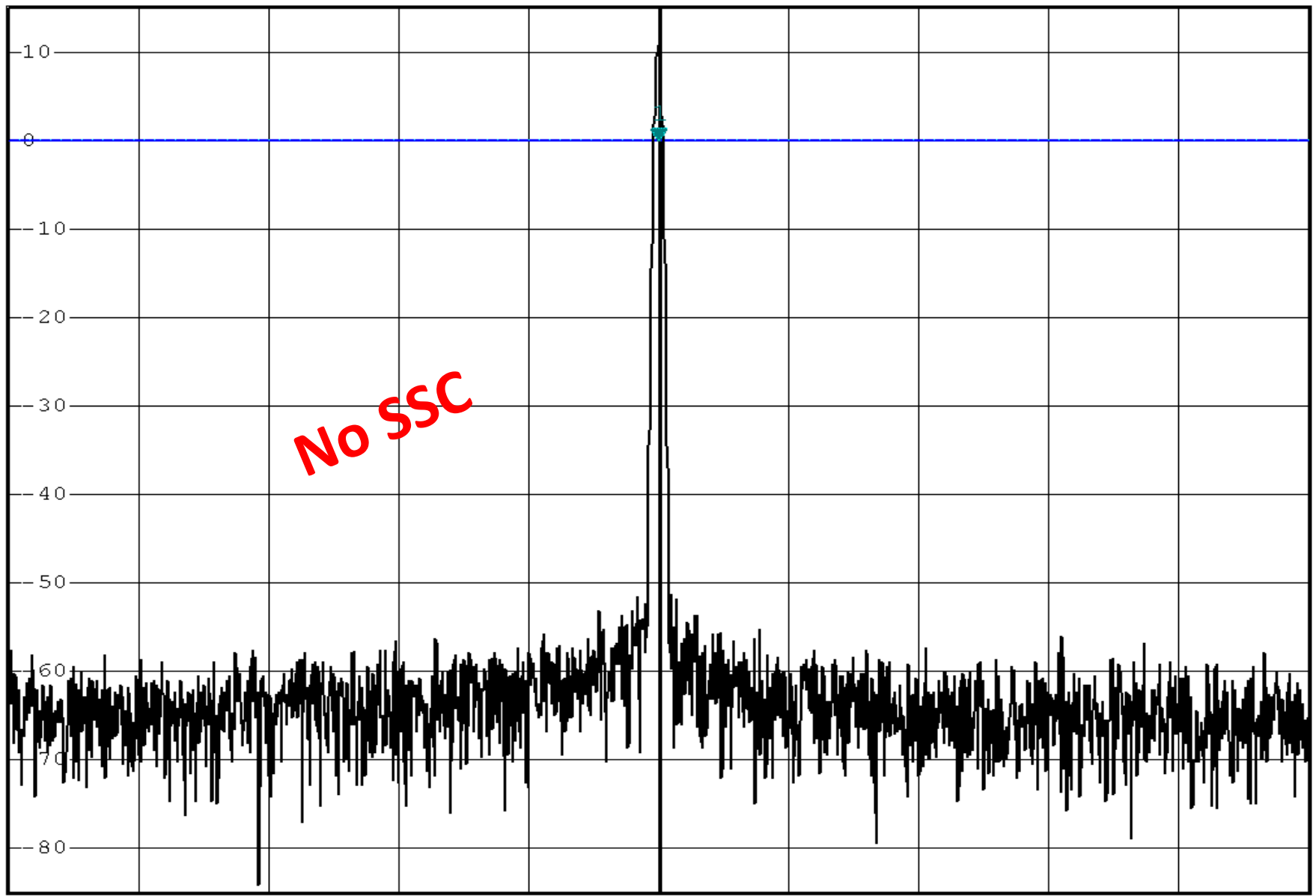

Center 6.8 MHz

300 kHz/

Span 3 MHz



Ref 15 dBm


Att 50 dB

* VBW 30 kHz

0.00 dBm

* SWT 100 ms

6.800000000 MHz

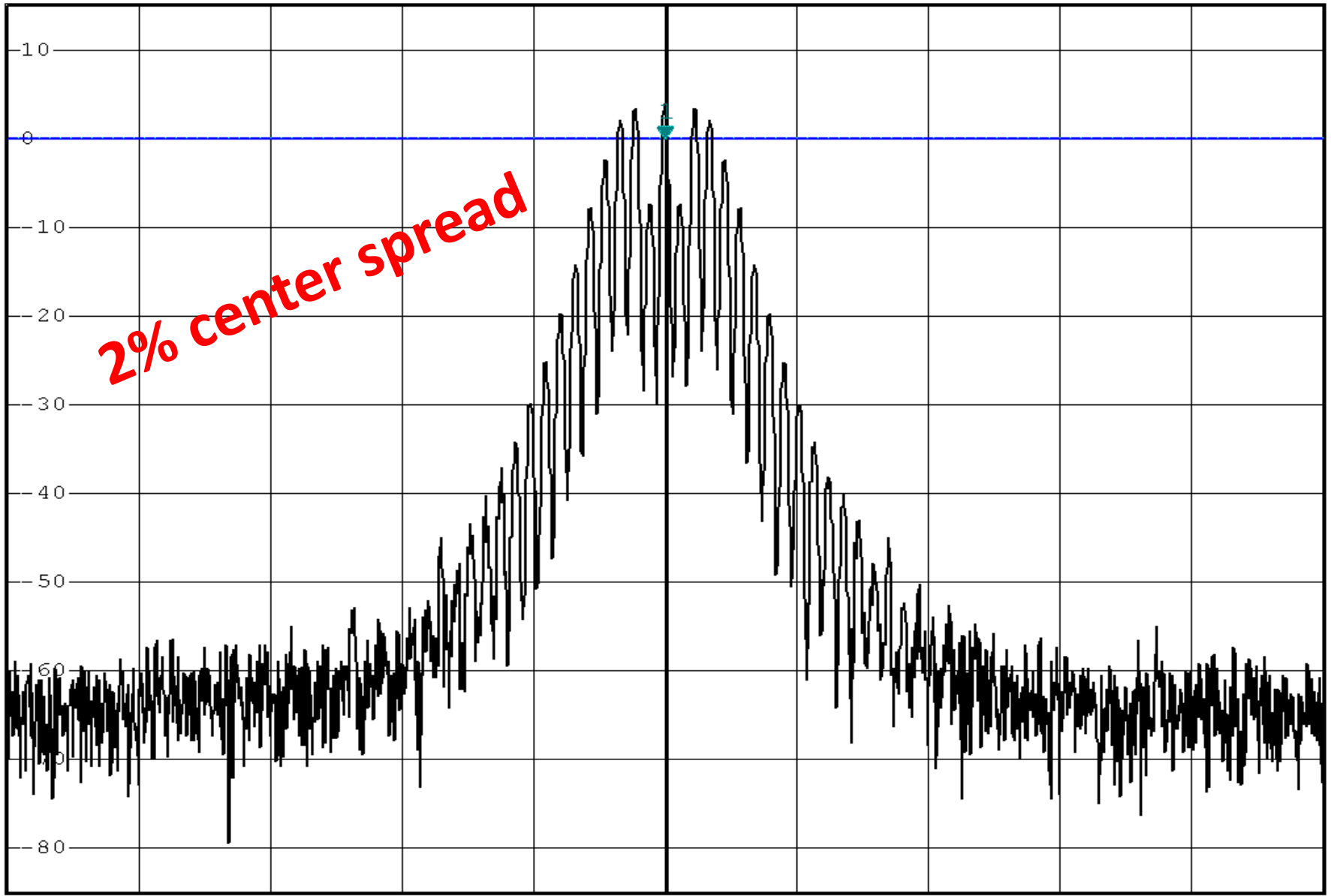

2% center spread

AP
VIEW

AP
FLWR

EXREE



A

EX

Center 6.8 MHz

300 kHz/

Span 3 MHz



Ref 15 dBm

Att 50 dB

*VBW 30 kHz

0.00 dBm

*SWT 100 ms

6.800000000 MHz

1 AP
VIEW


2 AP
CLRWR

EXREF



A

EXT

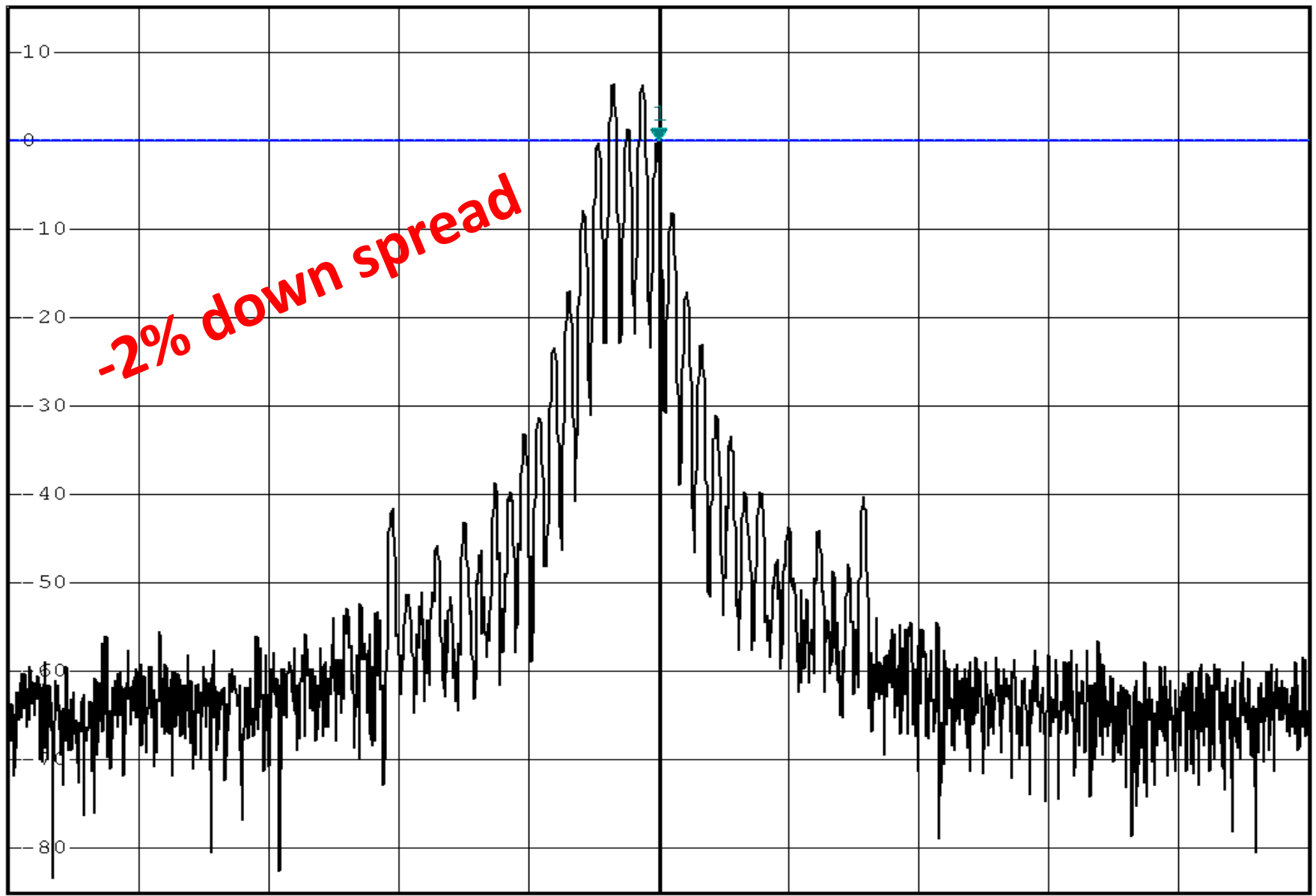

Center 6.8 MHz

300 kHz/

Span 3 MHz