


1 1.00V/ 2 500mV/ 3 1.00V/ 4 -1.510s 500.0mV/ Trig'd? f 2 1.06V

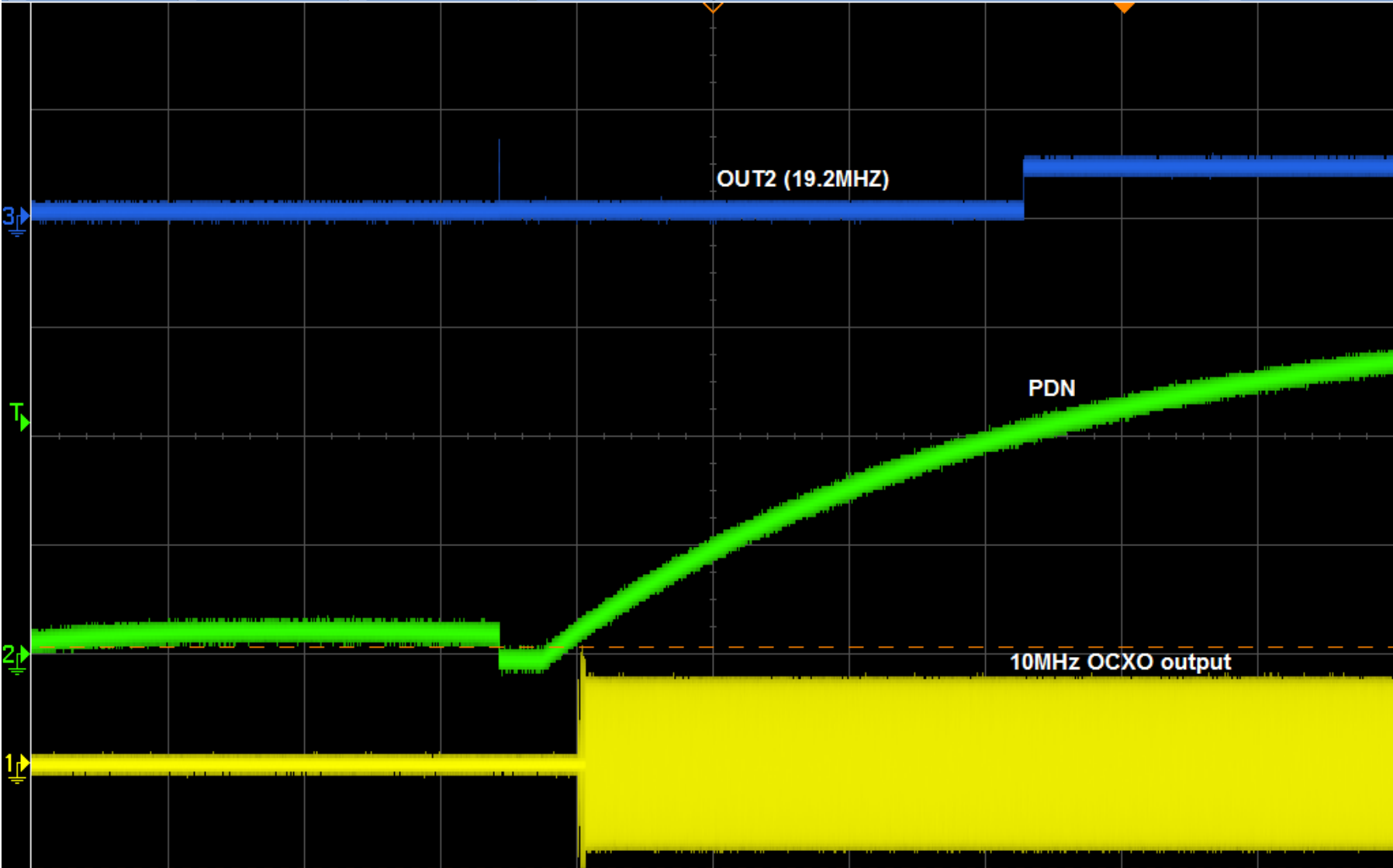

Freq(1):No edges      Pk-Pk(1) > 2.03V

Coupling DC      Imped 1M Ohm      BW Limit       Vernier       Invert       Probe