


1 1.00V/ 2 500mV/ 3 1.00V/ 4 -1.510s 500.0mV/ Trig'd? f 2 1.06V

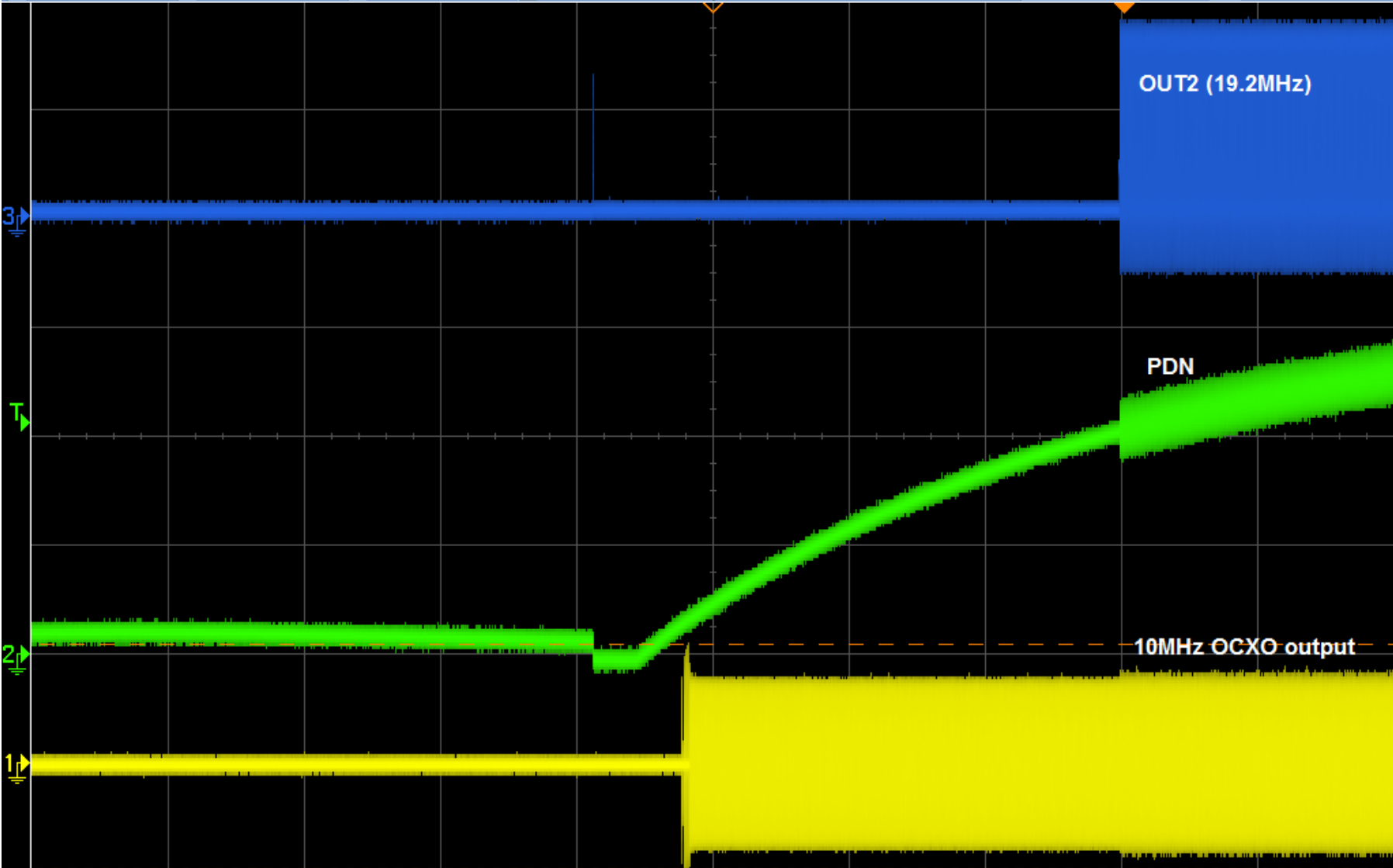

Freq(1):No edges Pk-Pk(1) > 2.06V

Coupling DC Imped 1M Ohm BW Limit Vernier Invert Probe