


UP1 Supply Voltage: 2.4~5.5V

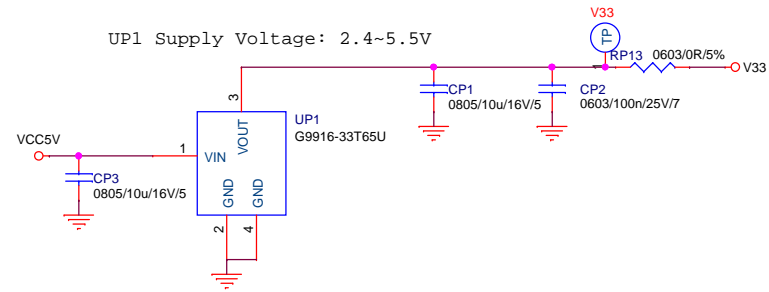

UP2 Supply Voltage: 4.5~16V

RP2= 1.1k ohm
RP4= 51.1K ohm
CP8= 47nF

DUTY = $RP4 / (RP2 + 2 * RP4) = 61.3\%$
Frequency = $1.44 / ((RP2 + 2 * RP4) * CP8) = 239.5\text{Hz}$
光學要求240Hz, 以避免LED Turn off 紅光issue

