

2004 Nov 24 - 01:44

REF -40.00 dBm


MKR 7.808 MHz

10.0 dB/ *A Write Posi

B Blank Auto

C Blank Auto

-110.43 dBm

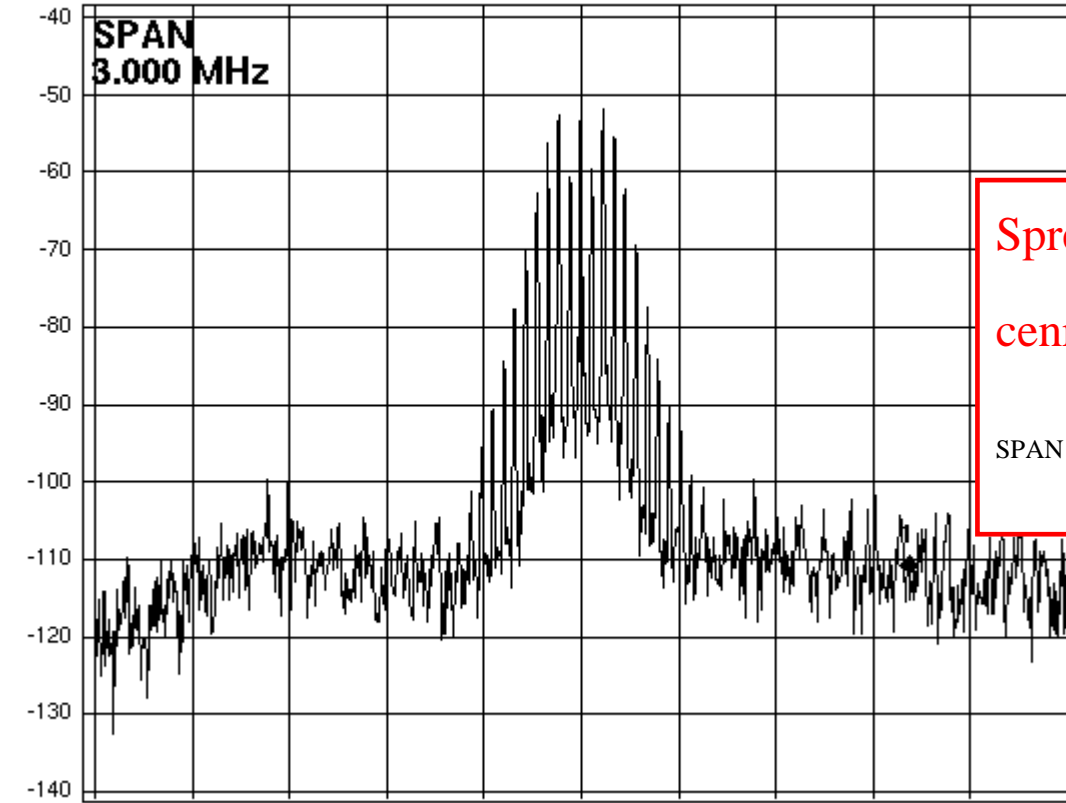

CENTER 6.800 MHz

SPAN 3.000 MHz

RBW 3 kHz

VBW 30 kHz

SWP 480 ms

HiS ATT 0 dB

2004 Nov 24 - 01:43

REF -40.00 dBm


MKR 7.136 MHz

10.0 dB/ *A Write Posi

B Blank Auto

C Blank Auto

-108.64 dBm

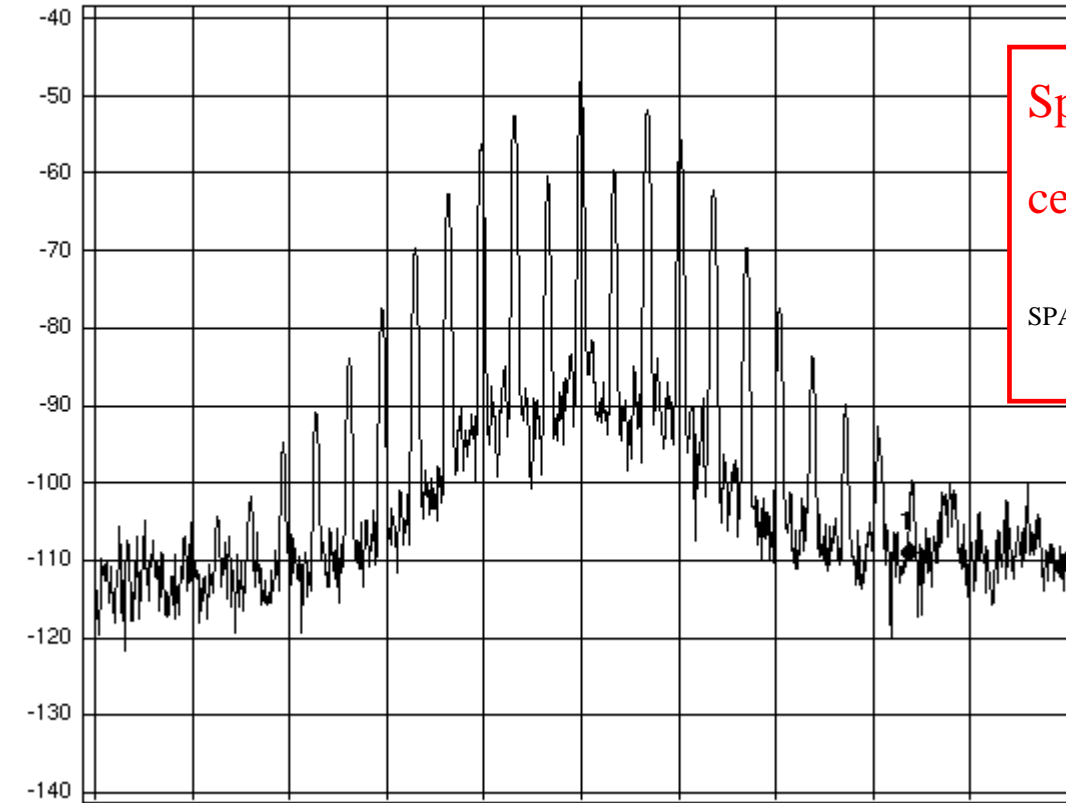

Spread Spectrum : N ON
center $\pm 2\%$
SPAN : 1 MHz z

CENTER 6.800 MHz

SPAN 1.000 MHz

RBW 3 kHz

VBW 30 kHz

SWP 480 ms

HiS ATT 0 dB