


Signal Path : 3-tone -20dBFS 48kHz

-Test: 3tone-20dB Output: C/Sub  
48LL71-48-1509-3tone-20dB-51 hh  
2017-02-15

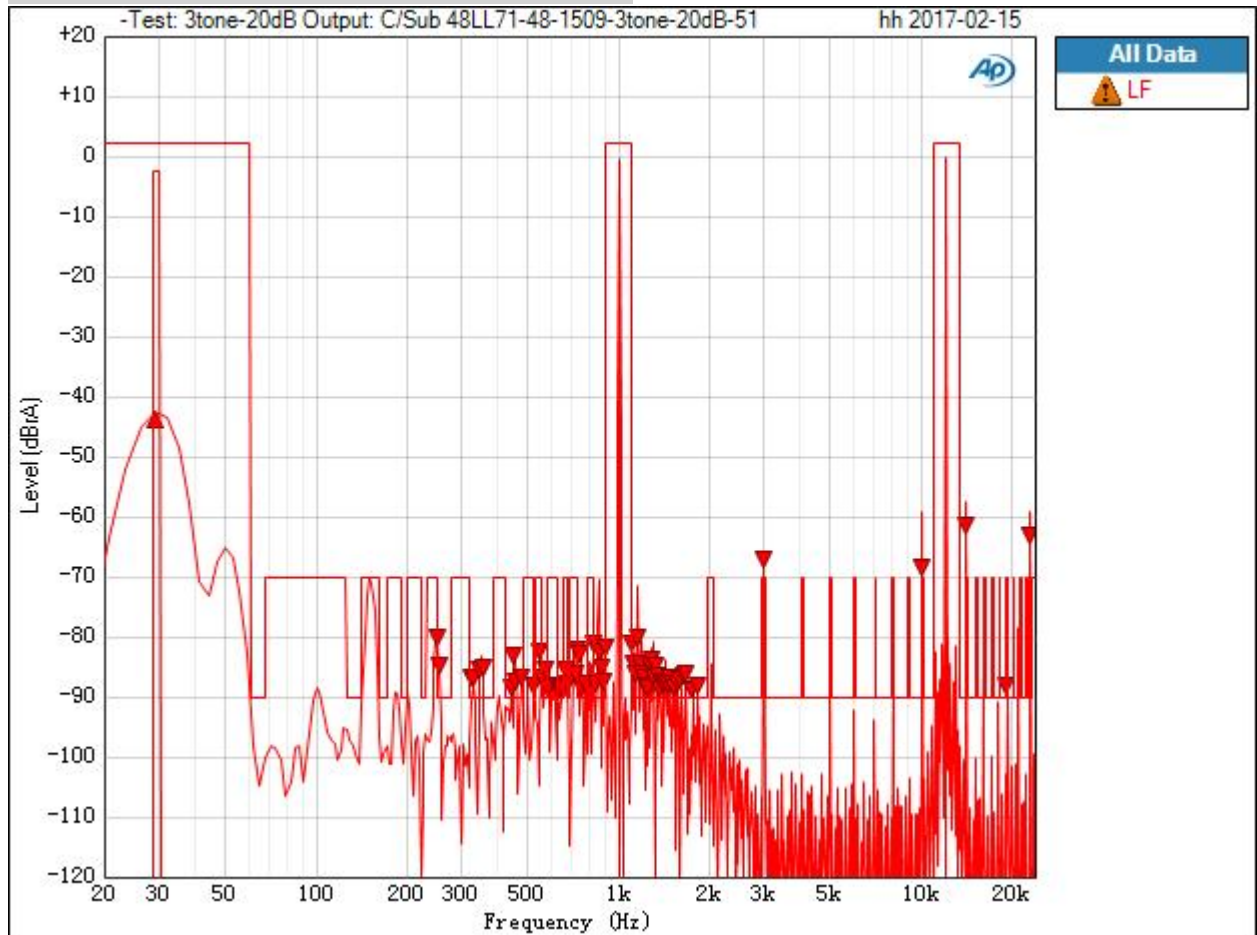

- LF Failed Upper Limit, Failed Lower Limit
- RF Failed Upper Limit, Failed Lower Limit
- Sub Failed Upper Limit
- Cen Failed Upper Limit, Failed Lower Limit
- Lss Failed Upper Limit, Failed Lower Limit
- Rss Failed Upper Limit, Failed Lower Limit
- Lsr Failed Lower Limit
- Rsr Failed Lower Limit
- Result: FAILED

