


Disc Benders - Bimorphs

#20-2235

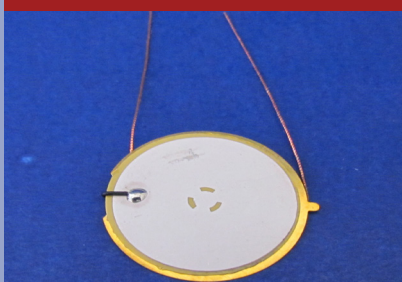

26.0mm dia. meter
2.6 kHz bimorph w/ leads

FEATURES


- Clear Sound
- High Sound Pressure
- Low Power Consumption
- Two PZT Layers
- Competitive Pricing
- Fast Delivery

APPLICATIONS

- Household Appliance Alarms
- Watch Alarms
- Smoke Detectors
- Keyboards/Push-button Devices
- Buzzers and Speakers
- Toys and Games

TECHNICAL SPECIFICATIONS

Max Drive Voltage	15 Volt P/P
Resonant Frequency	2.6 $\pm$ 0.50kHz
Capacitance (pF at 1kHz)	160,000 pF $\pm$ 30%
Ohms @ Resonant Frequency	<1,000
Brass Diameter	26.0mm $\pm$ 0.30mm
Ceramic Diameter	24.6mm
Overall Thickness	0.36mm $\pm$ 0.1mm
Brass Thickness	0.1mm

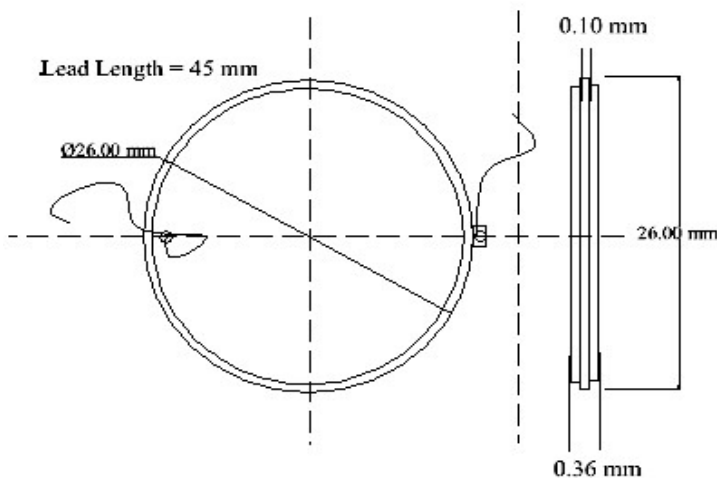

Rev. 8/22/14