Sa 5.00MSa/s  
Curr 700kpts

Edge CH1

f DC

L 600mV

1 DC1M

1.00 V/div  
-2.10 V

2 DC1M

1.00 V/div  
0.00 mV

ACQUIRE

Max[1]=3.28V

Min[1]=1.76V

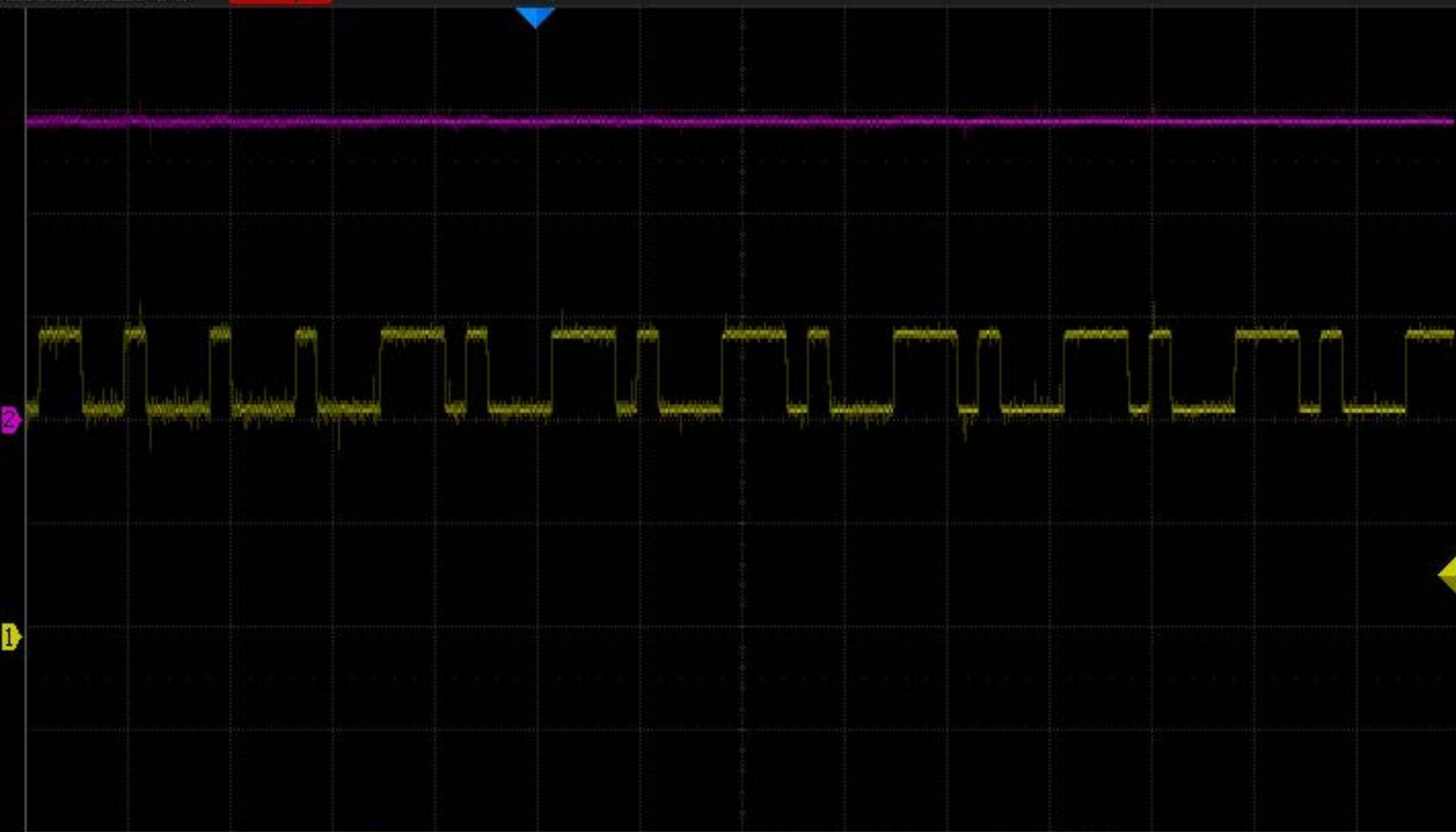
Max[2]=3.12V

Min[2]=2.64V

Acquisition  
NormalXY  
Off

Sequence

Mem Depth  
700kNext Page  
Page 1/2

Sa 100MSa/s  
Curr 700kpts

Edge CH1

DC

L 600mV

1 DC1M

1.00 V/div  
-2.10 V

2 DC1M

1.00 V/div  
0.00 mV

ACQUIRE

Max[1]=3.28V

Min[1]=1.84V

Max[2]=3.12V

Min[2]=2.68V

Acquisition  
NormalXY  
Off

Sequence

Mem Depth  
700kNext Page  
Page 1/2