


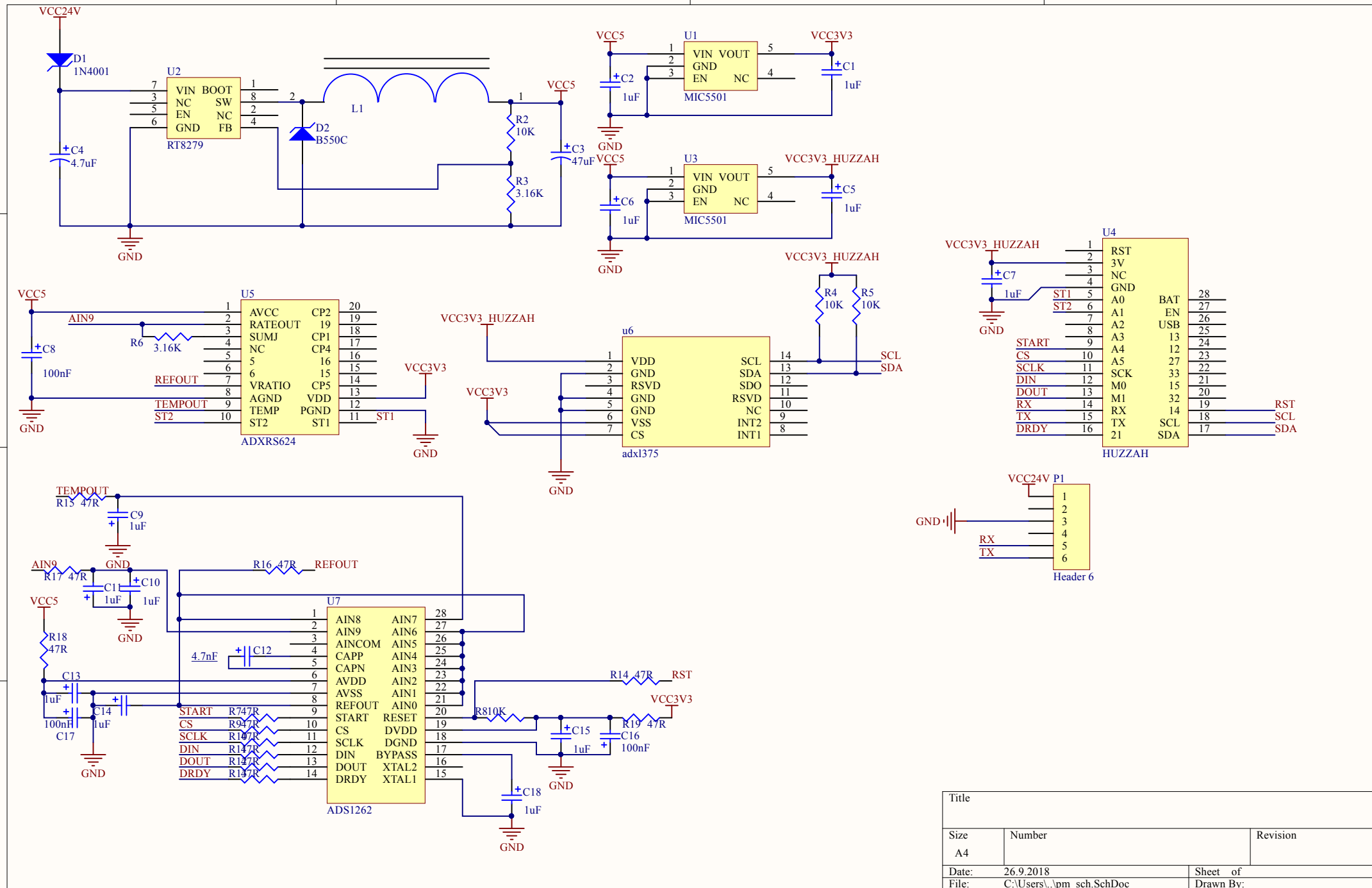

Title		
Size	Number	Revision
A4		
Date:	26.9.2018	Sheet of
File:	C:\Users\pm\sch.SchDoc	Drawn By:

Comment	Description	Designator	Footprint	LibRef	Quantity
Cap Pol2	Polarized Capacitor (Axial)	C1, C2, C5, C6, C7, C9, C10, C11, C12, C13, C14, C15, C16, C17, C18	0603	Cap Pol2	15
47uF	Aluminum Electrolytic Capacitor, Radial Style with Long Leads: 2.2uF, 450V	C3	B	EKA00DC122P00	1
4.7uF	Aluminum Electrolytic Capacitor, Radial Style with Long Leads: 2.2uF, 450V	C4	B	EKA00DC122P00	1
Cap Pol2	Polarized Capacitor (Axial)	C8	C	Cap Pol2	1
1N4001	High-Voltage Power Zener Diode	D1	SMB	ZM33U180	1
B550C	High-Voltage Power Zener Diode	D2	SMC	ZM33U180	1
Inductance_10		L1	CAPPR5-4X5	Inductance_10	1
Header 6	Header, 6-Pin	P1	HDR1X6	Header 6	1
Res3	Resistor	R2, R3, R4, R5, R6	0603	Res3	5
Res3	Resistor	R7, R9, R10, R11, R12, R13, R14, R15, R16, R17, R18, R19	AXIAL-0.3	Res3	12
Res3	Resistor	R8	J1-0603	Res3	1
adxl375		u6	ADXL375	adxl375	1
MIC5501		U1, U3	MIC5501	MIC5501	2
RT8279		U2	RT8279	RT8279	1
HUZZAH		U4	HUZZAH	HUZZAH	1
ADXRS624		U5	ADXRS624	ADXRS624	1
ADS1262		U7	ADS1262	ADS1262	1