


Lab Notebook Entry from LeCroy DSO
DSO S/N: LCRY2801N55750
User: LeCroyUser
Time: 3/7/2019 5:26:38 PM

3/7/2019 5:26:38 PM

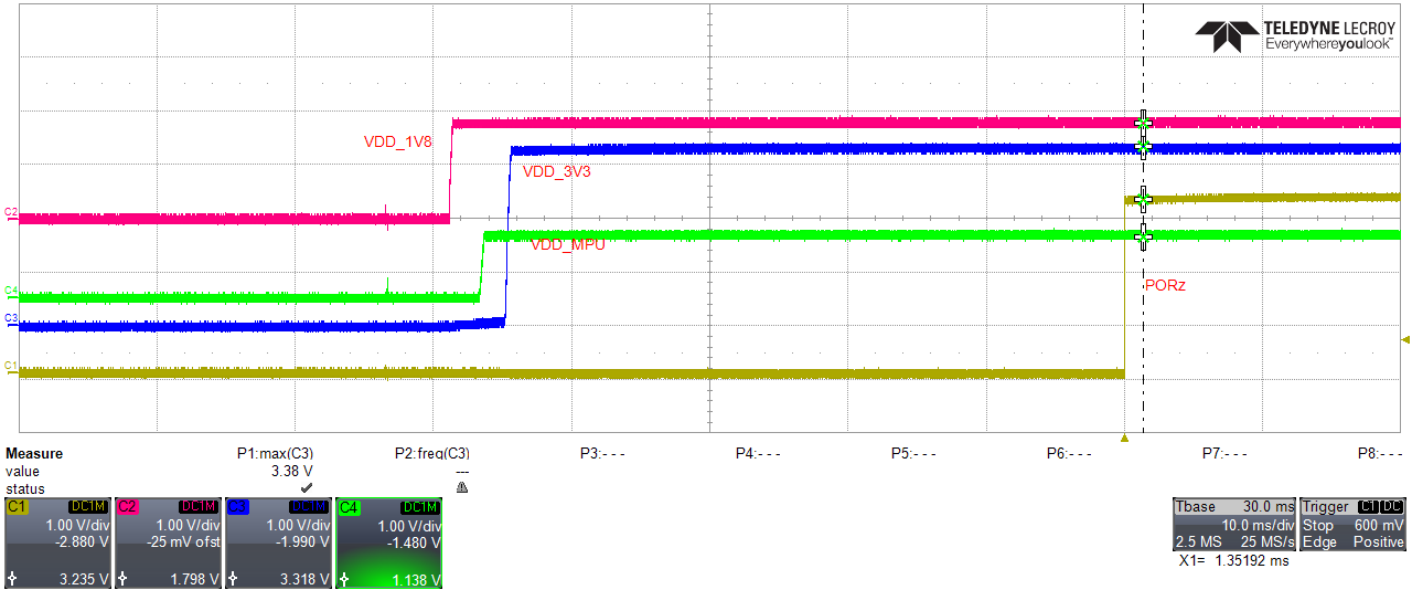

C4 - VDD_MPU, C3 - VDD_3V3, C2 - VDD_1V8, C1 - PORz



Channel Status

	C1	C2	C3	C4
V / Div	1.00 V	1.00 V	1.00 V	1.00 V
Offset	-2.880 V	-25 mV	-1.990 V	-1.480 V
Coupling	DC1MΩ	DC1MΩ	DC1MΩ	DC1MΩ
BW-Limit	1GHZ	1GHZ	1GHZ	1GHZ
Probe	10	10	10	10
Sweeps	1 #	1 #	1 #	1 #

Acquisition Status

	Time / Div	10.0 ms	Sampling Rate	25.000000 MS/s
Horizontal	Time / Pt	40.000000 ns	Sampling Mode	RealTime
	Pts / Div	250.0000 kS	Trigger Delay	30.0 ms
	Mode	Stop	Slope	Positive
Trigger	Type	Edge	Level	600 mV
	Source	C1	Coupling	DC