




Lab Notebook Entry from LeCroy DSO
DSO S/N: LCRY2801N55750
User: LeCroyUser
Time: 3/7/2019 12:49:56 PM

3/7/2019 12:49:56 PM

C4 - 1V8, C3 3V3, C2 DSP, C1 PORz

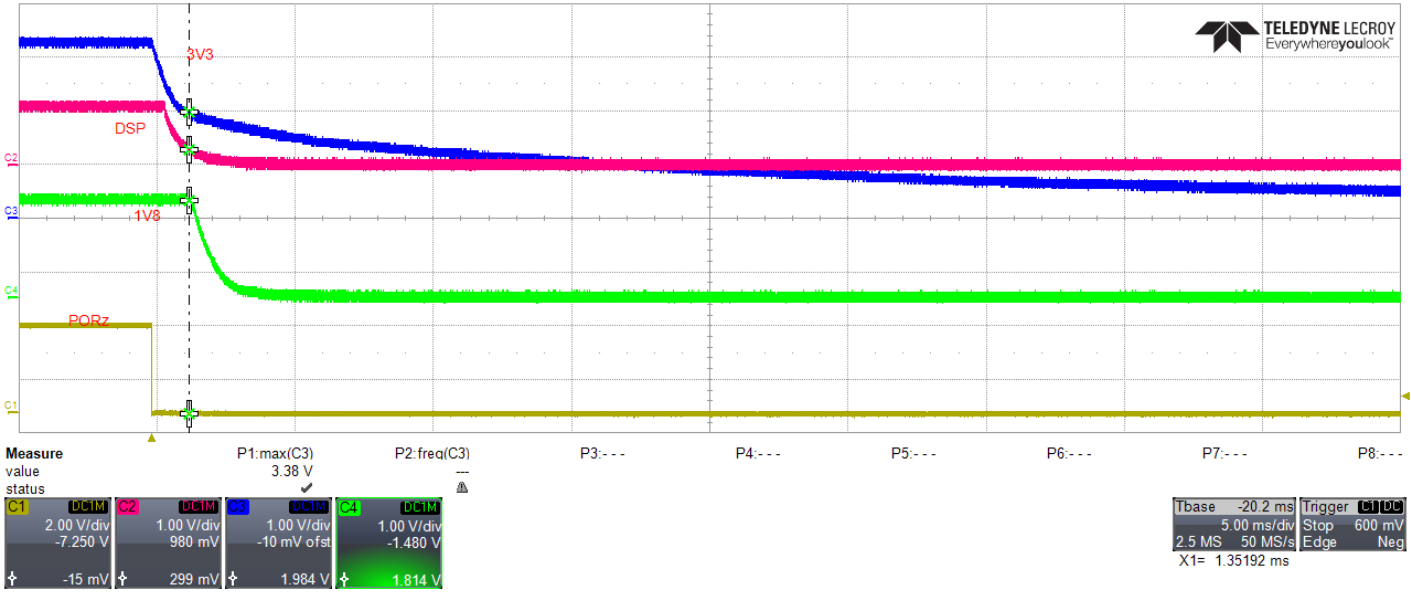

Channel Status

	C1	C2	C3	C4
V / Div	2.00 V	1.00 V	1.00 V	1.00 V
Offset	-7.250 V	980 mV	-10 mV	-1.480 V
Coupling	DC1MΩ	DC1MΩ	DC1MΩ	DC1MΩ
BW-Limit	1GHZ	1GHZ	1GHZ	1GHZ
Probe	10	10	10	10
Sweeps	1 #	1 #	1 #	1 #

Acquisition Status

	Time / Div	5.00 ms	Sampling Rate	50.000000 MS/s
Horizontal	Time / Pt	20.000000 ns	Sampling Mode	RealTime
	Pts / Div	250.0000 kS	Trigger Delay	-20.2 ms
	Mode	Stop	Slope	Negative
Trigger	Type	Edge	Level	600 mV
	Source	C1	Coupling	DC