




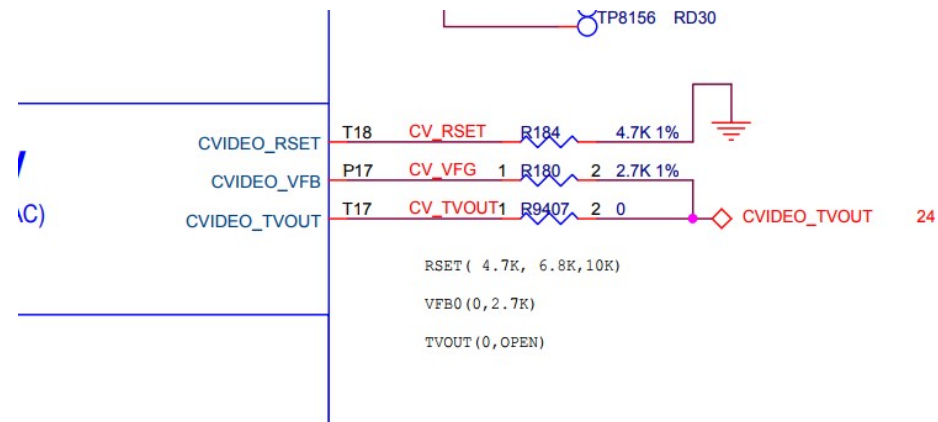



Default : R180 – 2.7K, R184 – 4.7K, R9407-0

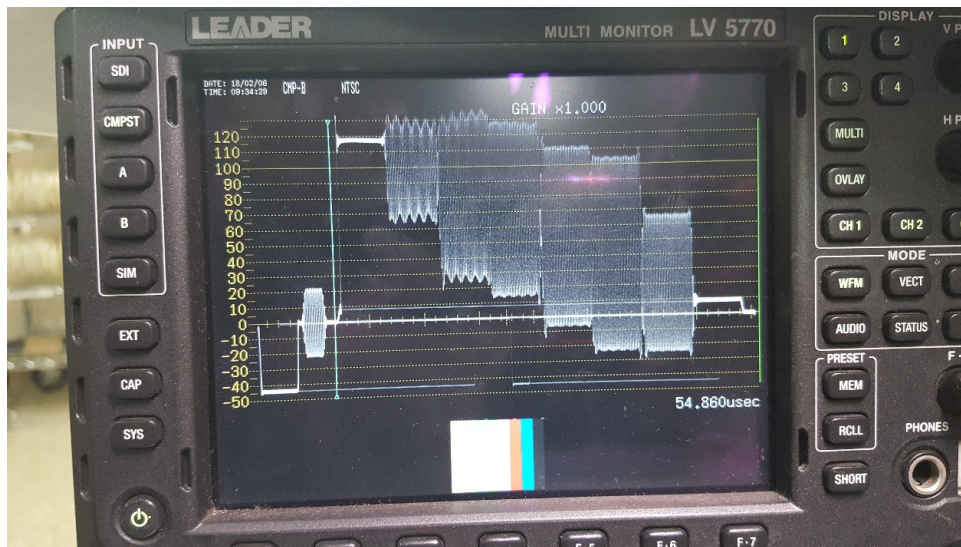

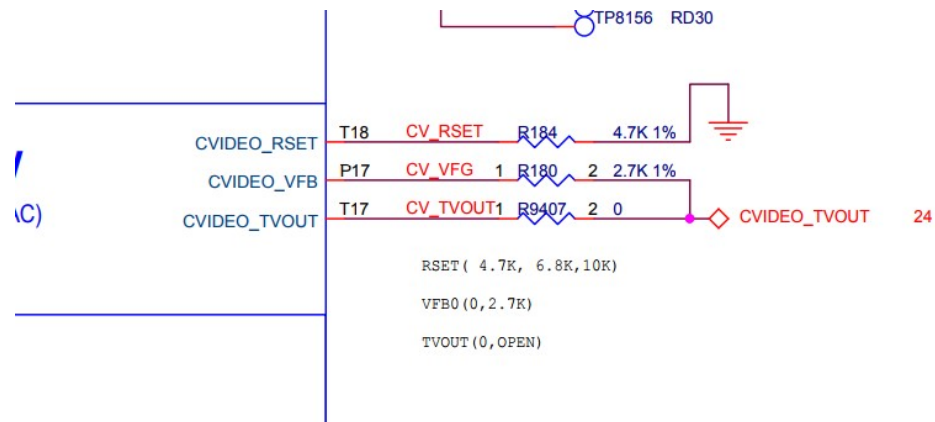



R180 – 2.7K, R184 – 6.8K, R9407-0

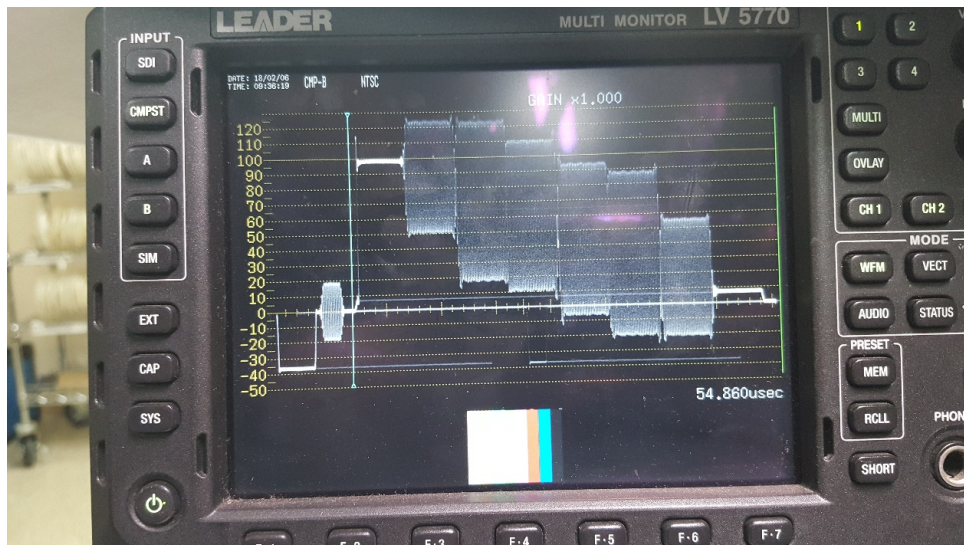


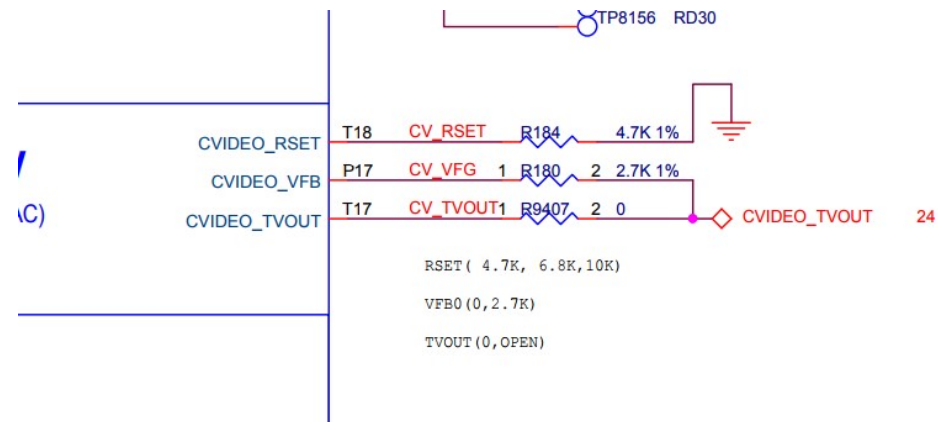



R180 – 2.7K, R184 – 10K, R9407-0

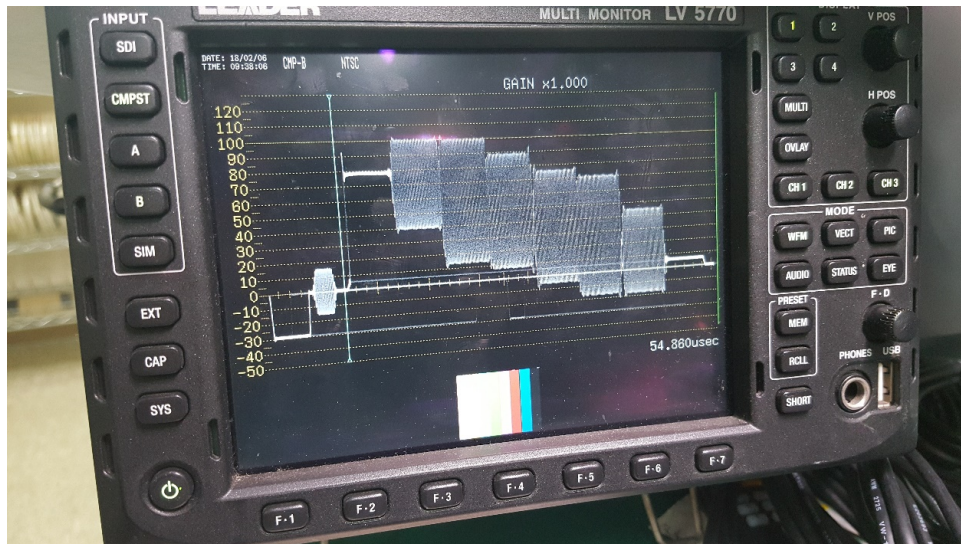


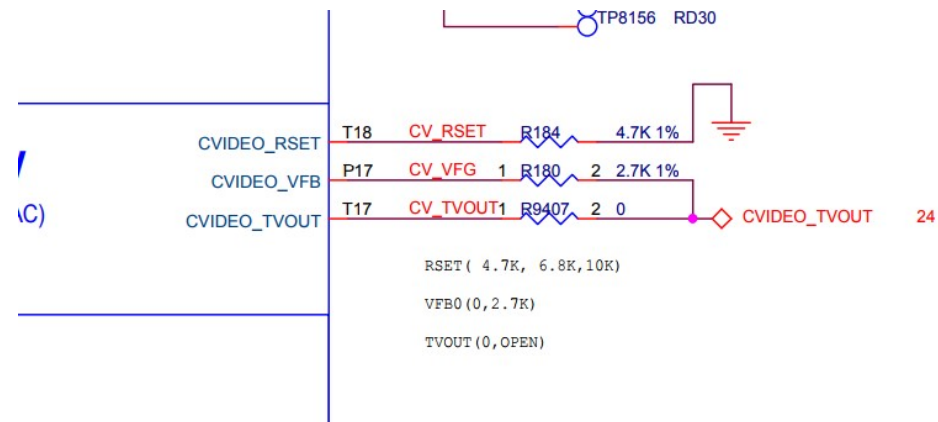



R180 – 1.0K, R184 – 6.8K, R9407-0

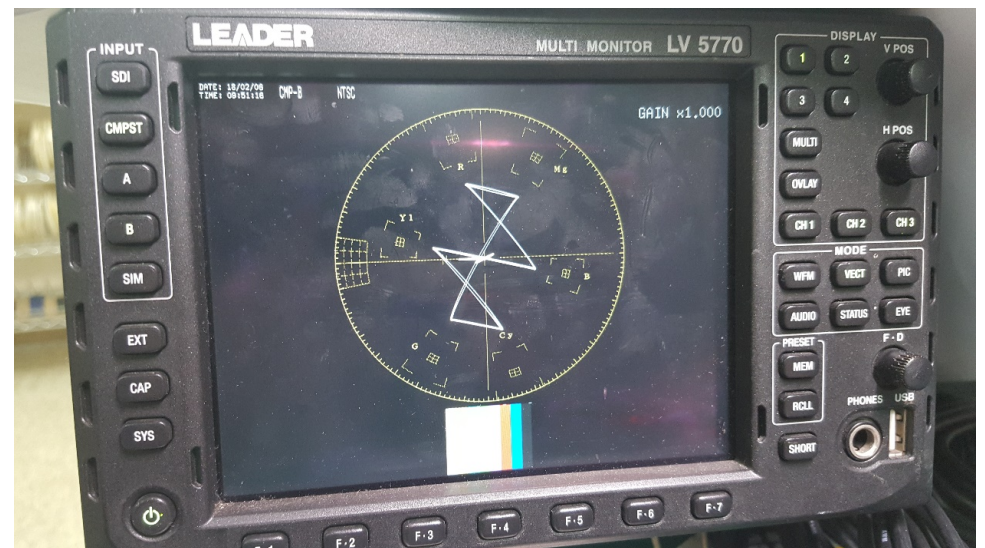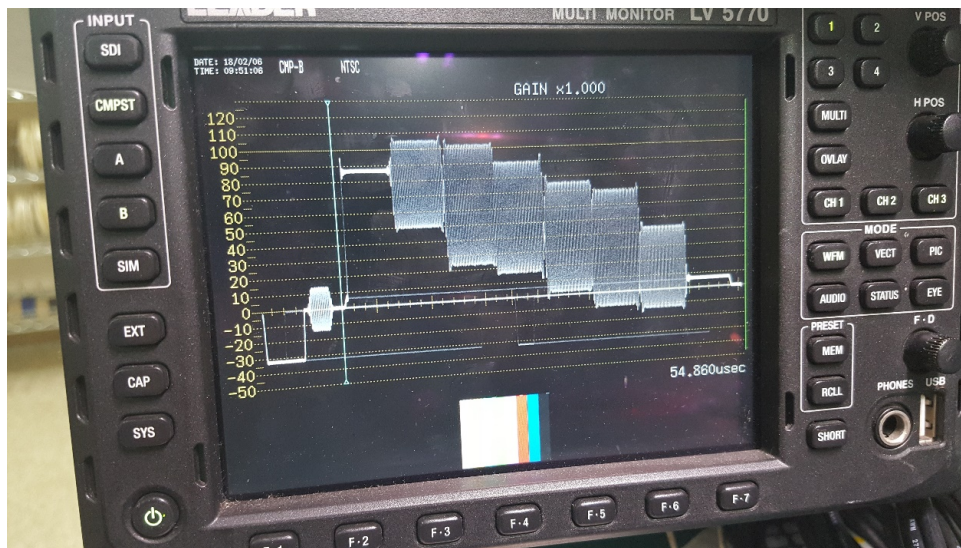

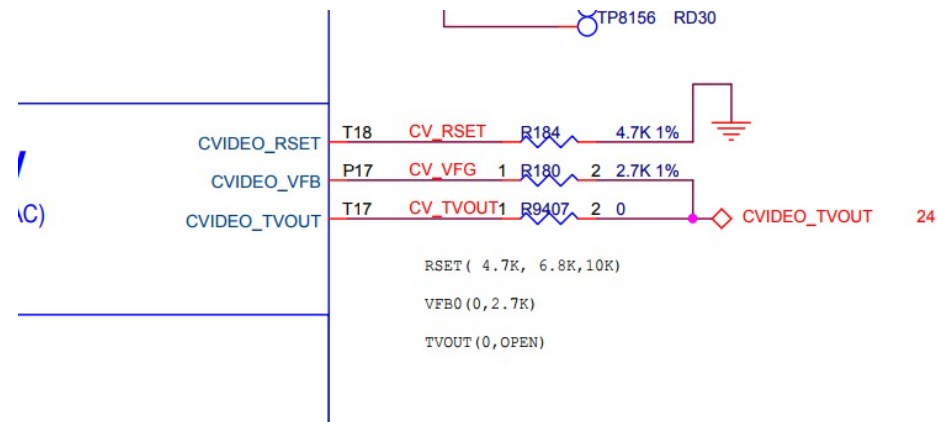

R180 – 3.3K, R184 – 6.8K, R9407-0

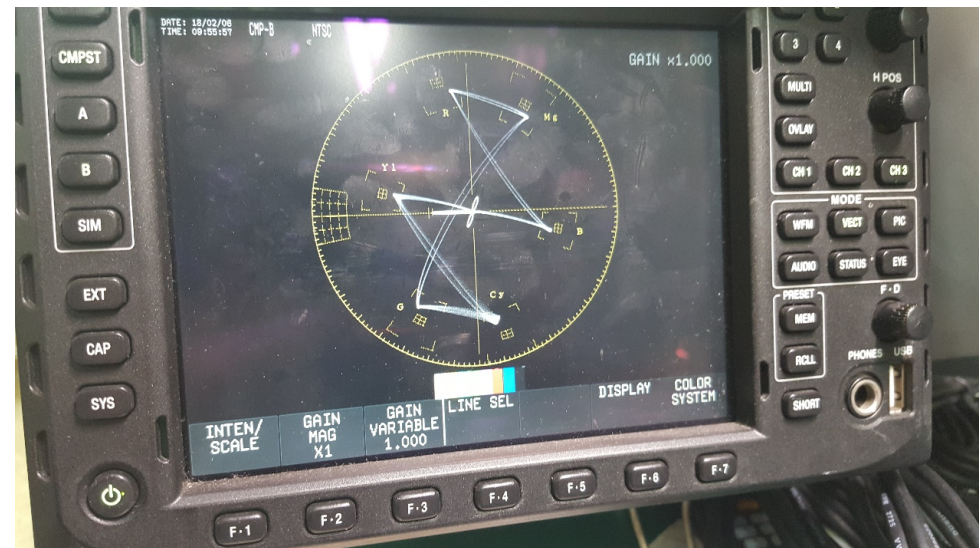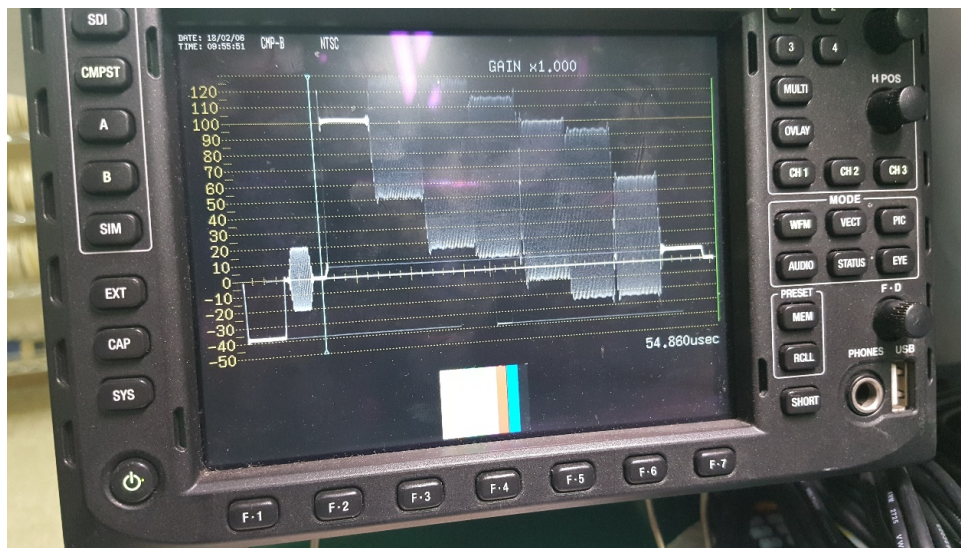

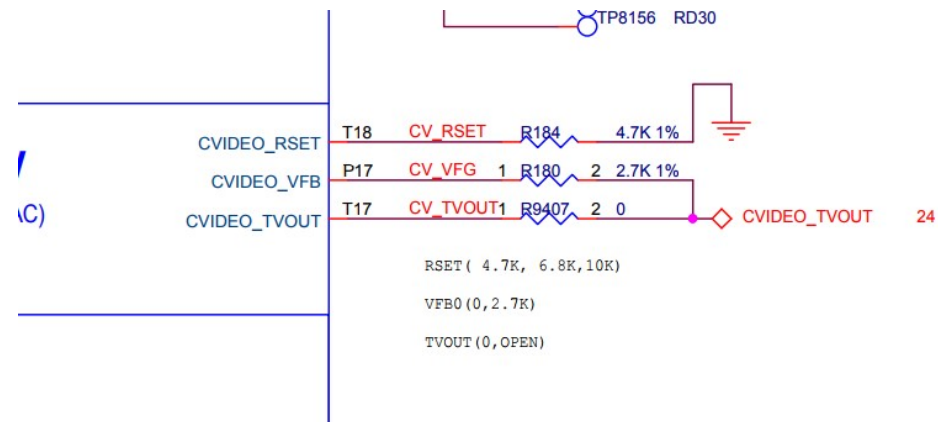

R180 – 3.0K, R184 – 6.8K, R9407-0

